
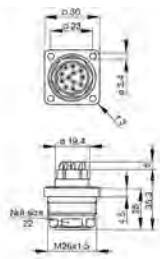


## Product information N11R BM FA F Metall/metal

Industrial Connecting Solutions: Circular Connectors: MIL, DIN, Universal Connectors: DIN 43651 Connectors (NR series): Surface mounted connector: N11R BM FA F Metall/metal

<http://www.e-catalog.beldensolutions.com/link/57078-24228-256281-256284-24367-24373-36313/en/conf/ui/state>

Name	N11R BM FA F Metall/metal
	
	Surface-mounted connector with flange and filter selection 11 x 1nF, metal housing
<b>Delivery informations</b>	
Availability	available
<b>Product description</b>	
Description	Surface-mounted connector with flange and filter selection 11 x 1nF, metal housing
Type	N11R BM FA F Metall/metal
Order No.	934 392-001
Type of contact	male
Number of contacts	11 + PE
Housing Color	grey
<b>Technical data</b>	
Pin dimensions	1.6 mm
Rated voltage	AC 25 V / DC 50 V
Rated current	5 A
Contact resistance	$\leq 5 \text{ m}\Omega$
Type of termination	solder, solid pins
Mounting	flange
<b>Material</b>	
Contact surface material	Ag
Contact bearer material	PET
Housing material	Zn Al/Ni
<b>Environmental conditions</b>	
Protection class (IEC 60529)	IP 65
Temperature range	-40 °C to +90 °C
<b>Packing unit</b>	
Packaging unit	50 pieces
<b>Scope of delivery and accessories</b>	
Accessories to order separately	can be plugged into N11R EF S; protective cover SHK 2, order no. 733 845-001
<b>Picture</b>	
Drawing	



# HIRSCHMANN

A **BELDEN** BRAND

**Belden Deutschland GmbH**

Im Gewerbepark 2  
58579 Schalksmühle  
Germany  
Phone: +49 7127/14-1806  
E-Mail: [icos-sales@belden.com](mailto:icos-sales@belden.com)

The information published in the websites has been compiled as carefully as possible. It is subject to alteration without notice in technical as well as in price-related/commercial respect. The complete information and data were available on user documentation. Mandatory information can only be obtained by a concrete query.