



HIRSCHMANN

A BELDEN BRAND

Product information GDME 3020 grau/grey

Industrial Connecting Solutions:Archive - Industrial Connectors:Rectangular connectors GDM-series (Archive):Type A EN 175301-803 (DIN 43650) / ISO 4400:Cable socket with electronic insert:GDME 3020 grau/grey

<http://www.e-catalog.beldensolutions.com/link/57078-24228-62529-86162-24310-24314-39803/en/conf/ui/state>

Name	GDME 3020 grau/grey
	
	cable socket with central screw M 3 x 40, strain relief and transparent cover, possibility to fit electronic inserts
Delivery informations	
Availability	available
Product description	
Description	cable socket with central screw M 3 x 40, strain relief and transparent cover, possibility to fit electronic inserts
Type	GDME 3020 grau/grey
Order No.	934 455-106
Other standard types	black housing, Order no. 934 455-100
Number of contacts	3 + PE
Cable gland	M20 (black)
Conductor size	max. 1.5 mm ²
Standard	DIN EN 175 301-803-A
Housing Color	black, with transparent cover
Construction type	A
Technical data	
Pin dimensions	6.3 mm x 0.8 mm, 4.8 mm x 0.8 mm
Rated voltage	AC 400 V, DC 250 V without inserts
Rated current	16 A
Contact resistance	<= 4 mOhm
Type of termination	screw
Suitable cables	8 mm to 14 mm diameter
Mounting	central nut
Material	
Contact surface material	Sn
Contact bearer material	PA
Housing material	PA
Environmental conditions	
Protection class (IEC 60529)	IP 65 (gasket necessary)
Pollution severity	3
Temperature range	-40 °C to +85 °C
Inflammability class	
Housing	94 V1
Contact bearer	94 V1
Approvals	
VDE	in preparation
SEV	in preparation
GL	in preparation
Packing unit	
Packaging unit	50 pieces

Industrial Connecting Solutions:Archive - Industrial Connectors:Rectangular connectors GDM-series (Archive):Type A EN 175301-803 (DIN 43650) / ISO 4400:Cable socket with electronic insert:GDME 3020 grau/grey

<http://www.e-catalog.beldensolutions.com/link/57078-24228-62529-86162-24310-24314-39803/en/conf/uistate>


Scope of delivery and accessories

Accessories to order separately

(NBR) flat gasket GDM 3-7,
Order no. 730 801-002;
(EPDM) flat gasket GDM 3-21,
Order no. 731 739-004;
knurled screw GDME 3N-7,
Order no. 732 280-001

Picture

Drawing

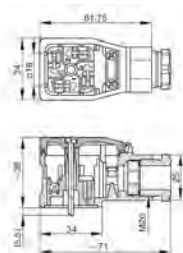

Belden Deutschland GmbH

Im Gewerbepark 2
58579 Schalksmühle
Germany
Phone: +49 7127/14-1806
E-Mail: icos-sales@belden.com

The information published in the websites has been compiled as carefully as possible. It is subject to alteration without notice in technical as well as in price-related/commercial respect. The complete information and data were available on user documentation. Mandatory information can only be obtained by a concrete query.