




## Product information GML 216 NJ LED 24 VR YE schwarz/black

Industrial Connecting Solutions:Rectangular Connectors:Valve Connectors (Type A -B -C):Type B:Field Attachable Valve Connectors:Valve Connectors with electronic insert (Industrial standard):GML 216

NJ LED 24 VR YE schwarz/black

<http://www.e-catalog.beldensolutions.com/link/57078-24228-256261-256266-256271-276218-24327-38204/en/conf/ulistate>

<b>Name</b>	GML 216 NJ LED 24 VR YE schwarz/black
	
	function indicator (LED) with freewheeling diode and protective circuit (varistor)
<b>Delivery informations</b>	
Availability	available
<b>Product description</b>	
Description	function indicator (LED) with freewheeling diode and protective circuit (varistor)
Type	GML 216 NJ LED 24 VR YE schwarz/black
Order No.	934 459-002
Other standard types	transparent housing, cable gland grey; Order No. 934 459-003
Number of contacts	2 + PE
Cable gland	M 16 (black)
Conductor size	max. 1.5 mm <sup>2</sup>
Standard	industrial standard (11 mm)
Housing Color	transparent
Construction type	B
<b>Description of Wiring</b>	
LED color	LED yellow
Suppressor	Varistor
<b>Technical data</b>	
Pin dimensions	6.3 mm x 0.8 mm
Rated voltage	AC/DC 24 V
Rated current	8 A
Contact resistance	<= 4 mOhm
Type of termination	screw / cable shoe / cable eye
Suitable cables	4.5 mm to 10 mm diameter
Mounting	central screw
<b>Material</b>	
Contact surface material	Sn
Contact bearer material	PA
Housing material	PA
<b>Environmental conditions</b>	
Protection class (IEC 60529)	IP 65
Pollution severity	3
Temperature range	-40 °C to +90 °C
<b>Inflammability class</b>	
Housing	94 V-1
Contact bearer	94 HB
<b>Approvals</b>	
UR	in preparation
VDE	in preparation
<b>Packing unit</b>	
Packaging unit	50 pieces



# HIRSCHMANN

A BELDEN BRAND

Industrial Connecting Solutions:Rectangular Connectors:Valve Connectors (Type A -B -C):Type B:Field Attachable Valve Connectors:Valve Connectors with electronic insert (Industrial standard):GML 216

NJ LED 24 VR YE schwarz/black

<http://www.e-catalog.beldensolutions.com/link/57078-24228-256261-256266-256271-276218-24327-38204/en/conf/uistate>


#### Scope of delivery and accessories

##### Accessories to order separately

(NBR) flat gasket GM 207-3, Order No. 731 423-002; knurled screw GDM 3011-8, Order No. 732 574-001; stainless steel screw GDM 3011 RF-1, Order No. 734 363-001

#### Picture

##### Drawing

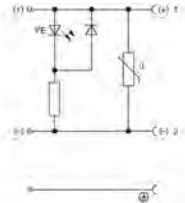

#### Belden Deutschland GmbH

Im Gewerbepark 2

58579 Schalksmühle

Germany

Phone: +49 7127/14-1806

E-Mail: [icos-sales@belden.com](mailto:icos-sales@belden.com)

The information published in the websites has been compiled as carefully as possible. It is subject to alteration without notice in technical as well as in price-related/commercial respect. The complete information and data were available on user documentation. Mandatory information can only be obtained by a concrete query.