


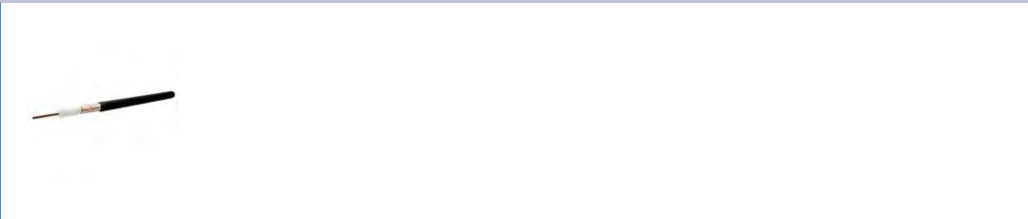

## Product information BAT-ANT-N-LC-G-100m-IP65

Industrial Ethernet:Industrial Wireless LAN:Accessories:Antenna:BAT-ANT-N-LC-G-100m-IP65

<http://www.e-catalog.beldensolutions.com/link/57078-24455-49859-24498-24499-40995/en/conf/uistate>

|  |   |
|--|---|
| Name                                     | BAT-ANT-N-LC-G-100m-IP65  |
|  |   |
|  | Leaky Cable for 2.4GHz; black   |
| <b>Delivery informations</b>             |   |
| Availability                             | available   |
| <b>Product description</b>               |   |
| Description                              | Leaky Cable for 2.4GHz; black   |
| Type                                     | BAT-ANT-N-LC-G-100m-IP65  |
| Order No.                                | 943 981-101   |
| Cable length                             | 100 m   |
| Cable specification                      | 2 x N male connectors; 1.5 dB at 2.4GHz   |
| <b>Radio technology</b>                  |   |
| Range                                    | -   |
| Frequency band                           | 2000 MHz - 2900 MHz   |
| Polarisation                             | -   |
| Elevation, Azimuth                       | -   |
| VSWR                                     | -   |
| Gain                                     | Longitudinal Attenuation between 2.4 and 2.485 GHz; LC at 10 cm from a concrete floor 15 dB/100 m; LC bei 15 mm from a metal surface 17 dB/100 m; LC directly against a metal surface 34 dB/100 m |
| Antenna connector                        | N-connector   |
| <b>Ambient conditions</b>                |   |
| Operating temperature                    | -40 °C to +85 °C  |
| Storage/transport temperature            | -70 °C to +85 °C  |
| Wind load                                | -   |
| <b>Mechanical construction</b>           |   |
| Dimensions (W x H x D)                   | 100m; d=15mm  |
| Mounting                                 | wall, minimum bending radius, single bend mm (in) 200 (7.87)  |
| Protection class                         | IP 65   |
| Material                                 | -   |
| Weight                                   | 24 kg   |
| <b>Scope of delivery and accessories</b> |   |
| Scope of delivery                        | Leaky Cable, 2 x N-connector preassembled, 1 x terminator 50 Ohm, 100 x fastening clip  |

For more information please contact:

**Hirschmann Automation and Control GmbH**

Stuttgarter Strasse 45-51

72654 Neckartenzlingen

Germany

Phone: +49 7127/14-1809

E-Mail: [inet-sales@belden.com](mailto:inet-sales@belden.com)

The information published in the websites has been compiled as carefully as possible. It is subject to alteration without notice in technical as well as in price-related/commercial respect. The complete information and data were available on user documentation. Mandatory information can only be obtained by a concrete query.