




Product information Rectangular connectors - GAN-DFFE7X-AG0200C1-XC607-AD

Industrial Connecting Solutions:Rectangular Connectors:Valve Connectors (Type A -B -C):Type A:Overmolded single ended Valve Connectors:Valve Connectors (DIN EN 175 301-803):Rectangular connectors

<http://www.e-catalog.beldensolutions.com/link/57078-24228-256261-256266-256270-276214-158164-147415/en/GAN-DFFE7X-AG0200C1-XC607-AD/uistate>

| | |
|---------------------------------|--|
| Name | Rectangular connectors |
| |  |
| | Cable socket with integrally molded lead, protective circuit (suppressor-diode), function indicator (LED), gasket (captive) and central screw, cable length 2m |
| Delivery informations | |
| Availability | available |
| Product description | |
| Description | Cable socket with integrally molded lead, protective circuit (suppressor-diode), function indicator (LED), gasket (captive) and central screw, cable length 2m |
| Type | GAN-DFFE7X-AG0200C1-XC607-AD |
| Order No. | 934 562-021 |
| Number of contacts | 2 + PE |
| Cable material | PVC |
| Cable color | grey |
| Cable length | 2 m |
| Cable diameter | 5.5 mm |
| Conductor size | 0.75 mm ² |
| Cable specification | LiYY 3G x 0.75 mm |
| Standard | DIN EN 175 301-803-A |
| Color of Housing | blue transparent, coding plate black |
| Construction type | A |
| Description of Wiring | |
| LED color | LED yellow (bipolar) |
| Suppressor | supressior diode |
| Technical data | |
| Contact dimensions | 6.3 mm x 0.8 mm, 4.8 mm x 0.8 mm |
| Wire stranding | 24 x 0.2 |
| Rated voltage | AC/DC 24 V |
| Rated current | 10 A |
| Contact resistance | ≤ 10 mΩ |
| Mounting | central nut M3 |
| Material | |
| Contact surface material | CuSn |
| Contact bearer material | PA 66 |
| Housing material | PUR |
| Environmental conditions | |
| Protection class (IEC 60529) | IP65, IP67 |
| Pollution severity | 3 |
| Temperature range | -25 °C ... 80 °C |
| Inflammability class | |
| Housing | 94 HB |
| Cable | fire resist. IEC 60332-1, DIN VDE 0472 Part 804 type B |
| Contact bearer | 94 V0 |
| Approvals | |
| VDE | VDE |

Industrial Connecting Solutions:Rectangular Connectors:Valve Connectors (Type A -B -C):Type A:Overmolded single ended Valve Connectors:Valve Connectors (DIN EN 175 301-803):Rectangular connectors


<http://www.e-catalog.beldensolutions.com/link/57078-24228-256261-256266-256270-276214-158164-147415/en/GAN-DFFE7X-AG0200C1-XC607-AD/ui/state>

Packing unit

Packaging unit | 50 pieces

Picture

Drawing

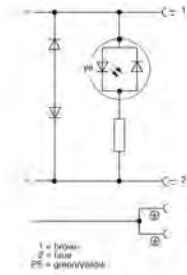

Belden Deutschland GmbH

Im Gewerbepark 2
58579 Schalksmühle
Germany
Phone: +49 7127/14-1806
E-Mail: icos-sales@belden.com

The information published in the websites has been compiled as carefully as possible. It is subject to alteration without notice in technical as well as in price-related/commercial respect. The complete information and data were available on user documentation. Mandatory information can only be obtained by a concrete query.