 


Thermal Transfer Labels

These labels are used for component marking. Self-laminating labels for wire and cable marking are also available, see page 153.


See pages 140–141 for more information on label materials.



Product Selection															
Article No.	Part No.	Type	Drawing Reference	Width (W)		Height (H)		Vertical Repeat (H2)		Horizontnal Repeat (W2)		Width of Liner (W3)		Labels per Row	Pkg. Qty.
			(pages 151–152)	In.	(mm.)	In.	(mm.)	In.	(mm.)	In.	(mm.)	In.	(mm.)		
101 Material															
596-00020	TAG77T1-101	TAG77T1	A	3.0"	(76.2)	.9375"	(23.8)	1.0"	(25.4)	3.0"	(76.2)	3.12"	(79.2)	1	2000
250 Material															
598-00277	TYHCT-250	TYHC	B	.25"	(6.35)	1.5"	(38.1)	1.625	41.27	.25"	(6.35)	4.12"	(104.7)	16	5000
596-21250	TAG21T6-250	TAG21T6	C	.5"	(12.7)	.75"	(19.05)	.875"	(22.22)	.5"	(12.7)	3.25"	(82.55)	6	10000
596-11250	TAG11T4-250	TAG11T4	D	.65"	(16.5)	.2"	(5.08)	.3"	(7.62)	.65"	(16.5)	2.6"	(66.04)	4	5000
596-28250	TAG28T4-250	TAG28T4	E	.80"	(20.3)	1.43"	(36.3)	1.62"	(41.1)	.80"	(20.3)	3.45"	(87.6)	4	5000
596-15250	TAG15T3-250	TAG15T3	F	1.0"	(25.4)	.5"	(12.7)	.6"	(15.24)	1.0"	(25.4)	3.35"	(85.09)	3	10000
596-00044	TAG35T2-250	TAG35T2	G	2.0"	(50.8)	.375"	(9.53)	.50"	(12.7)	2.0"	(50.8)	4.1"	(104.14)	2	10000
336 Material															
596-00026	TAG96T1-336	TAG96T1	H	1.875"	(47.6)	.25"	(6.35)	.375"	(9.35)	1.875"	(47.6)	2.0"	(50.8)	1	5000
596-00041	TAG69T1-336	TAG69T1	I	2.0"	(50.8)	.275"	(6.98)	.5"	(12.7)	2.0"	(50.8)	2.125"	(53.97)	1	10000
596-00040	TAG68T1-336	TAG68T1	J	3.8"	(96.5)	.275"	(6.98)	.5"	(12.7)	3.8"	(96.5)	4.0"	(101.6)	1	10000
795 Material															
596-15795	TAG15T3-795	TAG15T3	F	1.0"	(25.4)	.5"	(12.7)	.6"	(15.24)	1.0"	(25.4)	3.35"	(85.09)	3	10000
596-27795	TAG27T1-795	TAG27T1	K	1.5"	(38.11)	.75"	(19.05)	.875"	(22.2)	1.5"	(38.11)	2.20"	(55.88)	1	3000
596-75795	TAG75T1-795	TAG75T1	L	2.0"	(50.8)	.625"	(15.87)	.75"	(19.05)	2.0"	(50.8)	2.12"	(53.8)	1	2000
596-73795	TAG73T1-795	TAG73T1	BB	2.0"	(50.8)	1.0"	(25.4)	1.125"	(28.57)	1.0"	(25.4)	2.20"	(55.83)	1	3000
596-76795	TAG76T1-795	TAG76T1	M	2.5"	(63.5)	2.0"	(50.8)	2.12"	(53.8)	2.5"	(63.5)	2.62"	(66.5)	1	1000
596-72795	TAG72T1-795	TAG72T1	N	2.75"	(69.85)	1.25"	(31.75)	1.375"	(34.93)	2.75"	(69.85)	2.95"	(74.95)	1	3000
596-78795	TAG78T1-795	TAG78T1	O	3.0"	(76.2)	4.0"	(101.6)	4.12"	(104.7)	3.0"	(76.2)	3.12"	(79.2)	1	500
596-80795	TAG80T1-795	TAG80T1	P	3.0"	(76.2)	5.0"	(127)	3.0"	(76.2)	3.0"	(76.2)	3.125"	(79.37)	1	500
596-79795	TAG79T1-795	TAG79T1	Q	4.0"	(101.6)	2.0"	(50.8)	2.12"	(53.97)	4.0"	(101.6)	4.25"	(107.9)	1	500
822 Material															
596-27822	TAG27T1-822	TAG27T1	K	1.5"	(38.11)	.75"	(19.05)	.875"	(22.2)	1.5"	(38.11)	2.20"	(55.88)	1	3000
596-00019	TAG75T1-822	TAG75T1	L	2.0"	(50.8)	.625"	(15.87)	.75"	(19.05)	2.0"	(50.8)	2.12"	(53.8)	1	2000
596-70822	TAG70T12-822	TAG70T12	R	.25"	(6.35)	.25"	(6.35)	.5"	(12.7)	.25"	(6.35)	3.2"	(81.2)	12	10000
596-00028	TAGPP1T6-822	TAGPP1T6	S	.625"	(15.87)	.333"	(8.45)	.75"	(19.05)	.625"	(15.87)	3.8"	(96.52)	6	1000
596-00082	TAGPP1T6-82210M	TAGPP1T6	S	.625"	(15.87)	.333"	(8.45)	.75"	(19.05)	.625"	(15.87)	3.8"	(96.52)	6	10000
596-11822	TAG11T4-822	TAG11T4	D	.65"	(16.5)	.2"	(5.08)	.3"	(7.62)	.65"	(16.5)	2.6"	(66.04)	4	5000
596-00046	TAGPP2T6-822	TAGPP2T6	U	.66"	(16.7)	.33"	(8.38)	.75"	(19.05)	.66"	(16.7)	4.125"	(104.7)	6	1000
596-00083	TAGPP3T4-822	TAGPP3T4	V	.688"	(17.4)	.25"	(6.35)	.375"	(9.52)	.688"	(17.4)	2.9"	(73.66)	4	1000
596-13822	TAG13T4-822	TAG13T4	W	.75"	(19.05)	.25"	(6.35)	.35"	(8.89)	.75"	(19.05)	3.35"	(85.09)	4	10000
596-15822	TAG15T3-822	TAG15T3	F	1.0"	(25.4)	.5"	(12.7)	.6"	(15.24)	1.0"	(25.4)	3.35"	(85.09)	3	10000
596-84822	TAG84T3-822	TAG84T3	T	1.25"	(31.75)	.375"	(9.53)	.50"	(12.7)	1.25"	(31.75)	4.0"	(101.6)	3	10000
596-00023	TAG83T1-822	TAG83T1	X	4.0"	(101.6)	.312"	(7.52)	.438"	(11.13)	4.0"	(101.6)	4.1"	(104.14)	1	5000
596-00022	TAG81T8-822	TAG81T8	Y	.325"	(8.25)	.20"	(5.08)	.30"	(7.62)	.325"	(8.25)	2.6"	(66.04)	8	5000
596-16822	TAG16T3-822	TAG16T3	Z	.9"	(22.86)	.25"	(6.35)	.35"	(8.89)	.9"	(22.86)	3.35"	(85.09)	3	10000
596-17822*	TAG17T2-822	TAG17T2	AA	1.5"	(38.11)	.25"	(6.35)	.35"	(8.89)	1.65"	(41.98)	3.35"	(85.09)	2	10000
596-73822	TAG73T1-822	TAG73T1	BB	2.0"	(50.8)	1.0"	(25.4)	1.125"	(28.57)	1.0"	(25.4)	2.20"	(55.83)	1	3000
596-42822	TAG72T1-822	TAG72T1	N	2.75"	(69.85)	1.25"	(31.75)	1.375"	(34.93)	2.75"	(69.85)	2.95"	(74.95)	1	3000
596-71822	TAG71T5-822	TAG71T5	CC	.5"	(12.7)	.43"	(11.1)	.662"	(16.81)	.43"	(11.1)	3.35"	(85.09)	5	10000
596-82822	TAG82T2-822	TAG82T2	DD	1.5"	(38.1)	.25"	(6.35)	.30"	(7.62)	1.5"	(38.1)	3.20"	(81.28)	2	10000

Dimensions are approximate and subject to technical changes. Use **Part No.** for ordering and **Type** for specification purposes.

* TAG17T2-822 not recommended for TT10SM, TT210SM, TT300SM, and TT310SM printers. Use TAG82T2 instead.

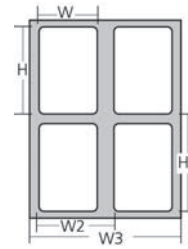Thermal Transfer Labels *continued*

Product Selection			Drawing Reference	Width (W)	Height (H)	Vertical Repeat (H2)	Horizontal Repeat (W2)	Width of Liner (W3)	Labels per Row	Pkg. Qty.
Article No.	Part No.	Type								
822C Material*										
596-00029	TAGPP1T6-822C	TAGPP1T6	S	.625" (15.87)	.333" (8.45)	.75" (19.05)	.625" (15.87)	3.8" (96.52)	6	1000
596-00030	TAGPP1T6-822C10M	TAGPP1T6	S	.625" (15.87)	.333" (8.45)	.75" (19.05)	.625" (15.87)	3.8" (96.52)	6	10000
596-00003	TAG11T4-822C	TAG11T4	D	.65" (16.5)	.2" (5.08)	.3" (7.62)	.65" (16.5)	2.6" (66.04)	4	5000
596-00047	TAGPP2T6-822C	TAGPP2T6	U	.66" (16.7)	.33" (8.38)	.75" (19.05)	.66" (16.7)	4.125" (104.7)	6	1000
596-00084	TAGPP3T4-822C	TAGPP3T4	V	.688" (17.4)	.25" (6.35)	.375" (9.52)	.688" (17.4)	2.9" (73.66)	4	1000
596-00001	TAG15T3-822C10M	TAG15T3	F	1.0" (25.4)	.5" (12.7)	.6" (15.24)	1.0" (25.4)	3.35" (85.09)	3	10000
596-00043	TAG27T1-822C	TAG27T1	K	1.5" (38.11)	.75" (19.05)	.875" (22.2)	1.5" (38.11)	2.20" (55.88)	1	3000
900 Material**										
596-13900	TAG13T4-900	TAG13T4	W	.75" (19.05)	.25" (6.35)	.35" (8.89)	.75" (19.05)	3.35" (85.09)	4	10000
596-16900	TAG16T3-900	TAG16T3	Z	.9" (22.86)	.25" (6.35)	.35" (8.89)	.9" (22.86)	3.35" (85.09)	3	10000
DTH Material***										
596-00033	TAG13T4-DTH	TAG13T4	W	.75" (19.05)	.25" (6.35)	.35" (8.89)	.75" (19.05)	3.35" (85.09)	4	10000
596-00034	TAG16T3-DTH	TAG16T3	Z	.9" (22.86)	.25" (6.35)	.35" (8.89)	.9" (22.86)	3.35" (85.09)	3	10000
596-00035	TAG15T3-DTH	TAG15T3	F	1.0" (25.4)	.5" (12.7)	.6" (15.24)	1.0" (25.4)	3.35" (85.09)	3	10000
596-00036	TAG27T2-DTH	TAG27T2	K	1.5" (38.11)	.75" (19.05)	.875" (22.2)	1.5" (38.11)	2.20" (55.83)	2	10000
596-00037	TAG99T1-DTH	TAG99T1	EE	2.0" (50.8)	.25" (6.35)	.375" (9.52)	2.0" (50.8)	2.2" (55.8)	1	2500
596-00038	TAG73T1-DTH	TAG73T1	BB	2.0" (50.8)	1.0" (25.4)	1.125" (28.57)	1.0" (25.4)	2.20" (55.83)	1	3000
596-00039	TAG33T1-DTH	TAG33T1	FF	3.0" (76.2)	2.0" (50.8)	2.125" (53.97)	2.0" (50.8)	3.1" (78.74)	1	1000
PAP - Non-Adhesive Cardstock										
596-00017	TAG74T2-PAP	TAG74T2	GG	1.75" (44.45)	.375" (9.53)	.562" (14.2)	1.75" (44.45)	3.5" (88.9)	2	1000
596-00025	TAG82T2-PAP	TAG86T2	HH	2.0" (50.8)	.396" (10.05)	.562" (14.2)	2.0" (50.8)	4.05" (102.0)	2	1000
596-00024	TAG85T1-PAP	TAG85T1	II	3.0" (76.2)	.50" (12.7)	.60" (15.24)	3.0" (76.2)	3.2" (8.28)	1	5000

Dimensions are approximate and subject to technical changes. Use **Part No.** for ordering and **Type** for specification purposes.

* Clear

** Not recommended for TT1210 printer

*** For use with DTH ribbons only!

Thermal Transfer Labels *continued*

(Not shown to scale)



 
TAG77T1-101

A



TYHCT-250

B




TAG21T6-250

C



TAG11T4-250,
TAG11T4-822,
TAG11T4-822C

 D



TAG28T4-250

E




TAG15T3-DTH,
TAG15T3-795,
TAG15T3-822,
TAG15T3-822C,
TAG15T3-250

F



TAG35T2-250

G

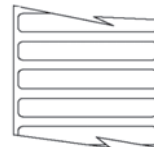


TAG96T1-336

H




TAG69T1-336

I

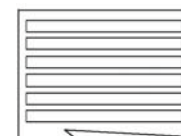


TAG68T1-336

J

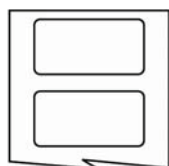


TAG27T1-822,
TAG27T1-795,
TAG27T1-822C,
TAG27T2-DTH

K

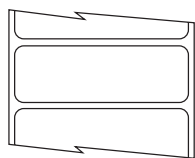

TAG75T1-795

L

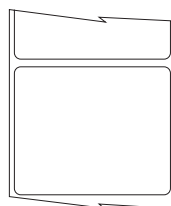

TAG76T1-795

M



TAG72T1-795, TAG72T1-822

N




TAG78T1-795

O




TAG80T1-795

P

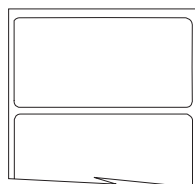

TAG79T1-795

 Q



TAG70T12-822

R



TAGPP1T6-822,
TAGPP1T6-822C,
TAGPP1T6-82210M,
TAGPP1T6-822C10M

S




TAG84T3-822

T

Thermal Transfer Labels *continued*

(Not shown to scale)

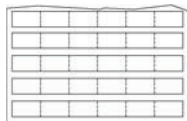

TAGPP2T6-822,
TAGPP2T6-822C
U



TAGPP3T4-822,
TAGPP3T4-822C
V



TAG13T4-822,
TAG13T4-900,
TAG13T4-DTH
W



TAG83T1-822
X




TAG81T8-822
Y




TAG16T3-DTH,
TAG16T3-822,
TAG16T3-900
Z



TAG17T2-822
AA

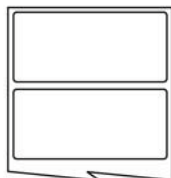

 
TAG73T1-822, TAG73T1-
DTH, TAG73T1-795
BB



TAG71T5-822
CC




TAG82T2-822
DD

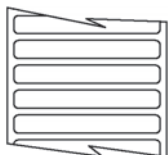


TAG99T1-DTH
EE




TAG33T1-DTH
FF

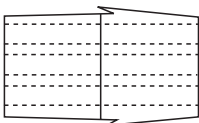

TAG74T2-PAP
GG

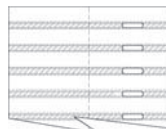

TAG82T2-PAP
HH

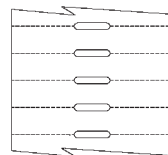

TAG85T1-PAP
II