

## T50MR9M4

Screw Mount Tie, 50lb. 8.46" Max Bun Dia 1.77" #10 Screw PA66, Natural, 1000/pk

Article Number: 113-05007

Part Number: T50MR9M4

Type: T50MR

Material: PA66




### 1. Base Data

---

<b>Part No.</b>	T50MR9M4
<b>Type</b>	T50MR
<b>Color</b>	Natural
<b>Features</b>	One-piece, all plastic ties for quick, simple cable mounting.
<b>Application</b>	The 'T' range of cable ties have a built in mounting hole and once fastened around the cables the bundle can be simply secured to the panel with a screw or bolt.

### 2. Product Dimensions


---

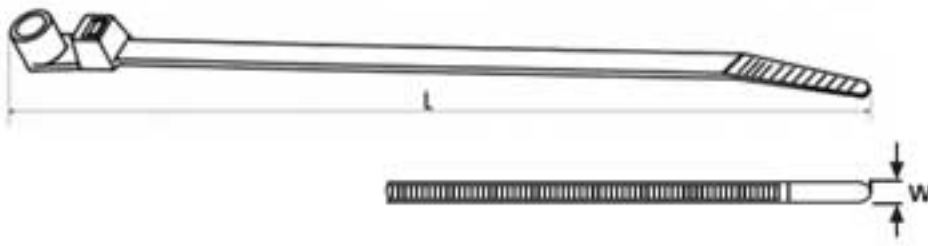

<b>Min. Tensile Strength</b>	50 lbs / 225 N
<b>Length (L)</b>	8.46 " / 215 mm
<b>Width (W)</b>	.18 " / 4.7 mm
<b>Height (H)</b>	.22 " / 5.7 mm
<b>Min. Ø Bundle</b>	.06 " / 1.5 mm
<b>Max. Ø Bundle</b>	1.77 " / 45.0 mm
<b>Mounting Hole Ø</b>	.21 " / 5.4

#### 4. Material and Specifications

---

<b>Material</b>	Polyamide 6.6 (PA66)
<b>Material Shortcut</b>	PA66
<b>Flammability</b>	UL94 V2
<b>Operating Temperature</b>	-40 °F to +185 °F (-40 °C to +85 °C) continuous
<b>ROHS Conformity</b>	

#### Logistic and Packaging

---

<b>Packaging Type</b>	bag
<b>Pkg. Qty.</b>	1000
<b>Carton Qty.</b>	5000
<b>UPC</b>	08930608642

**Miscellaneous**

 
---

**UL Recognized (US and Canada)** Yes

### Screw Mount Ties

One-piece, all plastic ties for quick, simple cable mounting.

Material Data	
Material	<b>Polyamide 6.6 (PA66)</b>
Operating Temperature	<b>-40 °F to +185 °F (-40 °C to +85 °C) continuous</b>
Flammability	<b>UL94 V2</b>



Product Selection				Min. Tensile Strength lbs. (N)	Length (L) in. (mm)	Max. Ø Bundle in. (mm)	Width (W) in. (mm)	Color	Pkg. Qty.	
Article No.	Part No.	Type	Mounting							
<b>T18MR</b>										
113-00026	<b>T18MR9C2</b>	T18MR	# 4 screw	18 lbs (80)	4.33" (110)	.79" (20)	.10" (2.5)	Natural	100	
113-00028	<b>T18MR9M4</b>	T18MR		18 lbs (80)	4.33" (110)	.79" (20)	.10" (2.5)	Natural	1000	
113-00022	<b>T18MR0C2</b>	T18MR		18 lbs (80)	4.33" (110)	.79" (20)	.10" (2.5)	Black	100	
113-00024	<b>T18MR0M4</b>	T18MR		18 lbs (80)	4.33" (110)	.79" (20)	.10" (2.5)	Black	1000	
<b>T30MR</b>										
113-03019	<b>T30MR9C2</b>	T30MR	# 8 screw	30 lbs (135)	6.30" (160)	1.26" (32)	.14" (3.5)	Natural	100	
113-00036	<b>T30MR9M4</b>	T30MR		30 lbs (135)	6.30" (160)	1.26" (32)	.14" (3.5)	Natural	1000	
113-03010	<b>T30MR0C2</b>	T30MR		30 lbs (135)	6.30" (160)	1.26" (32)	.14" (3.5)	Black	100	
113-03011	<b>T30MR0M4</b>	T30MR		30 lbs (135)	6.30" (160)	1.26" (32)	.14" (3.5)	Black	1000	
<b>T50MR</b>										
113-05004	<b>T50MR9C2</b>	T50MR	# 10 screw	48 lbs (215)	8.46" (215)	1.77" (45)	.18" (4.6)	Natural	100	
113-05007	<b>T50MR9M4</b>	T50MR		48 lbs (215)	8.46" (215)	1.77" (45)	.18" (4.6)	Natural	1000	
113-05000	<b>T50MR0C2</b>	T50MR		48 lbs (215)	8.46" (215)	1.77" (45)	.18" (4.6)	Black	100	
113-05002	<b>T50MR0M4</b>	T50MR		48 lbs (215)	8.46" (215)	1.77" (45)	.18" (4.6)	Black	1000	
<b>T50MRT</b>										
113-05101	<b>T50MRT9C2</b>	T50MRT	#6-32 tap thru screw	50 lbs (225)	8.47" (215)	1.77" (45)	.19" (4.7)	Natural	100	
113-05102	<b>T50MRT9M4</b>	T50MRT		50 lbs (225)	8.47" (215)	1.77" (45)	.19" (4.7)	Natural	1000	
113-05100	<b>T50MRT0C2</b>	T50MRT		50 lbs (225)	8.47" (215)	1.77" (45)	.19" (4.7)	Black	100	
113-00037	<b>T50MRT0M4</b>	T50MRT		50 lbs (225)	8.47" (215)	1.77" (45)	.19" (4.7)	Black	1000	
<b>T50MI</b>										
113-00032	<b>T50MI9C2</b>	T50MI	# 10 screw	50 lbs (225)	12.40" (315)	3.35" (85)	.19" (4.7)	Natural	100	
113-00033	<b>T50MI9M4</b>	T50MI		50 lbs (225)	12.40" (315)	3.35" (85)	.19" (4.7)	Natural	1000	
113-00038	<b>T50MI0C2</b>	T50MI		50 lbs (225)	12.40" (315)	3.35" (85)	.19" (4.7)	Black	100	
113-00031	<b>T50MI0M4</b>	T50MI		50 lbs (225)	12.40" (315)	3.35" (85)	.19" (4.7)	Black	1000	
<b>T50ML</b>										
113-05419	<b>T50ML9C2</b>	T50ML	# 10 screw	50 lbs (225)	15.35" (390)	4.00" (100)	.18" (4.6)	Natural	100	
113-05403	<b>T50ML9M4</b>	T50ML		50 lbs (225)	15.35" (390)	4.00" (100)	.18" (4.6)	Natural	1000	
113-00007	<b>T50ML0C2</b>	T50ML		50 lbs (225)	15.35" (390)	4.00" (100)	.18" (4.6)	Black	100	
113-00035	<b>T50ML0M4</b>	T50ML		50 lbs (225)	15.35" (390)	4.00" (100)	.18" (4.6)	Black	1000	
<b>T120MR</b>										
113-12029	<b>T120MR9K2</b>	T120MR	# 1/4" screw	120 lbs (535)	15.55" (395)	4.02" (102)	.30" (7.6)	Natural	50	
113-00018	<b>T120MR9H4</b>	T120MR		120 lbs (535)	15.55" (395)	4.02" (102)	.30" (7.6)	Natural	500	
113-12020	<b>T120MR0K2</b>	T120MR		120 lbs (535)	15.55" (395)	4.02" (102)	.30" (7.6)	Black	50	
113-00011	<b>T120MR0H4</b>	T120MR		120 lbs (535)	15.55" (395)	4.02" (102)	.30" (7.6)	Black	500	

Installation tools - MK7, MK7HT, MK7P, MK9, MK9HT, MK9P. Dimensions are approximate and subject to technical changes. Use **Part No.** for ordering and **Type** for specification purposes.