


"F" Series Connectors

"F" connectors allow a coaxial cable to maintain a 75-ohm impedance. They are used with 59, 6, 7 and 11 cable series. Use of "F" connectors helps avoid impedance problems with interfaces and splices.


- 59 and 6 "F" connectors are available in a convenient feed-through design.
- 7 and 11 connectors have an internal pin contact that mate to female ports.
- Our family of universal connectors is designed to accept 60% through Quad shield cables. They maintain good electrical and mechanical properties and are installed with a crimp tool.

360 "F" Connectors

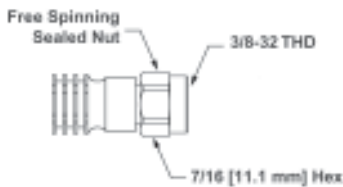

Series 56 and 6


Part Number	Cable Type	Crimp Size
GF-360-59	Series 59	.360 Hex
GF-360-59Q	Series 59 Quad	.360 Hex
GF-360-6	Series 6	.360 Hex
GF-360-6Q	Series 6 Quad	.360 Hex

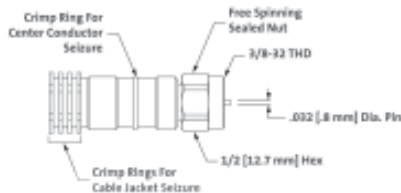

Series 7 and 11

Part Number	Cable Type	Crimp Size
GAF-360-7	Series 7	.410 Hex
GAF-360-7Q	Series 7 Quad	.410 Hex
GAF-360-11	Series 11	.475 Hex
GAF-360-11Q	Series 7 Quad	.475 Hex


USA "F" Connectors

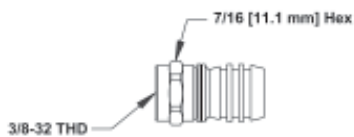

USA "F" Male


Part Number	Cable Type	Crimp Size
GF-59-AHS/USA	60% - Quad	.360 hex
GF-6-AHS/USA	60% - Quad	.360 hex

AHS "F" Connectors

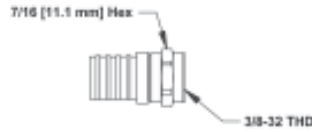

"F" Male Connector

Part Number	Crimp Size	Braid Coverage
GF-59-AHS/290	.324 HEX	40% - 60%
GF-59-AHS/312	.324 HEX	60% - 90%
GF-59-AHS/322	.324 HEX	60% - 90%
GF-59-AHS/342	.324 HEX	Quad 60 / 40%
GF-59-AHS/357	.324 HEX	Quad High Braid %
GF-59-AHP/284	.324 HEX	Low Braid Plenum
GF-59-AHP/312	.324 HEX	High Braid Plenum
GF-6-AHS/322	.324 HEX	40% - 60%
GF-6-AHS/342	.324 HEX	Quad 60 / 40%
GF-6-AHS/357	.324 HEX	Quad High Braid %
GF-6-AHP/312	.324 HEX	Low Braid Plenum
GF-6-AHP/328	.324 HEX	High Braid Plenum

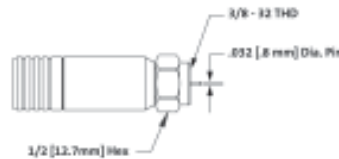


Series 7 Integral Pin

Part Number	Crimp Size	Braid Coverage
GAF-236/051-AHS/368	0.384 Hex	Single Braid
GAF-236/051-AHS/398	0.475 Hex	Quad

Series 11 Integral Pin

Part Number	Crimp Size	Braid Coverage
GAF-11-AHS/460	.475 Hex	Up to 90%
GAF-11-AHS/480	.475 Hex	Quad
GAF-11-AHP/450	.475 Hex	Plenum

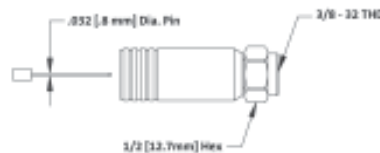

Series 11 Crimp-on Pin

Part Number	Crimp Size	Braid Coverage
GF-11-AHS/460	.100 x .475 Hex	Up to 90%
GF-11-AHS/480	.100 x .475 Hex	Quad
GF-11-AHP/450	.100 x .475 Hex	Plenum