


# Adjustable Wrenches

## Features:

**Precision-machined jaws** are individually chosen and assembled by hand for smooth operation.

Available in high-capacity.

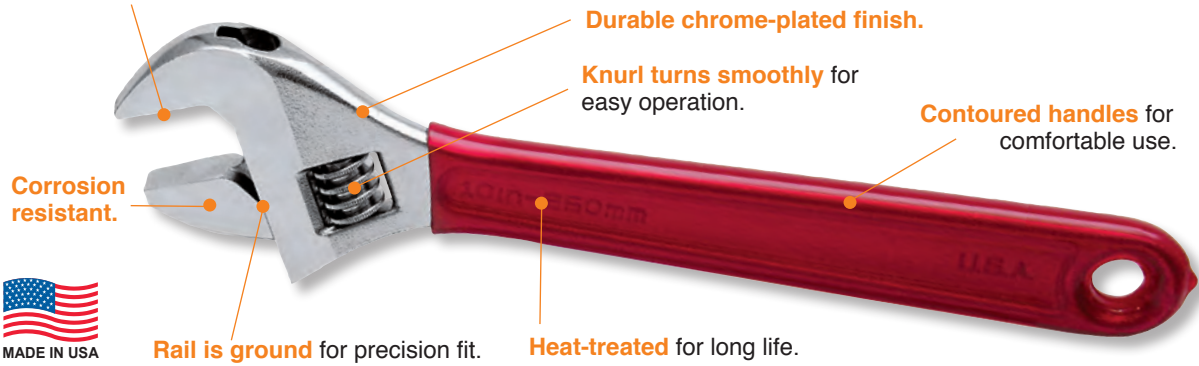

## Adjustable Wrenches – Extra Capacity

*Additional Features:*

- Extra capacity allows use of a smaller size wrench to handle bigger jobs, especially in confined spaces.
- Forged heat-treated alloy steel for maximum strength and light weight.
- High-polish chrome finish.



D507-8

| Cat. No. | Handle Finish              | Length           | Capacity        | Weight (lbs.) |
|----------|----------------------------|------------------|-----------------|---------------|
| 507-6    | high-polish chrome         | 6-1/4" (158 mm)  | 15/16" (23 mm)  | .25           |
| 507-8    | high-polish chrome         | 8-1/4" (209 mm)  | 1-1/8" (28 mm)  | .51           |
| 507-10   | high-polish chrome         | 10-1/4" (260 mm) | 1-5/16" (33 mm) | .86           |
| 507-12   | high-polish chrome         | 12-1/4" (311 mm) | 1-1/2" (38 mm)  | 1.32          |
| D507-6   | plastic-dipped             | 6-3/8" (162 mm)  | 15/16" (23 mm)  | .27           |
| D507-8   | plastic-dipped             | 8-3/8" (213 mm)  | 1-1/8" (28 mm)  | .62           |
| D507-10  | plastic-dipped             | 10-3/8" (264 mm) | 1-5/16" (33 mm) | 1.00          |
| D507-12  | plastic-dipped             | 12-3/8" (315 mm) | 1-1/2" (38 mm)  | 1.54          |
| HD507-6  | heavy-duty, plastic-dipped | 6-3/8" (162 mm)  | 15/16" (23 mm)  | .27           |
| HD507-8  | heavy-duty, plastic-dipped | 8-3/8" (213 mm)  | 1-1/8" (28 mm)  | .54           |
| HD507-10 | heavy-duty, plastic-dipped | 10-3/8" (264 mm) | 1-5/16" (33 mm) | 1.00          |
| HD507-12 | heavy-duty, plastic-dipped | 12-3/8" (315 mm) | 1-1/2" (38 mm)  | 1.54          |

## Adjustable Wrenches – Standard Capacity, Plastic-Dipped Handles

*Additional Features:*

- Plastic-dipped handles for added comfort.
- Forged heat-treated alloy steel for maximum strength and light weight.
- High-polish chrome finish.



D506-15

| Cat. No. | Handle Type | Handle Finish              | Length           | Capacity         | Weight (lbs.) |
|----------|-------------|----------------------------|------------------|------------------|---------------|
| D506-4   | dovetail    | plastic-dipped             | 4-1/2" (114 mm)  | 1/2" (12 mm)     | .13           |
| D506-6   | dovetail    | plastic-dipped             | 6-3/8" (162 mm)  | 3/4" (19 mm)     | .27           |
| D506-15  | tapered     | plastic-dipped             | 15-1/8" (384 mm) | 1-11/16" (42 mm) | 3.21          |
| D500-18  | tapered     | plastic-dipped             | 18-3/8" (467 mm) | 2-1/16" (52 mm)  | 5.02          |
| D500-24  | tapered     | plastic-dipped             | 24-1/4" (616 mm) | 2-1/2" (63 mm)   | 8.26          |
| HD506-4  | dovetail    | heavy-duty, plastic-dipped | 4-1/2" (114 mm)  | 1/2" (12 mm)     | .13           |

All dimensions are in inches and (millimeters).

**▲WARNING:** Always wear approved eye protection.

**▲WARNING:** NOT insulated. Plastic-dipped or slip-on plastic handles are NOT intended for protection against electrical shock.

**▲WARNING:** Do NOT push or hammer wrench.

**▲WARNING:** Do NOT extend handle length.

