

Cushion-Grip Screwdrivers

Conduit-Fitting and Reaming Screwdriver

Additional Features:

- Hooded-blade design keeps tip from slipping out of screws, especially when tightening hard-to-reach conduit fittings. Thicker hood is designed for rugged use.
- Reams and smooths 1/2" (13 mm), 3/4" (19 mm), and 1" (25 mm) thin-wall conduit ends to protect wire and permit correct installation of fittings.
- Reams both the inside and outside of the conduit at the same time.
- Longer Cushion-Grip handle provides comfort and more torque for reaming.
- Replaceable reaming blade is now held in place with a 1/16" set screw.



Cat. No.	Shank Tip Width	Shank Length	Overall Length	Weight (lbs.)
85191	5/16" (8 mm)	2-1/2" (64 mm)	7-1/2" (191 mm)	.50
19353	conduit reamer replacement blade kit			.01

Conduit Reamer

- Locks onto screwdrivers; reams and smooths thin-wall conduit.
- Reams ID and OD at the same time.
- Two set-screws for round- and square-shank screwdrivers.
- Fits up to 3/8" (10 mm) keystone-tip screwdrivers.
- NOT for use on power tools.



Cat. No.	Conduit Capacity	Weight (lbs.)
19352	1/2", 3/4", 1"	.20
19353	conduit reamer replacement blade kit for 19352	.01
19351	conduit reamer replacement blade for 19350	.01


Rapi-Driv® Screwdrivers

Cabinet-Tip Screwdrivers – Rapi-Driv®

Additional Features:

- Crank-action handle spins screws fast with one hand.
- Saves time and effort, especially on long-threaded screws in switch plates, light fixtures, etc.

Cat. No.	Shank Tip Width	Shank Length	Overall Length	Weight (lbs.)
670-3	3/16" (5 mm)	4" (102 mm)	7-3/4" (197 mm)	.15
670-6	3/16" (5 mm)	6" (152 mm)	9-3/4" (248 mm)	.20
671-6	1/4" (6 mm)	6" (152 mm)	9-3/4" (248 mm)	.20

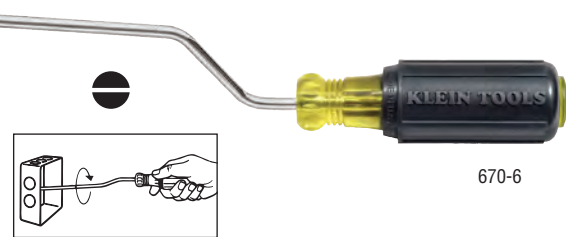


Phillips Screwdrivers – Rapi-Driv®

Additional Features:

- Crank-action handle spins screws fast with one hand.
- Saves time and effort, especially on long-threaded screws in switch plates, light fixtures, etc.

Cat. No.	Tip Size	Shank Length	Overall Length	Weight (lbs.)
681-6	No. 1	6" (152 mm)	9-3/4" (248 mm)	.20
682-6	No. 2	6" (152 mm)	9-3/4" (248 mm)	.25

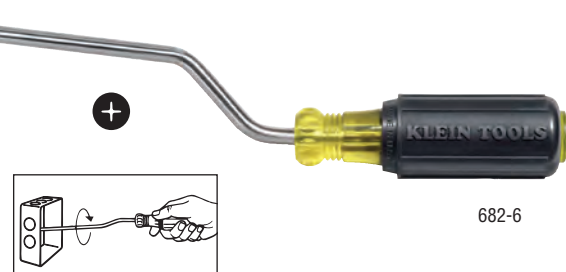

All dimensions are in inches and (millimeters).

⚠ WARNING: Always wear approved eye protection.

⚠ WARNING: NOT insulated. Will NOT protect against electrical shock.

⚠ WARNING: Do NOT use to pry or chisel.

