

Identification

Part number

M

Drawing

Dimensions in mm

Cable entry protection with metric cable entries (IP 68)


metal



19 00 000 5080
19 00 000 5081

20
20

SW	E	Outer cable Ø	Nm
22	24.4	5 ... 9 mm	10
22	24.4	5 ... 9 mm 6 ... 12 mm	10
22	24.4	6 ... 12 mm	10
24	26.5	10 ... 14 mm	10
30	33.5	9 ... 16 mm	12
30	33.5	9 ... 16 mm 13 ... 18 mm	12
30	33.5	13 ... 18 mm	12
40	44	13 ... 20 mm	15
40	44	13 ... 20 mm 18 ... 25 mm	15
40	44	18 ... 25 mm	15
50	55	20 ... 26 mm	15
50	55	22 ... 32 mm	15
50	55	20 ... 26 mm 22 ... 32 mm	15
57	60	32 ... 38 mm	24

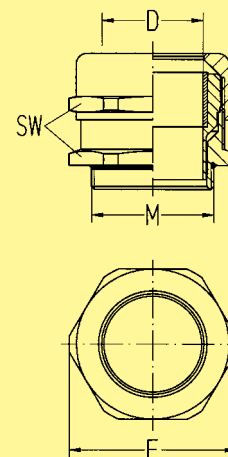

thermoplastic



19 00 000 5180
19 00 000 5182
19 00 000 5184
19 00 000 5190
19 00 000 5192
19 00 000 5194
19 00 000 5196
19 00 000 5197
19 00 000 5198

20
20
20
25
25
32
32
40
40

24	26.4	5 ... 9 mm	4.5
24	26.4	6 ... 12 mm	4.5
27	29.8	10 ... 14 mm	4.5
33	33.5	9 ... 16 mm	5.0
33	36.5	13 ... 18 mm	5.0
42	46.8	13 ... 20 mm	6.5
42	46.8	18 ... 25 mm	6.5
53	58.8	20 ... 26 mm	10.0
53	58.8	22 ... 32 mm	10.0

EMC clamp with metric cable entries (IP 68)



19 62 000 5080
19 62 000 5081
19 62 000 5082
19 62 000 5084
19 62 000 5090
19 62 000 5092
19 62 000 5094
19 62 000 5096
19 62 000 5097
19 62 000 5098

20
20
20
20
25
25
32
32
40
40

SW	E	cable-Ø D	shield-Ø B
22	24.4	6.5 ... 9.5	3.5 ... 8.5
22	24.4	4 ... 6.5	2.5 ... 6.5
22	24.4	7 ... 10.5	6.5 ... 10.5
22	24.4	9 ... 13	6.5 ... 10.5
22	31.2	6.5 ... 9.5	3 ... 8
28	31.2	9 ... 13	4.8 ... 8
35	38.5	11.5 ... 15.5	8 ... 13.5
35	38.5	14 ... 18	9 ... 14.5
43	47.3	17 ... 20.5	15 ... 20
43	47.3	20 ... 25	15 ... 20

