



CADDY® SPEED LINK SLK with Hook – SLK15L3 (196510)

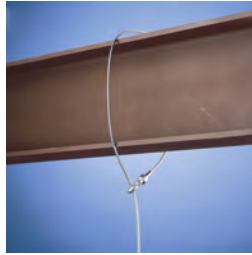

- Complete system includes wire, locking device and pre-assembled hook end fitting
- Hooks to a wide range of CADDY® fasteners
- Fastens to the building structure or hanging services by looping around and hooking to wire rope
- Easy to remove for applications requiring maintenance
- Spring latch helps provide secure connection
- Insert cable through hole and use bottom side of hook as an end stop
- Also available in Y-hook configuration

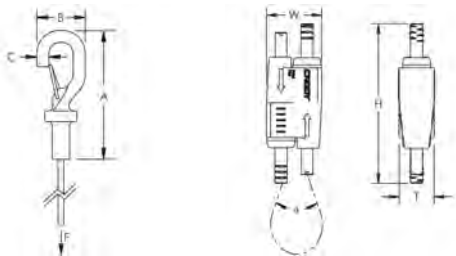

Part Number	SLK15L3
Article Number	196510
Material	Steel Polypropylene Zinc alloy
Finish	Electro-galvanized
Static Load Safety Factor	5:1
Wire Rope Diameter	1.5 mm
Wire Rope Length	9.9' 3 m
A	2.3 " 58.4 mm
B	0.9 " 22.9 mm
C	1/4 " 6.4 mm
Static Load (F)	44 lb 195 N
Height (H)	2.15 " 55 mm
Width (W)	3/4 " 19 mm
Thickness (T)	1/2 " 12.5 mm
Angle (a)	90 ° Max
Standard Packaging Quantity	20 pc
UPC	78285680144



Part Number	SLK15L3
UNSPSC	31151705
EAN-13	8711893135183
ETIM	EC011590

WARNING

ERICO products shall be installed and used only as indicated in ERICO's product instruction sheets and training materials. Instruction sheets are available at www.erico.com and from your ERICO customer service representative. Improper installation, misuse, misapplication or other failure to completely follow ERICO's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death.

Copyright © 2013 ERICO International Corporation. All rights reserved.

CADDY, CADWELD, CRITEC, ERICO, ERIFLEX, ERITECH, and LENTON are registered trademarks of ERICO International Corporation.

