



CADDY® SPEED LINK SLK with Y-Hook – SLK2YH500L3 (196550)

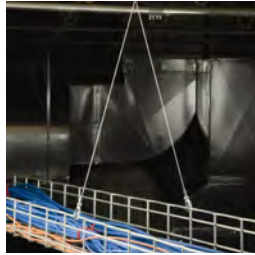

- Complete system includes wire, locking device and two pre-assembled hook end fittings
- Fastens to the building structure and hooks to hanging services and tray
- Spring latch helps provide secure connection
- Convenient design allows one hook to be temporarily detached for maintenance or to add cables to the tray
- Single drop with double hook provides increased stability to the system
- Also available in a single-hook end fitting configuration

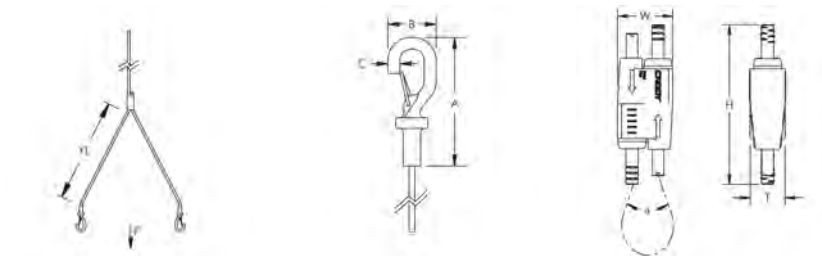

Part Number	SLK2YH500L3
Article Number	196550
Material	Steel Zinc alloy Polypropylene
Finish	Electro-galvanized
Static Load Safety Factor	5:1
Wire Rope Diameter	2 mm
Wire Rope Length	9.9' 3 m
Wire Rope "Y" Length (YL)	19.6" 500 mm
A	2.3" 58.4 mm
B	0.9" 22.9 mm
C	1/4" 6.4 mm
Static Load (F)	100 lb 440 N
Height (H)	2.15" 55 mm
Width (W)	3/4" 19 mm
Thickness (T)	1/2" 12.5 mm
Angle (a)	90 ° Max
Standard Packaging Quantity	10 pc



Part Number	SLK2YH500L3
UPC	78285680174
UNSPSC	31151705
EAN-13	8711893134803
ETIM	EC011590

WARNING

ERICO products shall be installed and used only as indicated in ERICO's product instruction sheets and training materials. Instruction sheets are available at www.erico.com and from your ERICO customer service representative. Improper installation, misuse, misapplication or other failure to completely follow ERICO's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death.

Copyright © 2013 ERICO International Corporation. All rights reserved.

CADDY, CADWELD, CRITEC, ERICO, ERIFLEX, ERITECH, and LENTON are registered trademarks of ERICO International Corporation.

