



ONE HOLE HYLUG™ CODE CONDUCTOR STANDARD BARREL NARROW TONGUE

TYPE YA-L-NT

COPPER COMPRESSION NARROW TONGUE TERMINAL

UL Listed 90° C,
600 Volts to 35 kV ◆

45° and 90° angles are available.
Please contact Customer Service to order:
1-800-346-4175

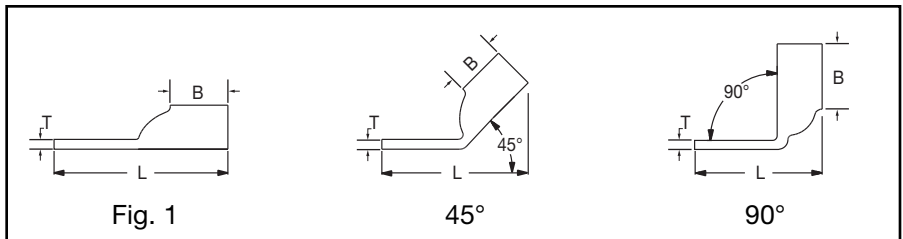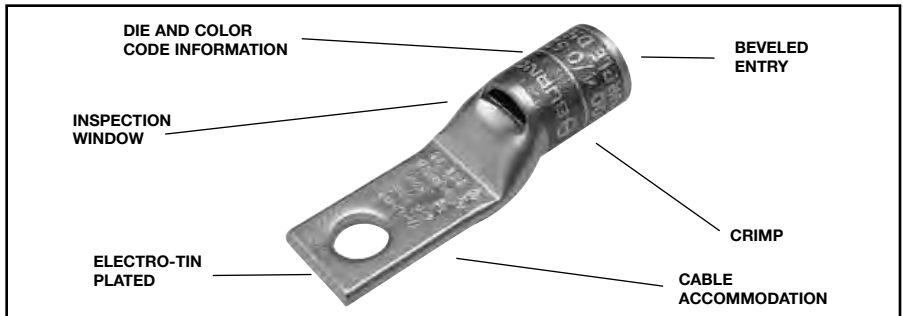

Catalog Number	Fig #	Conductor		Stud Hole Size	Tongue Width	Figure Dimensions			**** Dieless (# of crimps)	▲ Installation Tooling					Wire Strip Length
		AWG	*** MM²			(B)	(T)	(L)		Mechanical MD6, OUR840, MD7-34R	Hydraulic BCT500HS, Y500CTHS		Y35, Y39, Y750, Y46*, PAT750	Color Code	
YA8CLNT6	1	#8 AWG	10	6	.29"	.44"	.09"	1.08"	Y8MRB-1 (1) MY29-3 (1) MY29-11 (1) MRC840 (1) Y81KFT (1) Y81KFTMBH (1) PAT81KFT-18V (1)	W8CVT (1)	X8CRT (1)	U8CRT (1)	Red	49	1/2"
YA8CLNT8	1			8	.33"	.44"	.09"	1.18"							
YA6CLNT6	1	#6 AWG	—	6	.29"	.54"	.09"	1.17"	Y1MRTC (1)	W5CVT (1)	X5CRT (1)	U5CRT (1)	Blue	7	7/8"
YA4CLNT10	1	#4 AWG	—	# 10	.40"	.81"	.09"	1.73"	MY29-3 (1)	W4CVT (1)	X4CRT (1)	U4CRT (1)	Gray	8	7/8"
YA3CLNT14	1	#3 AWG	25	1/4"	.41"	.88"	.09"	1.82"	MY29-11 (1)	W3CVT (1)	W3CVT (1)	U3CRT (1)	White	9	15/16"
YA3CLNT516	1	#2 Sol.		5/16"	.49"	.88"	.09"	1.80"	MRC840						
YA2CLNT10	1	#2 AWG	35	# 10	.48"	.88"	.11"	1.80"	Y644HS (1)	W2CVT (1)	X2CRT (1)	U2CRT (1)	Brown	10	15/16"
YA2CLNT14	1			1/4"	.50"	.88"	.11"	1.80"	Y81KFT (1)						
YA2CLNT516	1			5/16"	.49"	.88"	.11"	1.82"	Y81KFTMBH (1) PAT81KFT-18V (1)						
YA1CLNT10	1	#1 AWG	50	# 10	.50"	.88"	.10"	2.23"	MY29-3 (1) MY29-11 (1) MRC840 Y644HS (1) Y81KFT (1) Y81KFTMBH (1) PAT81KFT-18V (1)	W1CVT (1)	X1CRT (1)	U1CRT (1)	Green	11	15/16"
YA1CLNT14	1			1/4"	.50"	.88"	.10"	2.23"							
YA25LNT10	1	1/0 AWG	—	# 10	.62"	.88"	.12"	2.28"	W25VT (2)	X25RT (2)	U25RT (1)	Pink	12	15/16"	
YA25LNT14	1			1/4"	.48"	.88"	.12"	1.93"							
YA25LNT516	1			5/16"	.62"	.88"	.12"	2.28"							
YA25LNT38	1	2/0 AWG	70	3/8"	.62"	.88"	.12"	2.18"	W26VT (2)	X26RT (2)	U26RT (1)	Black	13	1"	
YA26LNT10	1			# 10	.62"	.94"	.13"	2.62"							
YA26LNT14	1			1/4"	.48"	.94"	.13"	2.02"							
YA26LNT516	1			5/16"	.62"	.94"	.13"	2.62"							
YA26LNT38	1			3/8"	.72"	.94"	.12"	2.48"							

* Use PUADP-1 adapter with U dies in Y46 HYPRESS™.

** The MM² conductor size listed is for Class 2 and Class 5 conductor.

*** The MM² conductor sizes listed are the recommendations for Class 2 conductor.

**** Y644M is not recommended for standard barrel length #6 AWG HYLUG™.

▲ See tooling section of this catalog for complete tool and die listings. Use ONLY color-coded die recommendations for -FX connectors. For nest/indenter system contact factory.

◆ For applications greater than 2000 Volts consult cable manufacturer for voltage stress relief instructions.

Note: All dimensions shown are for reference only.

Blue highlighted items are industry standard and most frequently ordered.