



TWO HOLE HYLUG™ FLEX CONDUCTOR STANDARD BARREL NARROW TONGUE

TYPE YAV-L-NTFX

COPPER COMPRESSION
NARROW TONGUE TERMINAL

UL Listed 90° C
600 Volts to 35 kV ◆

45° and 90° angles are available.
Please contact Customer Service to order:
1-800-346-4175

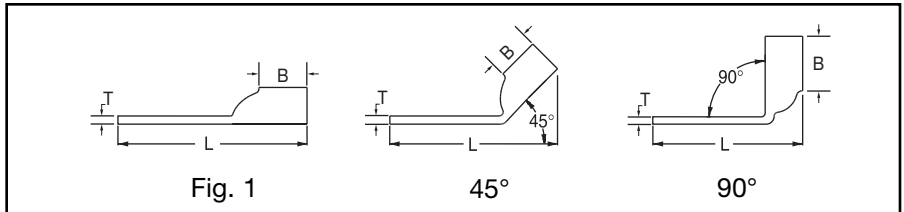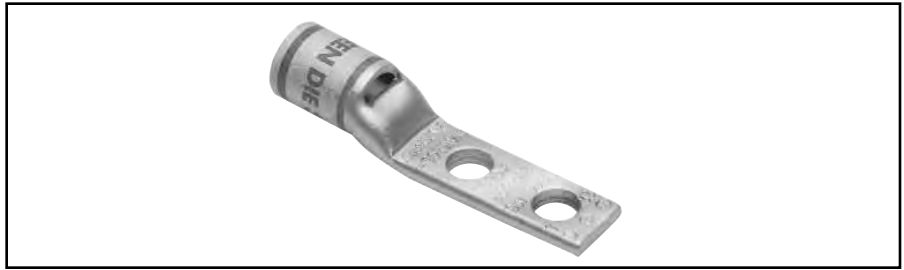

Catalog Number	Fig #	Conductor		Stud Hole Size	Stud Hole Spacing	Tongue Width	Figure Dimensions			▲ Installation Tooling							Wire Strip Length
		AWG	*** MM²							Dieless (# of crimps)	Mechanical	Hydraulic		Color Code	Die Index		
											MD6, OUR840, MD7-34R	BCT500HS, Y500CTHS	Y35, Y39, Y750, Y46*, PAT750				
YAV4CL2NT10E1FX	1	#4 AWG	—	#10	1.00"	0.41"	0.50"	0.09"	2.33"	MY29-11 (1) Y1MRTC (2) Y81KFT (1) Y81KFTMBH (1) PAT81KFT-18V (1)	W4CVT (1) W4CRT (1) X4CRT (1)	W4CVT (1) W4CRT (1) X4CRT (1)	U4CRT (1)	Gray	8	9/16"	
YAV4CL2NT10FX	1	#4 Weld 91/24		1/4"	0.63"	0.41"	0.50"	0.09"	1.95"								
YAV4CL2NT14FX	1	105/24			0.63"	0.45"	0.50"	0.09"	2.08"								
YAV2CL2NT10FX	1	#2 AWG	35	#10	0.63"	0.48"	0.63"	0.10"	2.14"	MY29-11 (1) Y1MRTC (2) Y81KFT (1) Y81KFTMBH (1) PAT81KFT-18V (1)	W2CVT (1) W2CRT (1) X2CRT (1)	W2CVT (1) W2CRT (1) X2CRT (1)	U2CRT (1)	Brown	10	11/16"	
YAV2CL2NT14E1FX	1	#2 Weld 125/24		1/4"	1.00"	0.48"	0.63"	0.10"	2.63"								
YAV2CL2NT14FX	1	150/24			0.63"	0.48"	0.63"	0.10"	2.26"								
YAV1CL2NT14FX	1	#1 AWG	—	1/4"	0.63"	0.50"	0.62"	0.12"	2.28"	MY29-11 (1) Y81KFT (1) Y81KFTMBH (1) PAT81KFT-18V (1)	W1CVT (1) W1CRT-1 (1) X1CRT-1 (1)	W1CVT (1) W1CRT-1 (1) X1CRT-1 (1)	U1CRT-1 (1)	Green	11	11/16"	
YAV1CL2NT516FX	1	#1 Weld 175/24 225/24		5/16"	1.00"	0.58"	0.63"	0.12"	2.72"								
YAV25L2NT14E1FX	1	1/0 AWG	50	1/4"	1.00"	0.64"	0.69"	0.12"	2.76"	MY29-11 (1) Y81KFT (1) Y81KFTMBH (1) PAT81KFT-18V (1)	W25VT (2) W25RT (2) X25RT (2)	W25VT (2) W25RT (2) X25RT (2)	U25RT (1)	Pink	12	11/16"	
YAV25L2NT14FX	1	1/0 Weld 275/24		1/4"	0.63"	0.64"	0.69"	0.12"	2.39"								
YAV25L2NT516FX	1			5/16"	1.00"	0.58"	0.69"	0.12"	2.82"								
YAV26L2NT14FX	1	2/0 AWG	70	1/4"	0.63"	0.76"	0.81"	0.13"	2.56"	MY29-11 (1) Y644HS (1) Y81KFT (1) Y81KFTMBH (1) PAT81KFT-18V (1)	W26VT (2) W26RT (2) X26RT (2)	W26VT (2) W26RT (2) X26RT (2)	U26RT (1)	Black	13	13/16"	
YAV26L2NT516FX	1	2/0 Weld 325/24		5/16"	1.00"	0.58"	0.81"	0.13"	2.99"								
YAV26L2NT38FX	1			3/8"	1.00"	0.63"	0.81"	0.13"	3.23"								
YAV28L2ENT14FX	1	4/0 AWG	—	1/4"	0.63"	0.76"	1.03"	0.15"	2.86"	MY29-11 (1) Y644HS (1) Y81KFT (1) Y81KFTMBH (1) PAT81KFT-18V (1)	W28VT (2) W28RT (2) X28RT (3)	W28VT (2) W28RT (2) X28RT (3)	U28RT (1)	Purple	15	1-1/16"	
YAV28L2NT38FX	1	4/0 Weld 550/24		3/8"	1.00"	0.94"	1.03"	0.15"	3.43"								

Consult cable manufacturers for stress relief instructions.
◆ For applications greater than 2000 Volts consult cable manufacturer for voltage stress relief instructions.

* Use PUADP-1 adaptor with U -dies in Y46 HYPRESS™.
▲ See tooling section of this catalog for complete tool and die listings. Use ONLY color-coded die recommendations for -FX connectors.

Note: All dimensions shown are for reference only.

Blue highlighted items are industry standard and most frequently ordered.