

TYPE GC-A

DUAL RATED
GROUND CLAMP

For Copper and
Aluminum Cable


GC-A ground clamps are UL Listed for use with either copper or aluminum conductors to copper water pipe, galvanized pipe or steel conduit. All clamps are constructed from tin plated high-strength extruded aluminum alloy. PENETROX™ oxide inhibiting joint compounds are recommended for all aluminum applications.



E-41

Features and Benefits

- Clamps are dual rated for both copper and aluminum conductors.
 - ◇ Maximum flexibility of application.
- All connectors are tin plated.
 - ◇ Provide low contact resistance and prevents galvanic corrosion.
- All clamps are range taking.
 - ◇ Only 3 catalog numbers covers complete range of applications from 1/2 - 4 inches.

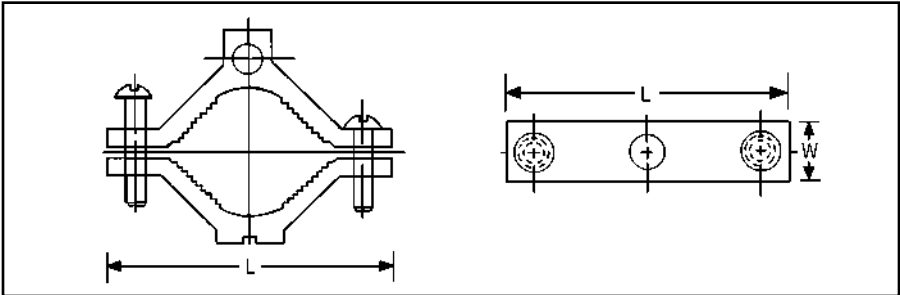

Catalog Number	Conduit, Pipe, or Water Tube Size	Wire Range	Screw Type	W	L	Hex Size
GC15A	1/2 - 3/4 - 1	1/0 - 14	Slotted	11/16	2-1/4	S
GC18A	1-1/4 - 1-1/2 - 2	250 kcmil - 6	Hex Socket	13/16	3-3/4	5/16
GC22A	2-1/2 - 3 - 3-1/2 - 4	250 kcmil - 6	Hex Socket	1	6-5/16	5/16

Blue highlighted items are industry standard and most frequently ordered.