


TYPES YAE-G AND YAE-N

(Continued)

INSULUG™

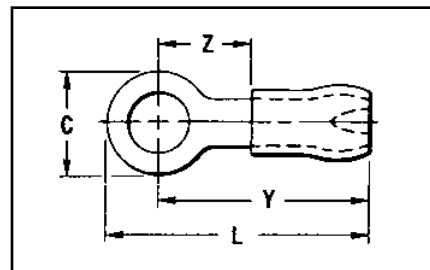

Catalog Number	Wire Range	Stud Size	**SAE-AS25036	Dimensions				Bulk Catalog Number	Installation Tooling	Tape Mounted Catalog Number 2000/Reel	Installation Tooling	Wire Strip Length
				C	L Max.	Y Max.	Z Min.					
YAE18N29 BOX	22-16 † Max. Insul. Dia. Accom.: .125 Color Code: Red	1-2	—	.14	.75	.68	.19	YAE18N29	MR8-1A, MR8-33T-1 (no extra dies required) M8ND with one of following dies: N14HET-25V1 N10ET-9 N14HET-15 N10ET-23 or Y10D Y10-22	YAE18N29M	TFM with DFM10D1 die	3/16"
YAE18N27 BOX		2	—	.19	.77	.66	.19	YAE18N27		YAE18N27M		
—		4	—	.25	.80	.68	.19	YAE18-N7		YAE18-N7M		
—		4	-148	.25	.80	.68	.19	YAE18N17		—		
—		4	—	.23	.78	.68	.19	YAE18N26		YAE18N26M		
YAE18N21 BOX		4-6	-102	.25	.89	.77	.28	YAE18N21		YAE18N21M		
—		4-6	—	.22	.79	.68	.19	YAE18N25		YAE18N25M		
YAE18G43 BOX		4-6	-101	.25	.90	.68	.19	YAE18G43		YAE18G43M		
YAE18N24 BOX		6-8	—	.28	.92	.77	.28	YAE18N24		YAE18N24M		
YAE18N1 BOX		6-8	-149	.31	.92	.77	.28	YAE18N1		YAE18N1M		
YAE18N BOX		8-10	-103	.31	.92	.77	.28	YAE18N		YAE18NM		
—		12, 1/4	-150	.45	1.11	.88	.40	YAE18N2		YAE18N2M		
YAE18N3 BOX		5/16	-104	.45	1.11	.88	.40	YAE18N3		YAE18N3M		
YAE18N15 BOX		3/8	-105	.53	1.19	.93	.43	YAE18N15		YAE18N15M		
YAE14N43 BOX	16-14 Max. Insul. Dia. Accom.: .156 Color Code: Blue	4-6	-106	.25	.82	.69	.20	YAE14N43	Y10D Y10-22	YAE14N43M	TFM with DFM9D1 die	3/16"
YAE14N1 BOX		6-8	-153	.31	.92	.75	.28	YAE14N1		YAE14N1M		
YAE14N BOX		8-10	-108	.31	.92	.75	.28	YAE14N		YAE14NM		
YAE14N2 BOX		1/4	-154	.45	1.11	.88	.40	YAE14N2		YAE14N2M		
YAE14N3 BOX	14-12 Max. Insul. Dia. Accom.: .180 Color Code: Green	5/16	-109	.45	1.11	.88	.40	YAE14N3	MR8-1A, MR8-33T-1 (no extra dies required) Y10D, M8ND with die N12HET-1	YAE14N3M	TFM with DFM7D1 die	21/64"
YAE14N4 BOX		3/8	-110	.53	1.19	.93	.44	YAE14N4		YAE14N4M		
—		10	—	.31	1.06	.93	.29	YAE12N7		—		
YAE12N9 BOX		6-8	—	.31	1.06	.90	.28	YAE12N9		YAE12N9M		
YAE12N1 BOX	12-10 Max. Insul. Dia. Accom.: .209 Color Code: Yellow	6-8	—	.31	1.06	.90	.28	YAE12N1	MR8-33T-1 (no extra dies required) M8ND with one of the following dies: N10HET-15, N10ET-9, N10ET-23, Y10D, Y10-22	YAE12N1M	TFM with DFM7D1 die	3/8"
YAE12N BOX		8-10	—	.31	1.06	.90	.28	YAE12N		YAE12NM		
YAE12N2 BOX		1/4	—	.46	1.25	1.02	.40	YAE12N2		YAE12N2M		
YAE10N5 BOX		4-6	-111	.38	1.15	.96	.28	YAE10N5		* YAE10N5M		
YAE10N11 BOX	12-10 Max. Insul. Dia. Accom.: .209 Color Code: Yellow	6-8	-156	.38	1.17	.98	.30	YAE10N11	MR8-33T-1 (no extra dies required) M8ND with one of the following dies: N10HET-15, N10ET-9, N10ET-23, Y10D, Y10-22	* YAE10N11M	TFM with DFM7D1 die	3/8"
YAE10N BOX		8-10	-112	.38	1.15	.96	.28	YAE10N		* YAE10NM		
YAE10N3 BOX		1/4	-157	.54	1.39	1.12	.44	YAE10N3		* YAE10N3M		
YAE10N2		5/16	-113	.54	1.39	1.12	.44	YAE10N2		* YAE10N2M		
YAE10N4		3/8	-114	.54	1.39	1.12	.44	YAE10N4		* YAE10N4M		

* 1000/Reel

** Class 2

† Use Y10D or Y10-22 only when crimping #16 AWG.

Blue highlighted items are industry standard and most frequently ordered.