 
 



Switch fuses OS32G...160G_, NFC-types


Ordering information




OH_65J_

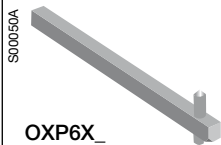


OSP6X_

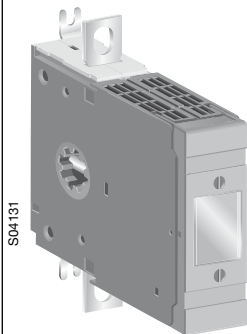

OSP_

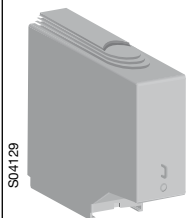

OSS_L

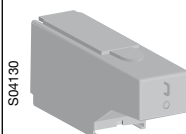

OSS_S

Optional handles, IP 65

For front operated switch fuses

Padlockable with 3 padlocks in the OFF-position, door interlock in the ON-position. Units/type = 1 pcs. Screw fixing from the back side of the handle, no screws on the front, ensures double protection.

Colour	Handle length [mm]	Type	Order number	Delivery batch [pcs]	Weight /unit [kg]
--------	--------------------	------	--------------	----------------------	-------------------

For shaft diameter 6 mm

Plastic handles, black and red-yellow: I-O/ON-OFF, grey: I-O.

Black	45	OHB45J6	1SCA022380R8770	100	0.12
Red-Yellow	45	OHY45J6	1SCA022380R8930	100	0.12
Black	65	OHB65J6	1SCA022380R9660	100	0.12
Red-Yellow	65	OHY65J6	1SCA022380R9820	100	0.12
Grey	65	OHG65J6	1SCA022380R9740	100	0.12

Plastic handles, black and red-yellow: Test/I-O/ON-OFF, grey: Test/I-O.

Black	45	OHB45J6T	1SCA109870R1001	100	0.12
Black	65	OHB65J6T	1SCA022399R8110	100	0.12
Red-Yellow	65	OHY65J6T	1SCA022456R9540	100	0.12
Grey	65	OHG65J6T	1SCA022456R9620	100	0.12

Extended shafts

Units/type = 1 piece

Shaft length [mm]	Front operated H / [mm]	Side operated H / [mm]	Type	Order number	Delivery batch [pcs]	Weight /unit [kg]
-------------------	-------------------------	------------------------	------	--------------	----------------------	-------------------

For OS 32...63²⁾, shaft diameter 6 mm

150	130...249	210...272	OSP6X150	1SCA022295R5600	10	0.05
161	141...260	221...283	OSP6X161 ³⁾	1SCA022067R1760	10	0.05
210	190...309	270...332	OSP6X210	1SCA022295R6080	10	0.06
290	270...389	350...412	OSP6X290	1SCA022042R6370	10	0.08
360	340...459	420...482	OSP6X360	1SCA022042R6530	10	0.1
430	410...529	490...552	OSP6X430	1SCA022056R6030	10	0.12
210	190...309	270...332	OSP6X210-45 ¹⁾	1SCA022294R4230	10	0.06
290	270...389	350...412	OSP6X290-45 ¹⁾	1SCA022304R4290	10	0.08

For OS 100...160²⁾, shaft diameter 6 mm

150	140...252	202.5...316	OSP6X150	1SCA022295R5600	10	0.05
161	140...263	202.5...327	OSP6X161 ³⁾	1SCA022067R1760	10	0.05
210	189...312	206...376	OSP6X210	1SCA022295R6080	10	0.06
290	269...392	286...456	OSP6X290	1SCA022042R6370	10	0.08
360	339...462	345...515	OSP6X360	1SCA022042R6530	10	0.1
430	409...532	415...585	OSP6X430	1SCA022056R6030	10	0.12
210	189...312	206...376	OSP6X210-45 ¹⁾	1SCA022294R4230	10	0.06
290	269...392	286...456	OSP6X290-45 ¹⁾	1SCA022304R4290	10	0.08

Fourth Poles

Snap-on mounting to the side of the switch.

Suitable for 3-pole switches	Mounting side	Type	Order number	Units/ type [pcs]	Weight [kg]
------------------------------	---------------	------	--------------	-------------------	-------------

Fusable 4. poles

OS125G_...160G_, DIN-type	Left/right	OSP160GD	1SCA114768R1001	1	0.40
OS125G_...160G_, BS-type	Left/right	OSP160GB	1SCA114769R1001	1	0.40

Switched 4. poles

OS100G_...160G_, N-type	Left/right	OSP160GN	1SCA114770R1001	1	0.40
-------------------------	------------	----------	-----------------	---	------

Terminal shrouds

Suitable for switches	Number of poles	Description	Type	Order number	Units/ type [pcs]	Weight [kg]
-----------------------	-----------------	-------------	------	--------------	-------------------	-------------

Pack of single pole terminal shrouds, snap-on mounting, grey plastic, IP 3X. Transparent shrouds available on request.

OS100G_...160G_	3	Long type	OSS160GG1L/3	1SCA114764R1001	3	0.10
OS100G_...160G_	3	Short type	OSS160GG1S/3	1SCA114766R1001	3	0.07
OS100G_...160G_	4	Long type	OSS160GG1L/4	1SCA114765R1001	4	0.12
OS100G_...160G_	4	Short type	OSS160GG1S/4	1SCA114767R1001	4	0.08

¹⁾ The shaft position is rotated 45 degrees

²⁾ Side operated, 4-pole: OS 32...63: add 45 mm, OS 100...160: add 35 mm

³⁾ Included as standard