

400A – 800A UL fuse class J, L

Disconnect
switches
Fusible

For a complete assembly,
please select one of each:

- 1 switch
- 1 handle
- 1 shaft
- 1 terminal lug kit



OS400J03



OXP12X280



OHB145J12




OZXA-400

400 – 800 Amp switches, 600V

UL general purpose amp rating	UL Fuse type 600V	Maximum horsepower rating Three phase			Catalog number	List price
		240V	480V	600V		
2 pole						
400	J	—	—	—	OS400J02	\$ 1680
600	J	—	—	—	OS600J02	2600
800	L	—	—	—	OES800L2	4280
3 pole						
400	J	125	250	350	OS400J03	1860
400	J	125	250	350	OS400J30	1860
600	J	200	400	500	OS600J03	2900
600	J	200	400	500	OS600J30	2900
800	L	250	500	600	OES800L3	4760
4 pole						
400	J	125	250	350	OS400J04F	2320
600	J	200	400	500	OS600J04F	3620
800	L	250	500	600	OES800L4	5950



OS400J03

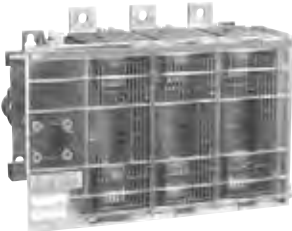

OES800L3



OHB_J12



OHY_J12



YASDA-33

Pistol handles – □ .47 x .47" (□ 12 x 12mm)

UL/NEMA type	IEC type	Color	Length inches/mm	Marking	Defeat-able	Padlock-able	Weight (lbs)	Catalog number	List price
1,3R,12	IP65	Black	4.9/125	O/I & Off/On	Yes	Yes	0.39	OHB125J12	\$ 90
		Red/Yel	4.9/125				0.39	OHY125J12	90
		Black	5.7/145				0.39	OHB145J12	90
		Red/Yel	5.7/145				0.39	OHY145J12	90
		Black	6.9/175				0.41	OHB175J12	100
		Red/Yel	6.9/175				0.41	OHY175J12	100
1,3R,4,4X,12	IP65	Black	5.7/145	O/I & Off/On	Yes	Yes	0.39	OHB145L12	130
		Red/Yel	5.7/145				0.39	OHY145L12	130
		Black	6.9/175				0.41	OHB175L12	140
		Red/Yel	6.9/175				0.41	OHY175L12	140
1,3R,4,4X,12	IP65	Metal	8.7/220	Off/On	—	Yes	1.50	YASDA-8	190
1,3R,4,4X,12	IP66	Stainless Steel	4.9/125	O/I & Off/On	Yes	Yes	1.70	OHM125L12	900
			6.9/175				1.80	OHM175L12	1100
			10.8/275				2.10	OHM275L12	1200

18

Direct mount handles

Item	Weight (lbs)	Catalog number	List price
Mounts to 12mm shaft	0.78	YASDA-33	\$ 155