

Other configurations


Side operated

30A – 800A^{①②}

Disconnect
switches
Non-fusible

For a complete assembly,
please select one of each:

- 1 switch
- 1 handle
- 1 shaft
- 1 terminal lug kit

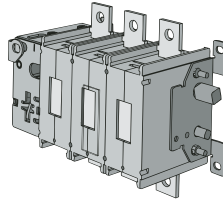

OETL-NF200A-S



OXP8X240




OHB80J8TE00S



OSNF30-S



OHY__J__

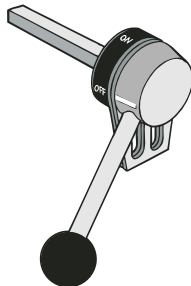

OETL-ZX74



OXP5X170
OXP8X240
OXP12X325



OZXA-24



OZXA-25



OZXA-26



OZXA-27

Side operated switches — 3 pole

UL general purpose amp rating	IEC AC21 amp rating	Maximum horsepower rating					Weight (lbs)	Catalog number	List Price
		Three phase							
		200V	208V	240V	480V	600V			
30	32	5	7.5	7.5	15	20	1.90	OSNF30-S	\$ 380
60	63	15	15	15	30	50	3.90	OSNF60-S	560
100	125	25	25	30	60	75	4.50	OSNF100-S	660
200	250	60	60	75	150	200	6.61	OETL-NF200A-S	780
400	630	100	100	125	250	350	13.66	OETL-NF400-S	1500
600	800	150	150	200	400	500	13.66	OETL-NF600A-S	2400

Handles

UL/NEMA type		Color	Length inches/mm	Marking	Defeat- able	Padlock- able	Weight (lbs)	Catalog number	List price
-----------------	--	-------	---------------------	---------	-----------------	------------------	-----------------	-------------------	---------------

For use with OSNF30-S

1, 12, 3R		Black	2.65/65	O/I & Off/On	Yes	Yes	0.29	OHB65J5	\$ 80
1, 12, 3R		Red/Yel	2.65/65	O/I & Off/On	Yes	Yes	0.29	OHY65J5	

For use with OSNF60-S — OSNF100-S

1, 12, 3R		Black	3.1/80	O/I & Off/On	Yes	Yes	0.30	OHB80J6	80
1, 12, 3R		Red/Yel	3.1/80	O/I & Off/On	Yes	Yes	0.30	OHY80J6	

For use with OETL-NF200A-S

1, 12, 3R		Black	3.1/80	O/I & Off/On	Yes	Yes	0.30	OHB80J8	80
1, 12, 3R		Red/Yel	3.1/80	O/I & Off/On	Yes	Yes	0.30	OHY80J8	

For use with OETL-400DM1 — OETL-NF600A-S

1, 12, 3R		Black	4.9/145	O/I & Off/On	Yes	Yes	0.39	OHB145J12	80
1, 12, 3R		Red/Yel	4.9/145	O/I & Off/On	Yes	Yes	0.39	OHY145J12	80
1, 12, 3R		Metal	4.9/145	Off/On	Yes	Yes	1.50	OETL-ZX74	190

Shafts

For use with:	Length inches/mm	Description	Weight (lbs)	Catalog number	List price
OSNF30-S	6.7/170	.20 x .20" (5 x 5mm)	0.08	OXP5X170	\$ 16
OSNF60-S — OSNF100-S	8.3/210	.24 x .24" (6 x 6mm)	0.10	OXP6X210	16
OETL-NF175-S — OETL-NF200A-S	9.5/240	.31 x .31" (8 x 8mm)	0.26	OXP8X240	24
OETL-NF400-S — OETL-NF600A-S	12.8/325	.47 x .47" (12 x 12mm)	0.90	OXP12X325	40

Terminal lug kits

For use on:	Wire size	Weight	Wire type	Lugs per kit	Catalog number	List price
OSNF30-S	#18 – 8	—	Cu	—	Integral	—
OSNF60-S	#14 – 4	—	Cu	—	Integral	—
OSNF100-S	#14 – 2/0	0.43	Cu/Al	6	OZXA-24	\$ 24
OETL-NF200A-S	#6 – 300 kcmil	0.93	Cu/Al	6	OZXA-25	80
OETL-NF400-S	#2 – 600 kcmil	3.520	Cu/Al	6	OZXA-26	190
OETL-NF600A-S	(2) #2 – 600 kcmil	4.62	Cu/Al	6	OZXA-27	380

① Side operated switches available through 800A as IEC rated.
② Please consult factory for additional information.