

DYMO®

Advanced Datacom

Advanced Labelling Tool with PC Connectivity

Rhino™ 6000



Get precision labelling results every time, in less time.

Unmatched labelling power and versatility with PC connection.

Bring the tough, portable DYMO® Rhino™ 6000 to any jobsite – it's packed with time-saving shortcuts for labelling any installation quickly and professionally.

Use RHINO CONNECT™ software to create labels on your computer, and download them to the label printer for even faster labelling on site. The DYMO® Rhino™ 6000 meets all ANSI and TIA/EIA-606-A industry labelling standards. Its exclusive, one-touch "Hot Keys" automatically format label text for electrical and patch panels, terminal and 110 blocks, wire and cable flags, horizontal and vertical wraps, and vertical and fixed length applications. The DYMO® Rhino™ 6000 also prints 6 barcode types, has 250+ pre-programmed industry symbols and terms, and much more. Works with 32- and 64-bit Windows® XP, Windows Vista® and Windows® 7.

Hard Case Kit (see back for details)



DYMO® | Rhino™ 6000 features:

- 1 **Connects to PC via USB cable.** Use RHINO CONNECT™ software to create labels on your PC and download them to the label printer for printing on site
- 2 **Meets all ANSI and TIA/EIA-606-A** industry labelling standards
- 3 **Exclusive, one-touch "Hot Keys"** provide shortcuts to size, shape and format label text for electrical and patch panels, terminal and 110 blocks, wire and cable flags, horizontal and vertical wraps, vertical and fixed-length applications including 5 line print capability
- 4 **Prints 6 different barcode types** including Code 39 and Code 128
- 5 **Powerful Serialization** – Built-in wizards for simple and advanced serialization
- 6 **Symbol library** with more than 250 pre-programmed industry symbols, terms, fractions and punctuation marks
- 7 **Last-label memory** and storage for up to 1000 of the labels you use most



Up to

**24
mm**



LABEL APPLICATIONS

LABEL COLOUR

All labels below for use with the Rhino™ 6000

6 mm

9 mm

12 mm

19 mm

24 mm

Labels that stick and stay stuck.

DYMO® Industrial labels are tough— jobsite tested and UL recognized. Labels won't smear or fade and are built with industrial-strength adhesives to resist moisture, UV light and extreme temperatures. Whether you are labelling to OSHA, ISO and ANSI colour standards or labelling in harsh conditions, DYMO® Industrial labels have you covered. DYMO® Industrial labels are designed to work exclusively with Rhino™ printers and to perform on a variety of surfaces.

[LEARN MORE: www.dymo.com/industrial](http://www.dymo.com/industrial)

VINYL

- UL Recognized Component to UL969
- RoHS compliant



Length 5.5 m



BLACK ON WHITE

–

18443
S0718580

18444
S0718600

18445
S0718620

1805430

BLACK ON YELLOW

–

18432
S0718450

18433
S0718470

1805431

BLACK ON ORANGE

–

18435
S0718490

18436
S0718500

1805427

BLACK ON GREY

–

1805413

1805419

1805425

WHITE ON RED

–

1805416

1805422

1805429

WHITE ON BLACK

–

1805437

1805435

1805436

1805432

WHITE ON GREEN

–

1805414

1805420

1805426

WHITE ON BLUE

–

1805243

1805417

1805423

WHITE ON PURPLE

–

1805415

1805421

1805428

WHITE ON BROWN

–

1805412

1805418


1805424

PERMANENT POLYESTER

- UL Recognized Component to UL969
- RoHS compliant



Length 5.5 m

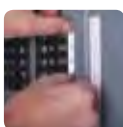

BLACK ON WHITE

1805442

18482
S0718240

18483
S0718210

18484
S0718220

1734523
S0773830

BLACK ON CLEAR

1805440

18508DMO
S0718160

622289

622290

1805433

BLACK ON METALLIC

1805441

18485
S0718170

18486
S0718180

18487
S0718200


1805434

HEAT SHRINK TUBES

- UL Recognized Component to UL224
- Meets MIL-STD-202G, MIL-M-81531 & SAE-DTL 23053/5 (Class 1 & 3)
- RoHS compliant



Length 1.5 m

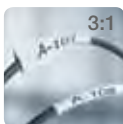

BLACK ON WHITE

18051
S0718260

18053
S0718280

18055
S0718300

18057
S0718330

1805443

BLACK ON YELLOW

18052
S0718270

18054
S0718290

18056
S0718310

18058
S0718340


1805444

FLEXIBLE NYLON

- UL Recognized Component to UL969
- RoHS compliant



Length 3.5 m

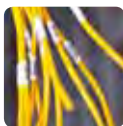

BLACK ON WHITE

–

18488
S0718100

18489
S0718120

1734524
S0773840

BLACK ON YELLOW

–

18490
S0718080


18491
S0718090

1734525
S0773850

NON-ADHESIVE TAG

- RoHS compliant

Length 5.5 m

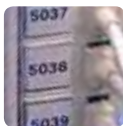

BLACK ON WHITE

18111
S0718350

–

18113
S0718380

–

–

SELF-LAMINATING

- RoHS compliant

Length 5.5 m



BLACK ON WHITE

–

–

–

–

1734821
S0773860

Rhino™ 6000 SINGLE UNIT (BOXED)

Code: S0773780

Box includes:

- Rhino™ 6000 printer
- 24 mm white flexible nylon tape
- Rechargeable lithium-ion battery pack
- AC adapter
- Quick reference guide
- Registration card

Product specifications:

- Runs on included lithium-ion rechargeable battery pack with AC adapter or optional 6 AA batteries
- 1 year warranty + 1 year extra warranty when registering
- Unit weight: 1820 gr

Optional accessories:

- RHINO CONNECT™ Software
- AC adapter
- Rechargeable lithium-ion battery pack

Code: S0721430

Code: S0899390

Rhino™ 6000 HARD CASE KIT

Code: S0771940

Hard Case Kit includes:

- Rhino™ 6000 printer
- RHINO CONNECT™ Software
- Durable hard carry case
- 24 mm white flexible nylon tape
- 9 mm white vinyl tape
- Rechargeable lithium-ion battery pack
- AC adapter
- USB cable
- Quick reference guide
- Registration card

Product specifications:

- Runs on included lithium-ion rechargeable battery pack with AC adapter or optional 6 AA batteries
- 1 year warranty + 1 year extra when registering
- Unit weight: 2260 gr

For more information or to find out your nearest distributor, please visit www.dymo.com/industrial or call us at +44 (0) 20 7341 5529.



©2011 DYMO®
DYMO bvba, Industriepark-Noord 30
B9100 Sint-Niklaas, Belgium
www.dymo.com/industrial

S0967290