
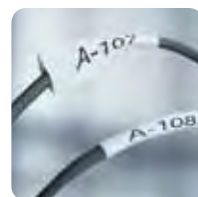


**DYMO**<sup>®</sup>

# DYMO<sup>®</sup> Industrial Labels

Label it fast, label it once, label it right.

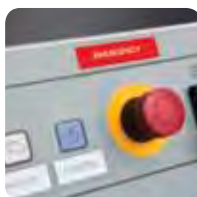

# Tough, jobsite-tested labels for industrial applications.

Labels

## Rely on DYMO® Industrial Labels.

DYMO® Industrial labels are tough – jobsite tested and UL recognized.

Thermal transfer printing means labels won't smudge, smear or fade.

Choose up to a 24 mm label width in a broad assortment of materials and colours that meet OSHA, ANSI, and ISO standards.

All DYMO® Industrial labels are distributed from an easy-to-load cartridge, and with a split-back design, peeling and applying is quick and easy.

DYMO® Industrial labels help you get labelling jobs done fast, and done right – the first time.



### DYMO® Industrial Labels are available in:


Flexible Nylon  
Permanent Polyester  
Indoor/Outdoor Vinyl  
Heat-Shrink Tube  
Non-Adhesive Tag  
Self-Laminating



## DYMO® Industrial Label Benefits:

- 1 Industrial-strength adhesives resist moisture, extreme temperatures, UV light and more – so labels won't curl or fall off
- 2 Available in a range of UL recognized materials for virtually every industrial labelling application; heat-shrink tubes tested to SAE, ASTM and military specifications
- 3 Thermal transfer printing technology – label text won't smudge, smear, or fade
- 4 Choose from 6, 9, 12, 19, and 24 mm label widths in a broad colour assortment that meet OSHA, ANSI, and ISO standards
- 5 Easy-to-peel split back design makes applying labels quick and easy

# The right label for virtually every situation and surface.

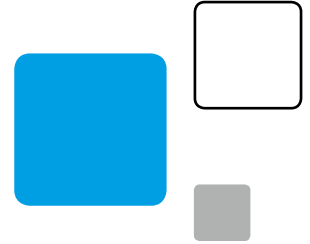

## Indoor/Outdoor Vinyl

For general labelling or extreme conditions. Vinyl labels offer moisture, chemical and UV resistance, making them ideal for labelling both indoors and outdoors. Available in the widest range of colours that adhere to OSHA, ANSI and ISO colour standards.

UL recognized as a component to UL 969

## Flexible Nylon

For labelling wires, cables and rounded surfaces. Flexible Nylon labels conform and stick tightly to wires, cables, curved and textured surfaces. Tear-proof material resists damage when pulled through tight spaces or conduits.

UL recognized as a component to UL 969

## Permanent Polyester

For labelling panels, blocks, faceplates, shelves, bins, beams and more. Permanent Polyester labels have a polished finish that leaves your work looking professional. Available in smaller widths that fit most patch panels, blocks and other distribution panels.

UL recognized as a component to UL 969

## Heat-Shrink Tube

For high-end cable identification. A 3:1 shrink ratio helps ensure a secure fit on wires and cables. Print directly on Heat-Shrink Tubes with any DYMO® Industrial labelling tool.

Meets MIL-M-81531, MIL-STD-202G, SAE-DTL- 23053/5 (Class 1 & 3)  
UL recognized as a component to UL 224

## Non-Adhesive Tag

For sliding into racks or faceplates that do not require adhesive. Made from polyester for increased durability.











## Self-Laminating

Self-Laminating labels protect your printed area from exposure to oil, solvents, water and abrasion when applied to wires and cables.

All DYMO® Industrial labels are RoHS compliant.

 
For technical specifications on all DYMO® Industrial label types, please visit our website at:  
[www.dymo.com/industrial](http://www.dymo.com/industrial)

## How to choose the right DYMO® Industrial label:

| ENVIRONMENT                                                                                          |  Heat/Cold Resistant |  UV Light Resistant |  Oil Resistant |  Water Resistant |  Chemical Resistant |  Colour Coding |
|------------------------------------------------------------------------------------------------------|---------------------------------------------------------------------------------------------------------|--------------------------------------------------------------------------------------------------------|---------------------------------------------------------------------------------------------------|------------------------------------------------------------------------------------------------------|----------------------------------------------------------------------------------------------------------|-----------------------------------------------------------------------------------------------------|
| SURFACE                                                                                              |                                                                                                         |                                                                                                        |                                                                                                   |                                                                                                      |                                                                                                          |                                                                                                     |
|  Cable/Wire       | Flexible Nylon<br>Heat-Shrink Tube                                                                      | Indoor/Outdoor Vinyl<br>Heat-Shrink Tube                                                               | Indoor/Outdoor Vinyl<br>Heat-Shrink Tube                                                          | Indoor/Outdoor Vinyl<br>Heat-Shrink Tube                                                             | Indoor/Outdoor Vinyl<br>Heat-Shrink Tube                                                                 | Indoor/Outdoor Vinyl                                                                                |
|  Curved Surface   | Flexible Nylon<br>Indoor/Outdoor Vinyl                                                                  | Indoor/Outdoor Vinyl<br>Flexible Nylon                                                                 | Indoor/Outdoor Vinyl                                                                              | Indoor/Outdoor Vinyl<br>Flexible Nylon                                                               | Indoor/Outdoor Vinyl                                                                                     | Indoor/Outdoor Vinyl                                                                                |
|  Flat Surface     | Permanent Polyester<br>Flexible Nylon                                                                   | Permanent Polyester<br>Indoor/Outdoor Vinyl                                                            | Permanent Polyester<br>Indoor/Outdoor Vinyl                                                       | Permanent Polyester<br>Indoor/Outdoor Vinyl                                                          | Permanent Polyester<br>Indoor/Outdoor Vinyl                                                              | Indoor/Outdoor Vinyl                                                                                |
|  Textured Surface | Permanent Polyester<br>Flexible Nylon                                                                   | Indoor/Outdoor Vinyl<br>Permanent Polyester                                                            | Indoor/Outdoor Vinyl<br>Permanent Polyester                                                       | Indoor/Outdoor Vinyl<br>Permanent Polyester                                                          | Indoor/Outdoor Vinyl<br>Permanent Polyester                                                              | Indoor/Outdoor Vinyl                                                                                |

Top = Best Option Bottom = Alternate Option

# Available DYMO® Industrial label widths and colours:



| IND                                                                                                                                                                                                                                                                                                                                                                                                                                                                                                                                                                                                             | LABEL APPLICATIONS | LABEL COLOUR      | Width                    |                             |                          |                          |                            |
|-----------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------|--------------------|-------------------|--------------------------|-----------------------------|--------------------------|--------------------------|----------------------------|
|                                                                                                                                                                                                                                                                                                                                                                                                                                                                                                                                                                                                                 |                    |                   | 6 mm                     | 9 mm                        | 12 mm                    | 19 mm                    | 24 mm                      |
| <b>Labels that stick and stay stuck.</b><br>DYMO® Industrial labels are tough— jobsite tested and UL recognized. Labels won't smear or fade and are built with industrial-strength adhesives to resist moisture, UV light and extreme temperatures. Whether you are labelling to OSHA, ISO and ANSI colour standards or labelling in harsh conditions, DYMO® Industrial labels have you covered. DYMO® Industrial labels are designed to work exclusively with Rhino™ printers and to perform on a variety of surfaces.<br><br><a href="http://www.dymo.com/industrial">LEARN MORE: www.dymo.com/industrial</a> |                    | BLACK ON WHITE    | –                        | 18443<br><i>S0718580</i>    | 18444<br><i>S0718600</i> | 18445<br><i>S0718620</i> | 1805430                    |
|                                                                                                                                                                                                                                                                                                                                                                                                                                                                                                                                                                                                                 |                    | BLACK ON YELLOW   | –                        | –                           | 18432<br><i>S0718450</i> | 18433<br><i>S0718470</i> | 1805431                    |
|                                                                                                                                                                                                                                                                                                                                                                                                                                                                                                                                                                                                                 |                    | BLACK ON ORANGE   | –                        | –                           | 18435<br><i>S0718490</i> | 18436<br><i>S0718500</i> | 1805427                    |
|                                                                                                                                                                                                                                                                                                                                                                                                                                                                                                                                                                                                                 |                    | BLACK ON GREY     | –                        | –                           | 1805413                  | 1805419                  | 1805425                    |
|                                                                                                                                                                                                                                                                                                                                                                                                                                                                                                                                                                                                                 |                    | WHITE ON RED      | –                        | –                           | 1805416                  | 1805422                  | 1805429                    |
|                                                                                                                                                                                                                                                                                                                                                                                                                                                                                                                                                                                                                 |                    | WHITE ON BLACK    | –                        | 1805437                     | 1805435                  | 1805436                  | 1805432                    |
|                                                                                                                                                                                                                                                                                                                                                                                                                                                                                                                                                                                                                 |                    | WHITE ON GREEN    | –                        | –                           | 1805414                  | 1805420                  | 1805426                    |
|                                                                                                                                                                                                                                                                                                                                                                                                                                                                                                                                                                                                                 |                    | WHITE ON BLUE     | –                        | –                           | 1805243                  | 1805417                  | 1805423                    |
| <b>VINYL</b><br>Length 5.5 m<br>- UL Recognized Component to UL969<br>- RoHS compliant<br>                                                                                                                                                                                                                                                                                                                                                                                                                                                                                                                      |                    | WHITE ON PURPLE   | –                        | –                           | 1805415                  | 1805421                  | 1805428                    |
|                                                                                                                                                                                                                                                                                                                                                                                                                                                                                                                                                                                                                 |                    | WHITE ON BROWN    | –                        | –                           | 1805412                  | 1805418                  | 1805424                    |
|                                                                                                                                                                                                                                                                                                                                                                                                                                                                                                                                                                                                                 |                    | BLACK ON WHITE    | 1805442                  | 18482<br><i>S0718240</i>    | 18483<br><i>S0718210</i> | 18484<br><i>S0718220</i> | 1734523<br><i>S0773830</i> |
| <b>PERMANENT POLYESTER</b><br>Length 5.5 m<br>- UL Recognized Component to UL969<br>- RoHS compliant<br>                                                                                                                                                                                                                                                                                                                                                                                                                                                                                                        |                    | BLACK ON CLEAR    | 1805440                  | 18508DMO<br><i>S0718160</i> | 622289                   | 622290                   | 1805433                    |
|                                                                                                                                                                                                                                                                                                                                                                                                                                                                                                                                                                                                                 |                    | BLACK ON METALLIC | 1805441                  | 18485<br><i>S0718170</i>    | 18486<br><i>S0718180</i> | 18487<br><i>S0718200</i> | 1805434                    |
|                                                                                                                                                                                                                                                                                                                                                                                                                                                                                                                                                                                                                 |                    | BLACK ON WHITE    | 18051<br><i>S0718260</i> | 18053<br><i>S0718280</i>    | 18055<br><i>S0718300</i> | 18057<br><i>S0718330</i> | 1805443                    |
| <b>HEAT SHRINK TUBES</b><br>Length 1.5 m<br>- UL Recognized Component to UL224<br>- Meets MIL-STD-202G, MIL-M-81531 & SAE-DTL 23053/5 (Class 1 & 3)<br>- RoHS compliant<br>                                                                                                                                                                                                                                                                                                                                                                                                                                     |                    | BLACK ON YELLOW   | 18052<br><i>S0718270</i> | 18054<br><i>S0718290</i>    | 18056<br><i>S0718310</i> | 18058<br><i>S0718340</i> | 1805444                    |
|                                                                                                                                                                                                                                                                                                                                                                                                                                                                                                                                                                                                                 |                    | BLACK ON WHITE    | –                        | –                           | 18488<br><i>S0718100</i> | 18489<br><i>S0718120</i> | 1734524<br><i>S0773840</i> |
| <b>FLEXIBLE NYLON</b><br>Length 3.5 m<br>- UL Recognized Component to UL969<br>- RoHS compliant<br>                                                                                                                                                                                                                                                                                                                                                                                                                                                                                                             |                    | BLACK ON YELLOW   | –                        | –                           | 18490<br><i>S0718080</i> | 18491<br><i>S0718090</i> | 1734525<br><i>S0773850</i> |
|                                                                                                                                                                                                                                                                                                                                                                                                                                                                                                                                                                                                                 |                    | BLACK ON WHITE    | 18111<br><i>S0718350</i> | –                           | 18113<br><i>S0718380</i> | –                        | –                          |
| <b>NON-ADHESIVE TAG</b><br>Length 5.5 m<br>- RoHS compliant<br>                                                                                                                                                                                                                                                                                                                                                                                                                                                                                                                                                 |                    | BLACK ON WHITE    | –                        | –                           | –                        | –                        | –                          |
| <b>SELF-LAMINATING</b><br>Length 5.5 m<br>- RoHS compliant<br>                                                                                                                                                                                                                                                                                                                                                                                                                                                                                                                                                  |                    | BLACK ON WHITE    | –                        | –                           | –                        | –                        | 1734821<br><i>S0773860</i> |

For more information or to find out your nearest distributor, please visit [www.dymo.com/industrial](http://www.dymo.com/industrial) or call us at +44 (0) 20 7341 5529.



©2011 DYMO®  
 DYMO bvba, Industriepark-Noord 30  
 B9100 Sint-Niklaas, Belgium  
[www.dymo.com/industrial](http://www.dymo.com/industrial)