


## Security/Alarm/Access Control/Sound Low-voltage Cable Nonshielded Plenum

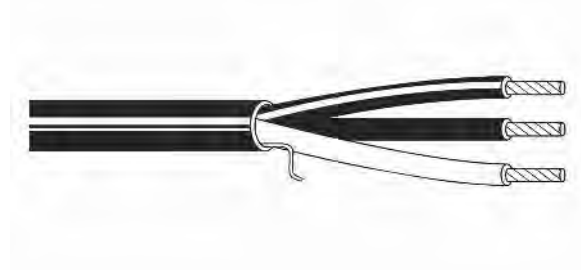

### Product Description

FRPVC

Bare copper conductor

UL Listed Type CMP, CL3P

### Applications

For use in security systems, intercom systems, sound/audio systems, access control, power-limited controls.

### Specifications

- CONDUCTOR: Bare copper, stranded or solid
- INSULATION: Flame-retardant polyvinyl chloride (FRPVC)
- OVERALL JACKET: Natural (white) flame-retardant polyvinyl chloride (FRPVC)
- STANDARDS: NEC: CMP (22-16 AWG), CL3P (14-12 AWG); NEC Article(s) 800, 725
- RATINGS: 75°C, 300 V

Electrical and Electronic Wire & Cable • Enterprise Cabling & Security Solutions • Fasteners

Anixter Inc. World Headquarters • 2301 Patriot Boulevard, Glenview, IL 60026-8020 • 1.800.ANIXTER • 224.521.8000 • [anixter.com](http://anixter.com)

Anixter is a leading global supplier of communications and security products, electrical and electronic wire and cable, fasteners and other small components. We help our customers specify solutions and make informed purchasing decisions around technology, applications and relevant standards. Throughout the world, we provide innovative supply chain management solutions to reduce our customers' total cost of production and implementation.

Anixter does not manufacture the items described in this publication. Any applicable product warranties are provided by the manufacturers. To the fullest extent permitted by law, Anixter disclaims all warranties, either express or implied.

The information provided and any images shown are for descriptive purposes only. Anixter makes no warranty or representation, express or implied, about the accuracy or completeness of any information provided. Data and suggestions made in the publication are not to be construed as recommendations to purchase or as authorizations to use any products in violation of any law or regulation. All products are sold subject to Anixter's General Conditions of Sale.

Standard color is white, other colors available. Most items available on spools or boxes except on larger O.D. products. Diameters and weights may vary among manufacturers. Paired conductors also available.

Part No.	Conductor Size AWG	No. of Conductors	Rating	Insulation	Insulation Thickness (in.)	Overall Jacket Thickness (in.)	Nom. O.D. (in.)	Approx. Wt. lb./1,000 ft.
AL-2202C-2-2N-01	22	2	CMP	FRPVC	0.007	0.015	0.110	11
AL-2202C-1-2N-01	22 (SOL)	2	CMP	FRPVC	0.007	0.015	0.103	11
AL-2203C-2-2N-01	22	3	CMP	FRPVC	0.007	0.015	0.117	14
AL-2204C-2-2N-01	22	4	CMP	FRPVC	0.007	0.015	0.127	17
AL-2204C-1-2N-01	22 (SOL)	4	CMP	FRPVC	0.007	0.015	0.119	17
AL-2206C-2-2N-01	22	6	CMP	FRPVC	0.007	0.015	0.168	22
AL-2208C-2-2N-01	22	8	CMP	FRPVC	0.007	0.015	0.183	30
AL-2210C-2-2N-01	22	10	CMP	FRPVC	0.007	0.015	0.110	42
AL-2212C-2-2N-01	22	12	CMP	FRPVC	0.007	0.015	0.110	44
AL-2002C-2-2N-01	20	2	CMP	FRPVC	0.008	0.015	0.124	13
AL-2003C-2-2N-01	20	3	CMP	FRPVC	0.008	0.015	0.127	17
AL-2004C-2-2N-01	20	4	CL3P	FRPVC	0.008	0.015	0.110	23
AL-1802C-2-2N-01	18	2	CMP	FRPVC	0.008	0.015	0.145	20
AL-1803C-2-2N-01	18	3	CMP	FRPVC	0.008	0.015	0.155	25
AL-1804C-2-2N-01	18	4	CMP	FRPVC	0.008	0.015	0.175	34
AL-1806C-2-2N-01	18	6	CMP	FRPVC	0.008	0.015	0.222	53
AL-1808C-2-2N-01	18	8	CMP	FRPVC	0.008	0.015	0.242	64
AL-1602C-2-2N-01	16	2	CMP	FRPVC	0.009	0.015	0.172	27
AL-1604C-2-2N-01	16	4	CMP	FRPVC	0.009	0.015	0.208	47
AL-1402C-2-2N-01	14	2	CL3P	FRPVC	0.010	0.017	0.222	40
AL-1404C-2-2N-01	14	4	CL3P	FRPVC	0.010	0.017	0.261	67
AL-1202C-2-2N-01	12	2	CL3P	FRPVC	0.011	0.017	0.256	61

### Electrical and Electronic Wire & Cable • Enterprise Cabling & Security Solutions • Fasteners

Anixter Inc. World Headquarters • 2301 Patriot Boulevard, Glenview, IL 60026-8020 • 1.800.ANIXTER • 224.521.8000 • [anixter.com](http://anixter.com)

Anixter is a leading global supplier of communications and security products, electrical and electronic wire and cable, fasteners and other small components. We help our customers specify solutions and make informed purchasing decisions around technology, applications and relevant standards. Throughout the world, we provide innovative supply chain management solutions to reduce our customers' total cost of production and implementation.

Anixter does not manufacture the items described in this publication. Any applicable product warranties are provided by the manufacturers. To the fullest extent permitted by law, Anixter disclaims all warranties, either express or implied.

The information provided and any images shown are for descriptive purposes only. Anixter makes no warranty or representation, express or implied, about the accuracy or completeness of any information provided. Data and suggestions made in the publication are not to be construed as recommendations to purchase or as authorizations to use any products in violation of any law or regulation. All products are sold subject to Anixter's General Conditions of Sale.