



CONTEG DATA SHEET

version: 01-09-2010

RUN SERIES 19" WALL MOUNT RACKS

CONTEG, spol. s r.o.

Headquarters Czech Republic:
Na Vítězné pláni 1719/4
140 00 Prague 4

Tel.: +420 261 219 182
Fax: +420 261 219 192
conteg@conteg.com
www.conteg.com

Local Offices:

Austria:	+43 699 1819 7071
Benelux:	+32 477 957 126
Eastern Europe:	+49 172 848 4346
France:	+33 686 074 386
Germany:	+49 170 523 4958
Russia:	+7 495 506 1328








The RUN series racks are installed on the wall. They offer an extended access level to the equipment installed; owing to removable and lockable side panels equipment can be accessed from the both the front and also from the side. Racks are designed for installing patch panels, active components, etc.

COLOR SAMPLER:

RAL 7035



RUN-09-60/40

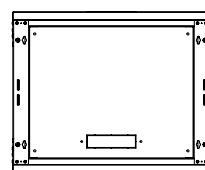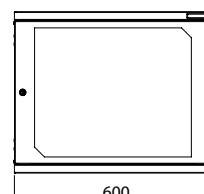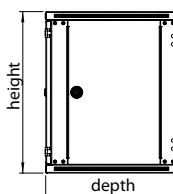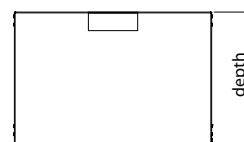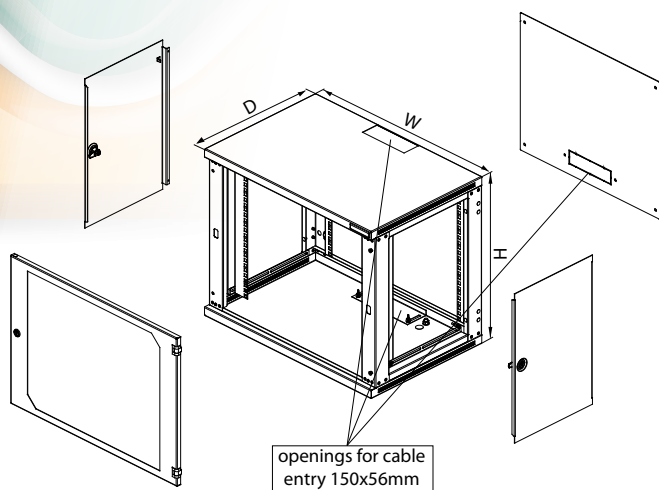

DESCRIPTION

Sizes

- Height: 4, 6, 9, 12, 15, 18U
- Width: 600mm
- Depth: 400, 500 or 600mm

Construction

- 1.25mm sheet steel

Load rating

- Standard 40kg (depth 400 and 500mm), standard 30kg (depth 600mm)

IP rating

- Standard IP30

Colors

- Standard RAL 7035
- Optionally other colors

Front door

- Tinted security glass (EN 12150-1) or sheet steel door
- Reversible door - easy to re-hang to open right or left

- Door opening angle 180°

Rear door

- Removable with module for cable entry
- When installed without the rear panel additional holes are exposed for installation of 19" components
- Mounting holes for wall installation on the back

Cable entries

- Top and bottom openings for cable entry, size 150x56mm
- Covered with sliding blank panel with butterfly nuts (DP-DB-200x68)
- Variable openings in relation to number of cables entering the rack
- Cable entries on rear edge of enclosure for straight cable path alongside the wall

Others

- Drilling template
- Possibility to add extra pair of extrusions (DP-LV-N-xx)

STANDARD CONFIGURATION:

- 1 pair of sliding 19" vertical extrusions
- 2 removable side panels with lock
- Tinted security glass door (EN 12150-1) with lock
- GND/earthing kit
- 16 mounting kits

LOAD RATING 30KG

Code	H in Units	Dimensions in mm				Dimensions including packing in mm			Gross weight in kg
		H	W	D	Useful depth	H	W	D	
RUN-06-60/60	6	358	603	600	580	378	620	630	20
RUN-09-60/60	9	491	603	600	580	510	620	630	26
RUN-12-60/60	12	624	603	600	580	645	620	630	29
RUN-15-60/60	15	758	603	600	580	778	620	630	33
RUN-18-60/60	18	891	603	600	580	910	620	630	39

LOAD RATING 40KG

Code	H in Units	Dimensions in mm				Dimensions including packing in mm			Gross weight in kg
		H	W	D	Useful depth	H	W	D	
RUN-04-60/40	4	267	600	400	380	290	620	430	14
RUN-06-60/40	6	358	600	400	380	378	620	430	16
RUN-09-60/40	9	491	600	400	380	510	620	430	20
RUN-12-60/40	12	624	600	400	380	645	620	430	23
RUN-15-60/40	15	758	600	400	380	778	620	430	27
RUN-18-60/40	18	891	600	400	380	910	620	430	33
RUN-04-60/50	4	267	600	500	480	290	620	530	16
RUN-06-60/50	6	358	600	500	480	378	620	530	18
RUN-09-60/50	9	491	600	500	480	510	620	530	23
RUN-12-60/50	12	624	600	500	480	645	620	530	26
RUN-15-60/50	15	758	600	500	480	778	620	530	30
RUN-18-60/50	18	891	600	500	480	910	620	530	36