

QuickPort® Single-Gang Wallplates (Field Configurable)

APPLICATION

Field-configurable wallplates accept QuickPort® snap-in modules to support multimedia applications with 1, 2, 3, 4 or 6 ports. Use where a one-piece, single-gang, economical flush-mount housing is desired. Six color choices, with color-matched screws.



SPECIFICATION

The wallplate housing shall be a one-piece, single-gang flush mount style that fits standard NEMA openings, or four-square boxes with reducer. It should provide 1-, 2-, 3-, 4- or 6-ports. Must be able to accept all Leviton QuickPort modules. It must be made of high-impact, fire-retardant plastic rated UL 94V-0, and be cULus Listed, and compliant with TIA-568-C specifications.

FEATURES

- Color-matched wallplate screws
- Six color choices: ivory, white, grey, black, light almond, and brown
- Fits within minimum rectangular NEMA openings
- Compatible with all individual QuickPort modules
- Individual-port configurability allows specification flexibility
- Narrow module width allows high port density in a small area

DESIGN CONSIDERATIONS

- Fits single-gang backboxes, or four-square boxes with appropriate user-provided reducer.
- Put blanks in unused ports for future expansion.
- Specify port identification method (colored modules, designation labels, and custom silkscreening available). To ID ports, use different colored connectors for each application (full selection of TIA-606 compatible colors –13 available), or Leviton's pre-printed Port Designation Labels.

STANDARDS COMPLIANCE

Meets or exceeds all applicable standards: cULus Listed; complies with TIA-568-C.

PHYSICAL SPECIFICATIONS


- Dimensions: 4.5" H x 2.75" W x .2" D (in-wall depth 1.2" w/ connectors installed)
- Capacity: Available in 1-, 2-, 3-, 4- or 6-port versions
- Materials: High-impact, fire-retardant plastic rated UL 94V-0
- Mounting: Color matched screws

WARRANTY INFORMATION


For a copy of Leviton product warranties, visit www.leviton.com/warranty.

ELECTRONIC FILES

For CAD files, typical specs, or technical drawings (.DXF, .DWG), visit www.leviton.com.

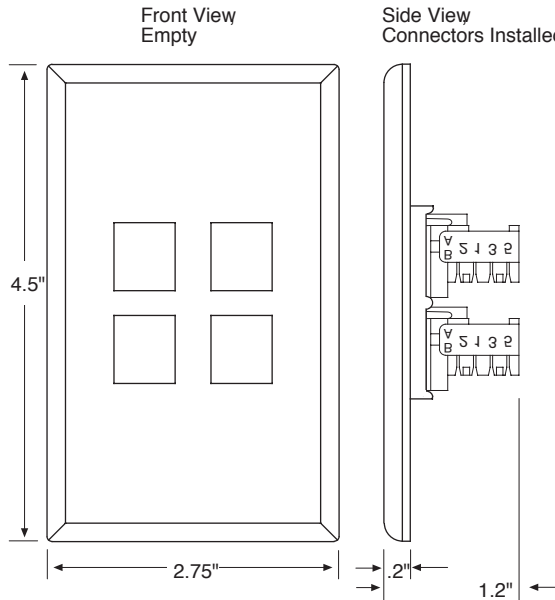

41080-xxP

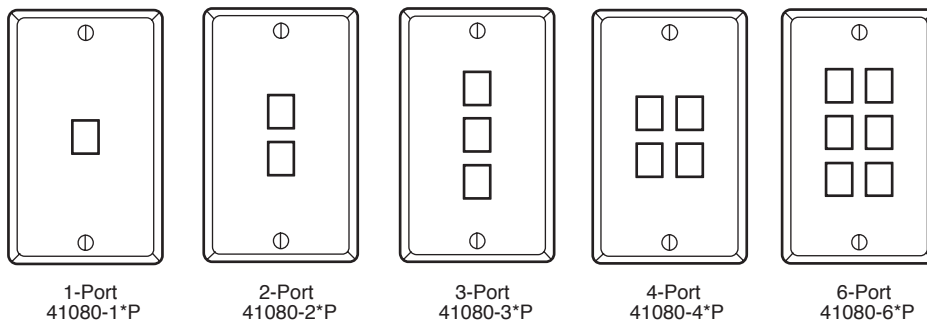

PART NUMBERS

Description	Part No.
QuickPort® Single-Gang 1-Port Wallplate	41080-1*P
QuickPort Single-Gang 2-Port Wallplate	41080-2*P
QuickPort Single-Gang 3-Port Wallplate	41080-3*P
QuickPort Single-Gang 4-Port Wallplate	41080-4*P
QuickPort Single-Gang 6-Port Wallplate	41080-6*P

* = Color Choices: Ivory (I), White (W), Grey (G), Black (E), Light Almond (T), Brown (B)



Leviton Network Solutions
2222 - 222nd St. SE
Bothell, WA 98021-4416

Asia / Pacific
T +1.631.812.6228
E infoasean@leviton.com

Canada
T +1.514.954.1840
E pcservice@leviton.com

Caribbean
T +1.954.593.1896
E infocaribbean@leviton.com

China
T +852.2774.9876
E infochina@leviton.com

Colombia
T +57.1.743.6045
E infocolombia@leviton.com

tel 1-800-824-3005
tel +1-425-486-2222
appeng@leviton.com
www.leviton.com

Europe
T +33.6.8869.1380
E infoeurope@leviton.com

India / SAARC
T +91.80.4322.5678
E infoindia@leviton.com

Mexico
T +52.55.5082.1040
E Isamarketing@leviton.com

Middle East & Africa
T +971.4.886.4722
E lmeinfo@leviton.com

South Korea
T +82.2.3273.9963
E infokorea@leviton.com