

110-Style eXtreme® 6+ Blocks Wall- and Rack-Mount Versions

APPLICATION

Leviton's eXtreme® 6+ 110-Style Blocks provide a centralized location to easily terminate 22-26 AWG solid copper wire for telephone, voice and data applications. The 110-style Blocks and Panels exceed Category 6 channel requirements.

STANDARDS COMPLIANCE

Meets or exceeds all applicable standards: UL listed components; complies with TIA/EIA-568-B.2-1 requirements; and meets FCC Part 68.

PHYSICAL SPECIFICATIONS

Dimensions: See dimensional line art on following page
Materials: 110 wiring bases are made of fire-retardant plastic rated UL 94V-0; C-4 clips are made of fire-retardant plastic rated UL 94V-0 with solder plated IDCs

DESIGN CONSIDERATIONS

- Use where space limitations and low cost are factors.
- 110 wiring bases are available with or without standoff legs.
- Include labels, label holders, and Category 6 C-4 clips.
- Port ID options: Use the label strips and holders provided. Color labeling strips sold separately.

WARRANTY INFORMATION

For a copy of Leviton product warranties, log on to www.levitonvoicedata.com/warranty.

See ELECTRONIC FILES for CAD files (.DXF, .DWG, MS-DOS.EPS) on disk



For ELECTRONIC Typical Specs see (.TXT) file on disk.

TYPICAL SPECIFICATION

The cross-connect shall be Category 6 110-style wiring bases, available for wall- or rack-mount. They shall provide 110 terminations supporting voice, security, and Category 6 data applications, including high megabit and shared-sheath applications when used with Category 6 rated cabling. The components shall be UL listed and TIA/EIA-568-B.2-1 compliant. Bases shall support 96-, 192- and 288-pair densities with provision for TIA/EIA-606 compliant labeling. Plastic bases and blocks must be made of fire-retardant plastic rated UL 94V-0.

110-Style eXtreme® 6+ Blocks



For Technical Support Call 1-425-485-4288; in USA call 1-800-824-3005.
Spec sheets and updates are also available at www.levitonvoicedata.com.

2222 - 222nd St. SE • Bothell, WA 98021 USA
Tel: 1-800-722-2082 / 1-425-485-4288 • Fax: 1-425-483-5270 • Int'l Fax: 1-425-485-9170 • GSA Schedule Available.









110-Style eXtreme® 6+ Blocks

Part Numbers
41AB6-XF4 **41NB6-1F4**
 41DR6-XF4 41NB6-1F4

DIMENSIONAL LINE ART

See ELECTRONIC FILES for CAD files (.DXF, .DWG, MS-DOS.EPS) on disk

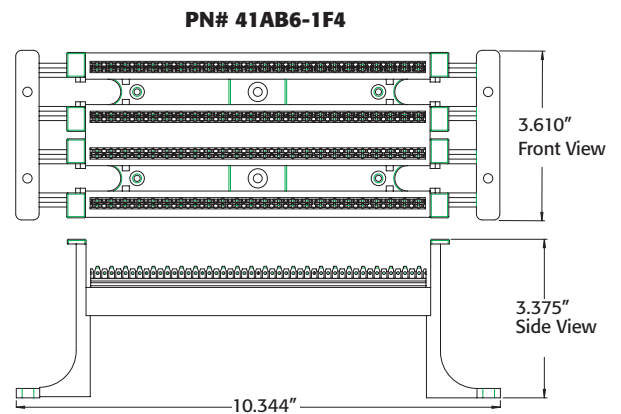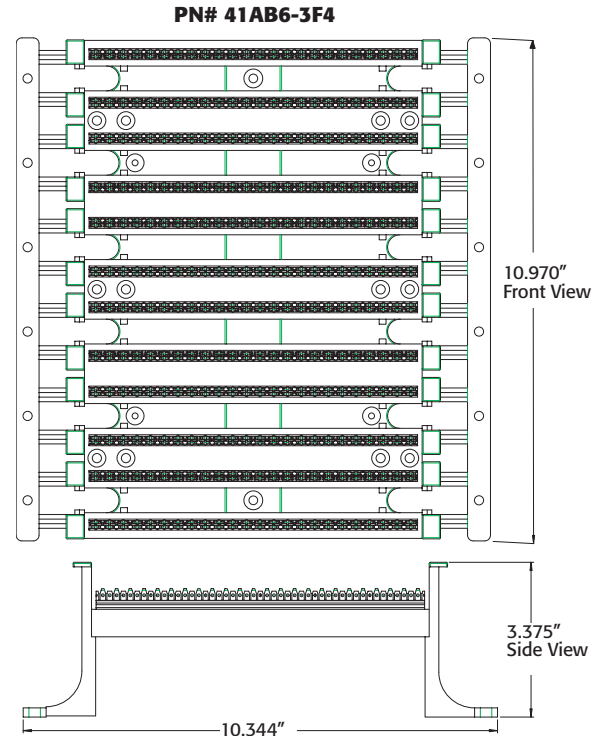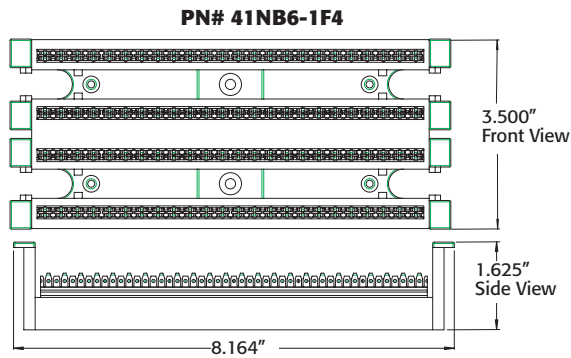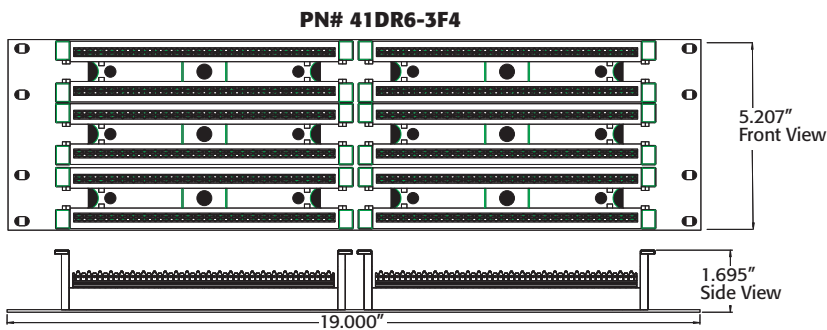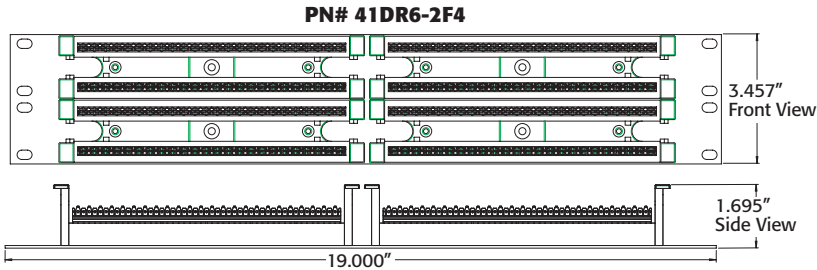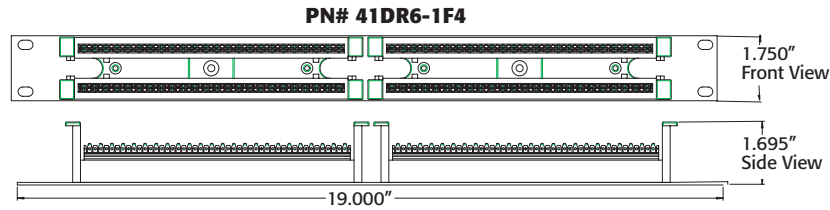

PART NUMBERS

Description	Part No.	Description	Part No.
eXtreme 6+ 110-Style Block, Wall-Mount w/ Legs, CAT 6, 96-Pair	41AB6-1F4	eXtreme 6+ 110-Style Block, Rack-Mount, CAT 6, 96-Pair	41DR6-1F4
eXtreme 6+ 110-Style Block, Wall-Mount w/o Legs, CAT 6, 96-Pair	41NB6-1F4	eXtreme 6+ 110-Style Block, Rack-Mount, CAT 6, 192-Pair	41DR6-2F4
eXtreme 6+ 110-Style Block, Wall-Mount w/ Legs, CAT 6, 288-Pair	41AB6-3F4	eXtreme 6+ 110-Style Block, Rack-Mount, CAT 6, 288-Pair	41DR6-3F4



For Technical Support Call 1-425-485-4288; in USA call 1-800-824-3005.
 Spec sheets and updates are also available at www.levitonvoicedata.com.



2222 - 222nd St. SE • Bothell, WA 98021 USA • Tel: 1-800-722-2082 / 1-425-485-4288 • Fax: 1-425-483-5270 • Int'l Fax: 1-425-485-9170 • GSA Schedule Available.