



Network Equipment Racks & Accessories

Two-Post Network Equipment Rack

3" Uprights, 19" & 23" Panel Mounting, Customer Premise

- Universal junction hole pattern matches most manufacturers racks.
- #12-24 panel mounting holes.
- Conformance to EIA/ECA-310-E.
- Load Rating: 1200 Lbs. (544kg) weight capacity when evenly distributed for the height of the rack (84" (2133mm) and shorter).
- Permanently stamped rack mount unit (RMU) markings included.
- Packaged unassembled in protective carton suitable for parcel shipment.
- Assembles in about ten (10) minutes using standard hand tools.
- Includes thirty (30) dog point combo head (Phillips and flat blade) mounting screws.
- Double sided universal ($\frac{5}{8}$ " (16mm), $\frac{5}{8}$ " (16mm), $\frac{1}{2}$ " (13mm)) mounting spacing.
- Twin top angles for rigidity.
- Tapped assembly holes eliminate the need for nuts and simplifies assembly and squaring.
- UL Listed (File No. E171936) as a communications circuit accessory.
- Material: Aluminum
- Finish ____ : Brushed (AL) uprights with Silver Telco Gray Powder Coat (TG) or Flat Black Powder Coat (FB)
Other finishes are available upon request

Junction Hole Pattern for 84" tall rails

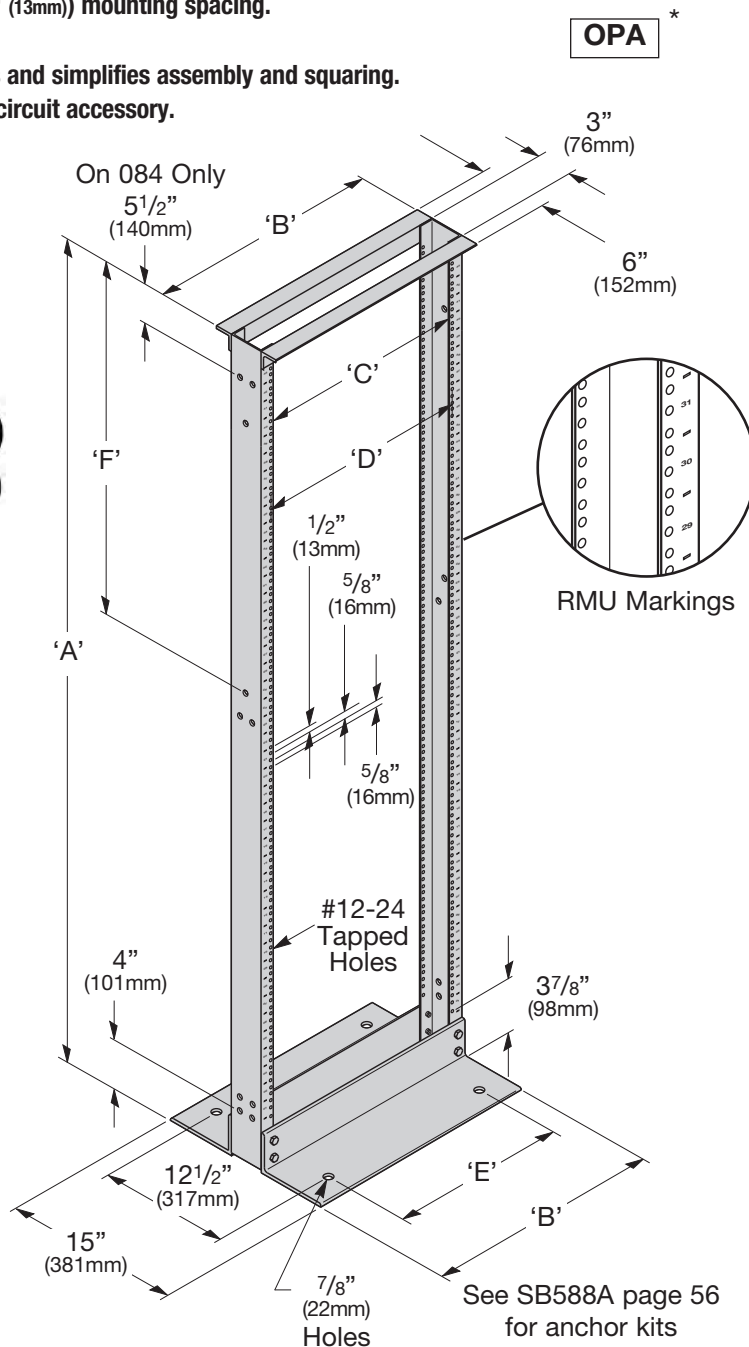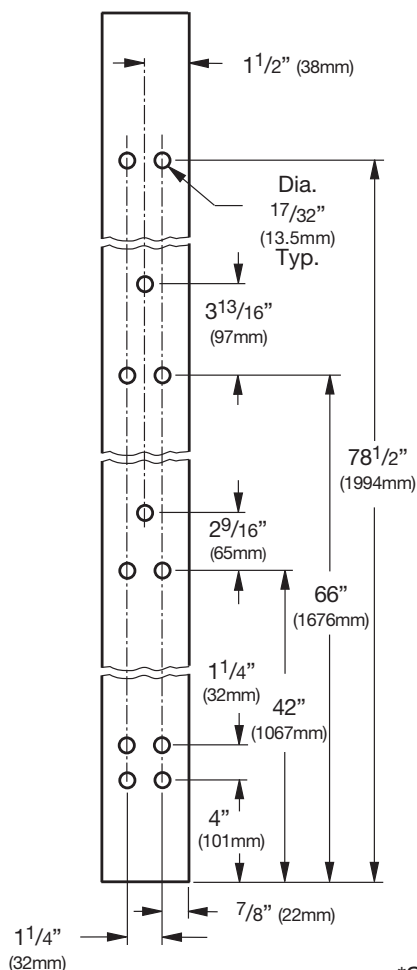

See SB588A page 56
for anchor kits

Continued on page 13.

*See page 8 for OPA details.

Two-Post Network Equipment Rack

3" Uprights, 19" & 23" Panel Mounting, Customer Premise

Dimensions					
		19" (482mm) Rack Width		23" (594mm) Rack Width	
		In.	(mm)	In.	(mm)
'A'	Overall Height	36" - 108"	(914 - 2743)	36" - 108"	(914 - 2743)
'B'	Overall Width	20 ⁵ / ₁₆ "	(516)	24 ⁵ / ₁₆ "	(617)
'C'	Panel Mounting	18 ⁵ / ₁₆ "	(465)	22 ⁵ / ₁₆ "	(567)
'D'	Usable Inside Width	17 ³ / ₄ "	(451)	21 ³ / ₄ "	(552)
'E'	Base Anchor Spacing	16"	(406)	20"	(508)

Universal Spacing [⁵/₈" (16mm), ⁵/₈" (16mm), ¹/₂" (13mm)]

Part Number	'A' Height		'F' Spacing		Mounting Spaces	Shipping Weight	
	In.	(mm)	In.	(mm)		Lbs.	(kg)
19" (482mm) Rack Width							
SB556036XU__	36"	(914)	6"	(152)	17	22.0	(10.0)
SB556048XU__	48"	(1219)	3 ⁷ / ₁₆ "	(87)	24	24.0	(10.9)
SB556072XU__	72"	(1829)	27 ⁷ / ₁₆ "	(697)	38	27.5	(12.5)
SB556084XU__	84"	(2133)	39 ⁷ / ₁₆ "	(1001)	45	30.0	(13.6)
SB556096XU__	96"	(2438)	51 ⁷ / ₁₆ "	(1306)	51	31.5	(14.3)
SB556108XU__	108"	(2743)	54 ³ / ₁₆ "	(1376)	58	33.5	(15.2)
23" (584mm) Rack Width							
SB558036XU__	36"	(914)	6"	(152)	17	24.5	(11.1)
SB558048XU__	48"	(1219)	3 ⁷ / ₁₆ "	(87)	24	26.5	(12.0)
SB558072XU__	72"	(1829)	27 ⁷ / ₁₆ "	(697)	38	30.0	(13.6)
SB558084XU__	84"	(2133)	39 ⁷ / ₁₆ "	(1001)	45	32.0	(14.5)
SB558096XU__	96"	(2438)	51 ⁷ / ₁₆ "	(1306)	51	34.0	(15.4)
SB558108XU__	108"	(2743)	54 ³ / ₁₆ "	(1376)	58	36.0	(16.8)

Finish __ : Brushed (AL), Telco Gray Powder Coat (TG) or
Flat Black Powder Coat (FB)

✓ FB & AL are popular items