


FLEXTRAY's design offers you more

Safety Edge

FLEXTRAY offers the "T" weld safety edge, which protects both the cable and the installer while installing cables.

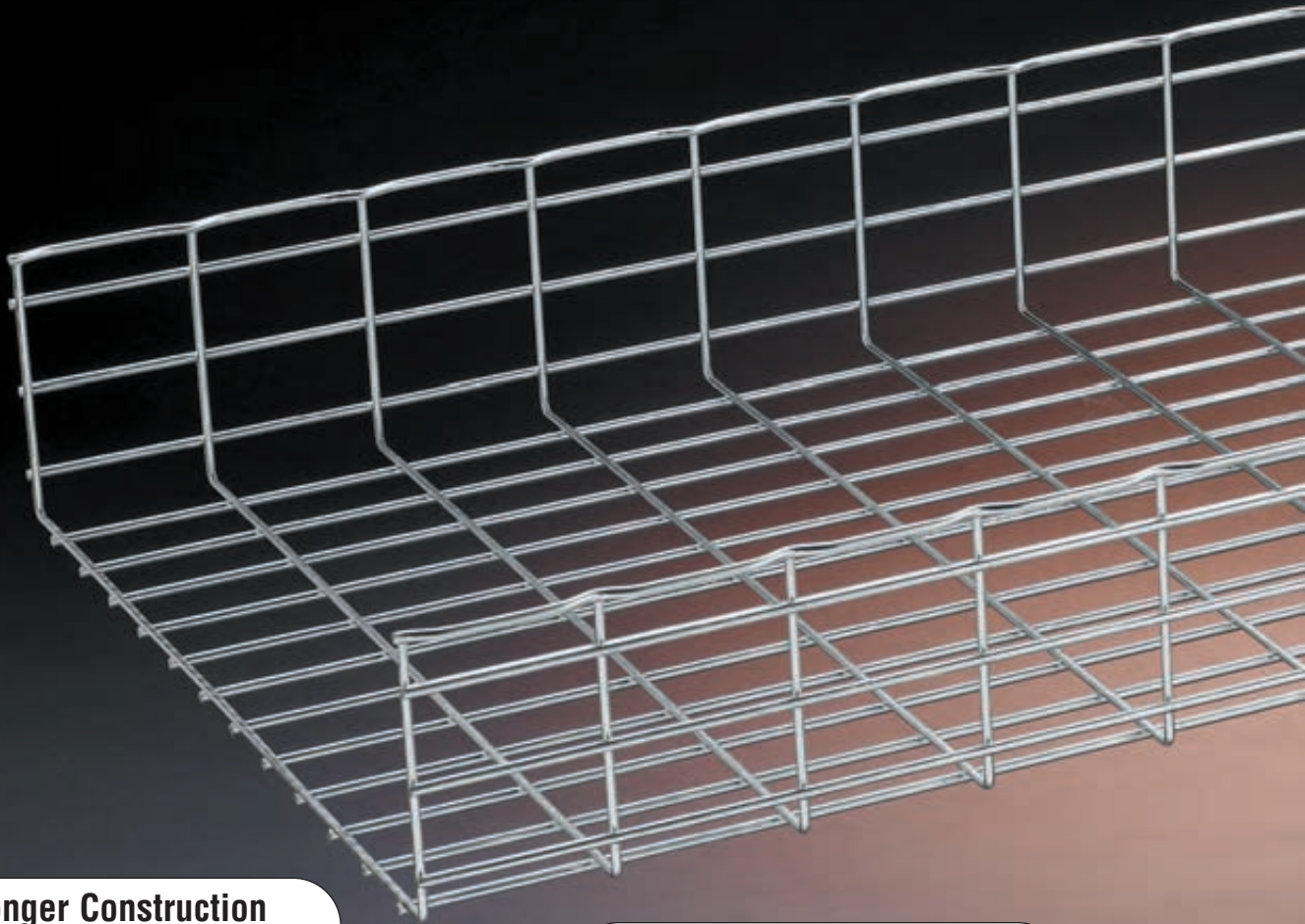

Stronger Construction

FLEXTRAY utilizes the largest gauge steel in the industry .196" (5mm) diameter minimum. Tray strength is governed by wire size and stronger material means stronger trays.

Clean Smooth Cuts

Only FLEXTRAY delivers the patented Cleanshear® cutting tool providing smooth edges and protecting your cable investment.

Most UL Classified Tray Sizes

FLEXTRAY meets UL grounding requirements. Save time and money with UL Classified Flextray and splices!

Largest Range Of Sizes Available

FLEXTRAY offers depths of 1 1/2" (38mm) to 6" (152mm) and widths up to 32" (813mm).


Union Made In The USA

FLEXTRAY is Union made in the U.S.A.


Flextray™ - Straight Sections

Straight Sections

1.5" Deep Flextray

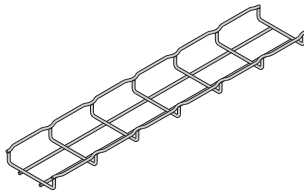



Height: 1.38" (35 mm)
Length: 118.312" (3 meter)
Wire Dia. Minimum: .196" (5.0 mm)
Finishes:
EG, GS, BLE, HD, 304S, 316S

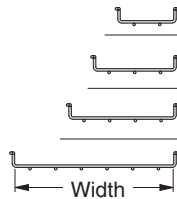


Part Number	Width		Wt. Per Pc.	
	in.	mm	lbs.	kg
FT1.5X4X10	4	100	5.8	2.63
FT1.5X6X10	6	150	7.4	3.35
FT1.5X8X10	8	200	9.0	4.08
FT1.5X12X10	12	300	12.1	5.49

Only FT1.5X12 (12" wide) is UL Classified and CSA certified

 2" Deep Flextray

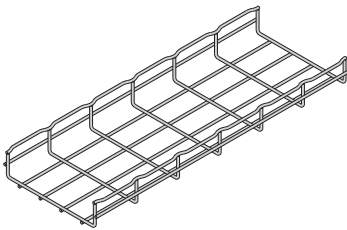

Height: 2.38" (60 mm)
Length: 118.312" (3 meter)
Wire Dia. Minimum: .196" (5.0 mm)
Finishes:
EG, GS, BLE, HD, 304S, 316S

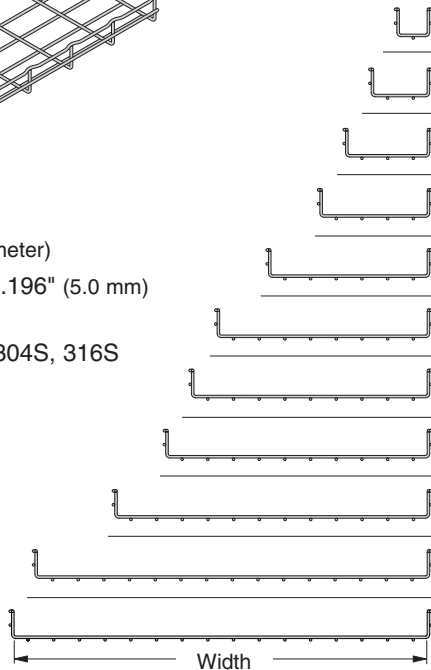


Part Number	Width		Wt. Per Pc.	
	in.	mm	lbs.	kg
FT2X2X10	2	50	6.6	2.99
FT2X4X10	4	100	8.2	3.72
FT2X6X10	6	150	9.7	4.40
FT2X8X10	8	200	11.2	5.08
FT2X12X10	12	300	14.3	6.48
FT2X16X10	16	400	17.4	7.89
FT2X18X10	18	450	18.9	8.57
FT2X20X10	20	500	20.4	9.25
FT2X24X10	24	600	23.5	10.66
FT2X30X10	30	750	28.1	12.74
FT2X32X10	32	800	29.7	13.47

FT2X6 (6" wide) through FT2X32 (32" wide) are UL Classified and CSA certified

See page - 2 for finish information

4" Deep Flextray

Part Number	Width		Wt. Per Pc.	
	in.	mm	lbs.	kg
FT4X4X10	4	100	11.25	5.10
FT4X6X10	6	150	12.79	5.80
FT4X8X10	8	200	14.32	6.49
FT4X12X10	12	300	17.39	7.89
FT4X16X10	16	400	20.45	9.27
FT4X18X10	18	450	21.99	9.97
FT4X20X10	20	500	23.52	10.67
FT4X24X10	24	600	26.59	12.06
FT4X30X10	30	750	31.19	14.15

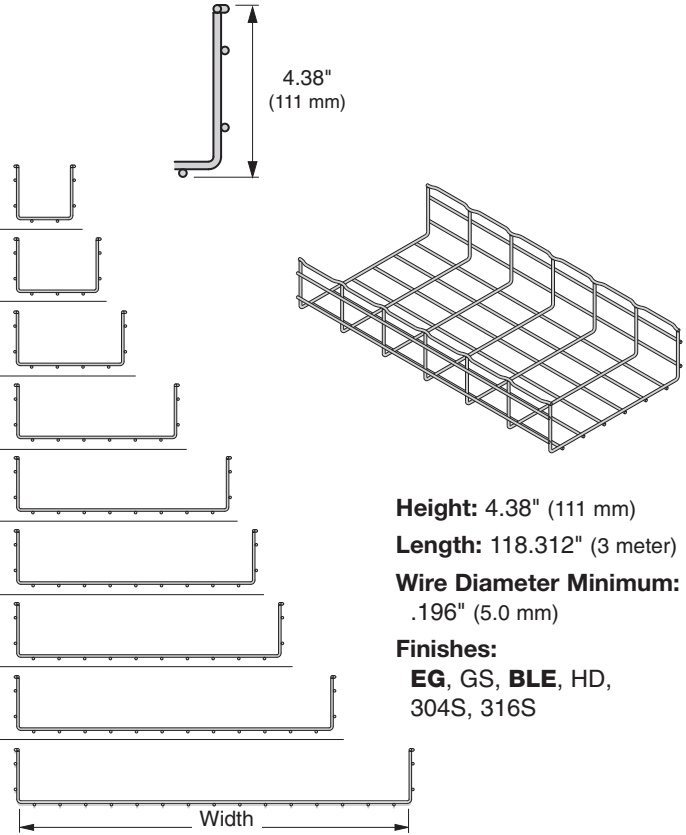


Height: 4.38" (111 mm)
Length: 118.312" (3 meter)
Wire Diameter Minimum:
 .196" (5.0 mm)
Finishes:
EG, GS, BLE, HD,
304S, 316S

All 4" deep Flextrays are UL Classified and CSA certified

6" Deep Flextray

Part Number	Width		Wt. Per Pc.	
	in.	mm	lbs.	kg
FT6X8X10	8	200	17.39	7.89
FT6X12X10	12	300	20.45	9.27
FT6X16X10	16	400	23.52	10.67
FT6X18X10	18	450	25.06	11.37
FT6X20X10	20	500	26.59	12.06
FT6X24X10	24	600	29.66	13.45

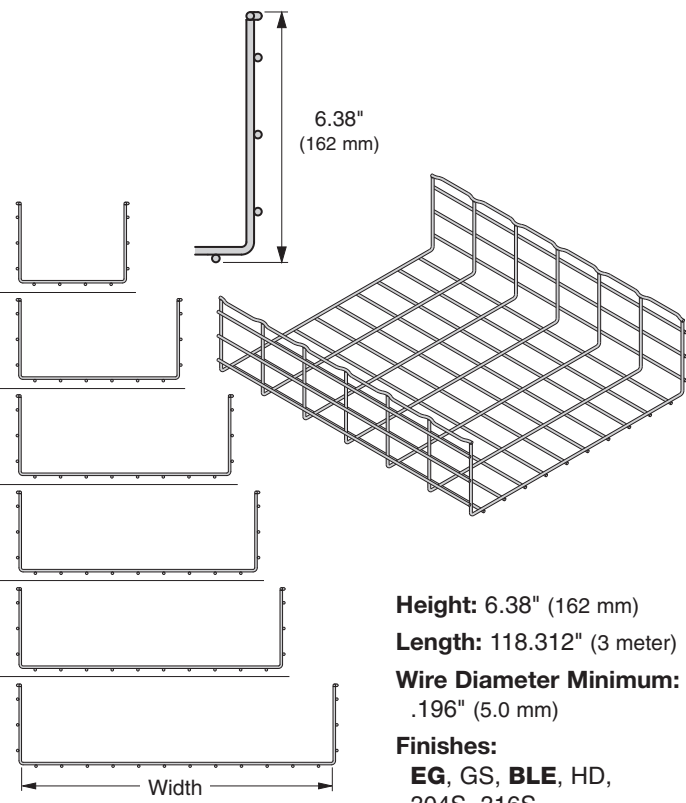

Height: 6.38" (162 mm)
Length: 118.312" (3 meter)
Wire Diameter Minimum:
 .196" (5.0 mm)
Finishes:
EG, GS, BLE, HD,
304S, 316S

All 6" deep Flextrays are UL Classified and CSA certified

See page - 2 for finish information