

High-performance,
entry-level price

Comfortable and
durable choice for PC
calls and multimedia



plantronics®

More UC headset for your UC dollar

Blackwire® 300 Series

The best-featured headset you never thought your budget could afford

Blackwire 300 Series

More headset for your UC dollar. Enter UC with the best-featured headset you never thought your budget could afford. Blackwire 300 Series USB headsets are a simple-to-use, comfortable, and durable choice for conference calls, Web-based training, and PC multimedia applications. Plus, they're priced right, easy to deploy, and offer a simple-to-upgrade UC solution that IT can roll out easily and rely on.

SIMPLICITY MEETS DURABLE DESIGN

- Two wearing styles available: hi-fi stereo (C320/325) or monaural (C310/315) design
 - Blackwire 310/320 are the base models featuring basic foam ear cushions.
 - The Blackwire 315/325 are the value-add models that feature leatherette ear cushions that fold flat for easy portability.
- Lightweight metal headband offers durability and a customizable, comfortable fit
- Intuitive inline controls to answer/end calls, control volume, and mute
- Smartly placed indicator lights and helpful audio alerts give user call, mute, and volume status

OUTSTANDING AUDIO QUALITY

- Wideband audio with noise-canceling for high-quality PC telephony
- Dynamic EQ feature automatically adjusts audio for voice or multimedia use
- Noise-canceling microphone filters out background sound
- Enhanced Digital Signal Processing (DSP) provides more natural voice sound
- SoundGuard® technology provides protection against audio spikes

RECOMMENDED ACCESSORIES*

- Travel case provides a secure and convenient transportation option
- Leatherette ear cushions offer alternate comfort option



GLOBAL CUSTOMER CARE

Backed by Plantronics industry leading global service and support.

800-544-4660 (US and Canada)

831-458-7700 (outside US)



OPTIMIZED FOR UNIFIED COMMUNICATIONS


Connects to	PC via USB
Compatible with	Windows® or Mac® OS
Ideal for	Users transitioning to PC telephony for webinars, conference calls, music, and other multimedia applications
Audio performance	Dynamic EQ, microphone frequency response 100 Hz–10 kHz optimal for wideband voice telephony (up to 6,800 Hz), hi-fi stereo (C320, C325) output from 20 Hz–20 kHz, enhanced digital signal processing (DSP), noise-canceling microphone
Hearing protection	SoundGuard: Acoustic limiting for protection against sounds above 118 dBA
Limited warranty	2 years
Models	C310 (monaural), C315 (monaural, foldable), C320 (stereo), C325 (stereo, foldable): UC Standard version built for UC applications and softphones from Avaya®, Cisco®, IBM®, Skype®, and more** C310-M (monaural), C315-M (monaural, foldable), C320-M (stereo), C325-M (stereo, foldable): Version optimized for Microsoft® Lync® 2010, and Microsoft® OCS 2007

For more information about the Blackwire 300 Series or other Plantronics products, please visit our website at plantronics.com

* Travel case and leatherette ear cushions come with the Blackwire 315/325.

**Download the latest release of Plantronics Spokes™ software to get one-touch call answer/end with these softphones.

©2013 Plantronics, Inc. All rights reserved. Plantronics, the Sound World graphic, Blackwire, SoundGuard, and Spokes are trademarks or registered trademarks of Plantronics, Inc. Microsoft, Windows, and Lync are trademarks or registered trademarks of Microsoft Corporation in the U.S. and other countries. Avaya is a trademark of Avaya Inc. registered in the US and other countries. Cisco is a registered trademark of Cisco Systems, Inc. and/or its affiliates in the U.S. and certain other countries. IBM is a trademark of International Business Machines Corporation, registered in many jurisdictions worldwide. Mac is a registered trademark of Apple Inc. Skype is a trademark of Skype Limited or other related Skype companies. 9.13

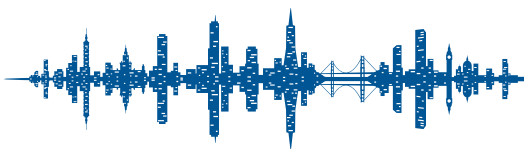

plantronics®