

# Utility Hand Tools

Klein® manufactures the highest quality tools in the industry, supporting linemen and utility workers around the world with premium products—quality and reliability you can count on every day.



**KLEIN  
TOOLS®**

# Ratcheting Cable Cutter

ACSR



**Quick-release lever** opens blade at any time during operation.

**Unique ratchet action** holds cable tight and allows rapid, straight cuts with minimum effort.

**ACSR Cable Cutter**  
(63607)



**Cleanly cuts 336 MCM Linnet ACSR and 2/0 triplex steel messenger cable.**

- High leverage ratchet mechanism for single-handed cutting of copper and aluminum cables, leaving no burrs or sharp edges.
- Patented two-step ratchet mechanism requires fewer strokes per cut.
- Precision ratcheting mechanism holds cable tight and allows rapid, straight cuts with minimum effort.
- Hardened steel cutting blades for lasting strength and sharpness.
- One-year warranty.

63607

## MCM Maximum Cable Capacity

Cat. No.	Copper	Aluminum	Communication Cable	ACSR	Overall Length	Handle Color	Weight (lbs.)
63607	400 MCM (185 mm <sup>2</sup> )	600 MCM (300 mm <sup>2</sup> )	–	336 MCM (170 mm <sup>2</sup> )	10-1/4" (260 mm)	yellow	1.50 (.68 kg)

All dimensions are in inches and (millimeters).

**WARNING:** Always wear approved eye protection.

**WARNING:** NOT insulated. Plastic-dipped or slip-on plastic handles are NOT intended for protection against electrical shock.



# Lineman's Wrenches

## Ratcheting 5-in-1 Lineman's Wrenches

- Bolt-through design allows bolts to pass through the socket.
- 3/4" and 1" x 1-1/8" combination square socket for most common utility hardware.
- Features two popular wrench sizes: 9/16" and 3/4".



Cat. No.	Description	Length	Weight (lbs.)
KT155HD	Ratcheting Lineman's Wrench Heavy-Duty	12" (305 mm)	2.10 (.95 kg)
KT155T	Ratcheting Lineman's Wrench Compact	9-3/8" (238 mm)	1.42 (.64 kg)



**⚠WARNING:** Never use on or near live electrical circuits.



## Lineman's Insulating 4-in-1 and Ratcheting Box Wrench

- Chrome plated finish resists corrosion.
- "See-through" insulating handle confirms metal ends are not connected (Cat. No. KT223X4-INS).
- 1/2", 9/16", 5/8" and 3/4" sizes in one tool; 12-point sockets.
- Reverse ratcheting action by reversing switches on each end of the wrench.

Cat. No.	Description	Socket Size	Length	Weight (lbs.)
KT223X4-INS	Insulating Lineman's Ratcheting Box Wrench	1/2", 9/16", 5/8" & 3/4"	9" (229 mm)	.70 (.32 kg)
KT223X4	Lineman's Ratcheting Box Wrench	1/2", 9/16", 5/8" & 3/4"	9" (229 mm)	.70 (.32 kg)

KT223X4

All dimensions are in inches and (millimeters).

**⚠WARNING:** Always wear approved eye protection.

**⚠WARNING:** Do NOT push or hammer wrench.

**⚠WARNING:** Do NOT touch uninsulated portion of the tool or any conductive object when either might contact an energized source.

**⚠WARNING:** Do NOT extend handle length.



## Specialty Wrenches

### 3-in-1 Impact Socket

- Includes 3/4" (also works with 13/16"), 1" and 1-1/8" square sizes.
- 7/16" hex quick-change adapter included.
- Improved ball detent on socket adapter.
- 13/16" diameter, 6" long hollow shaft allows use on long threaded bolts.

Cat. No.	Description	Length	Weight (lbs.)
NRHD	3-in-1 Impact Socket	7-3/4" (197 mm)	2.0 (.91 kg)
<b>Replacement Parts</b>			
NRHDA	Impact Socket Adapter		



NRHD



NRHDA  
Replacement Adapter

## Cushion-Grip Screwdriver

### Demolition Driver – Keystone-Tip Screwdrivers

- Plated metal strike cap to protect handle from hammer blows.
- Heat treated metal shaft runs complete length of handle to metal strike cap to transfer metal strike force.



602-4DD



602-7DD

Cat. No.	Tip Size	Blade Length	Overall Length	Weight (lbs.)
602-4DD	1/4"	4" (102 mm)	9" (229 mm)	.37 (.17 kg)
602-7DD	5/16"	7" (178 mm)	12-3/8" (314 mm)	.56 (.25 kg)


## Utility Hand Tools

### Lineman's Milled-Face Hammer

- One milled face for driving staples used in pole-line work and common, unhardened nails.
- Other face is smooth for driving heavier duty hardware.
- Rugged and well-balanced, with the weight to drive lag bolts.
- Forged, tempered-steel head is only 3-3/4" (95 mm) long for use in tight areas.



809-36MF

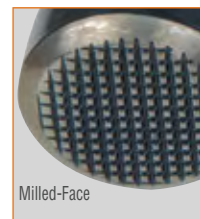

Milled-Face



Smooth face bends staples  
Milled-face drives staples straight

Cat. No.	Head Weight	Overall Length	Weight (lbs.)
809-36MF	36 oz. (1021 g)	14" (356 mm)	2.50 (1.13 kg)

All dimensions are in inches and (millimeters).

**▲WARNING:** Always wear approved eye protection.

**▲WARNING:** Do NOT use on live conductors.

See our complete line of **Lineman Equipment and Accessories** at

[www.kleintools.com](http://www.kleintools.com)



**KLEIN TOOLS**

