


## WRAS Submersible Pump Cable

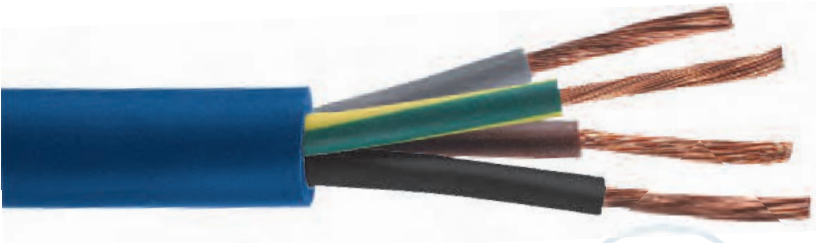

## Application

Suitable for use with drinking water.

## Specifications

UK - WRAS approved  
 Germany - KTW approved  
 France - ACS approved

- **Conductors:** Flexible Class 5 plain annealed copper conductor to IEC60228
- **Insulation:** Cross linked polymer
- **Sheath:** Cross linked rubber. Blue
- **Temperature Rating:** 90°C maximum conductor operating temperature  
 -25°C Flexing  
 -40°C Fixed
- **Voltage Rating:** 450/750 V
- **Core Colours:**  
 4 core: Brown, Black, Grey, Green-Yellow

Anixter Number	Nominal Conductor Area mm <sup>2</sup>	Nominal Outer Diameter mm	Approximate weight kg/km
<b>Single-Core Type</b>			
HYDRO-1C-0350	35	15	444
HYDRO-1C-0500	50	17	618
HYDRO-1C-0700	70	19	831
HYDRO-1C-0950	95	22	1118
HYDRO-1C-1200	120	24	1385
HYDRO-1C-1500	150	25	1630
<b>Four Core Type</b>			
HYDRO-4C-0060	6	17	366
HYDRO-4C-0100	10	23	632
HYDRO-4C-0160	16	26	896
HYDRO-4C-0250	25	31	1369
HYDRO-4C-0350	35	34	1827
HYDRO-4C-0500	50	39	2540
HYDRO-4C-0700	70	41	3640
HYDRO-4C-0950	95	47	4640
<b>Seven Core Type</b>			
HYDRO-7C-0025	2.5	18	460