


Dominion® LX

 Small to Midsize Businesses

Reliable Server Management for SMBs

Available models

- ▶ DLX-108: 1 remote, 1 local user, up to 8 servers
- ▶ DLX-116: 1 remote, 1 local user, up to 16 servers
- ▶ DLX-216: 2 remote, 1 local user, up to 16 servers

Features

- ▶ BIOS-level access and control
- ▶ Universal Virtual Media™*
- ▶ Absolute Mouse Synchronization™*
- ▶ Local and remote access
- ▶ Common browser-based user interface
- ▶ Security and encryption features
- ▶ RADIUS, LDAP and Active Directory® administration
- ▶ Multi-language support
- ▶ Modern architecture platforms with high definition (HD) 1920x1080 remote video resolution
- ▶ Flexible tiering for management of up to 256 computers from a single console
- ▶ Multiplatform support: Windows®, Macintosh®, Linux®, Sun®/Solaris™
- ▶ Flexible CIM options

*D2CIM-VUSB or D2CIM-DVUSB required

Please visit www.raritan.eu/LX to learn more



Affordable, high-quality, KVM-over-IP for the evolving small or midsize business


Get more, pay less!

Raritan's Dominion LX KVM-over-IP switches give one or two remote users, with an independent local port, BIOS-level access and control of 8 or 16 servers. With flexible tiering (cascading) users can manage up to 256 computers from a single console.

These appliances, specifically designed for small to midsize businesses (SMBs), offer economical, remote access from anywhere; efficient, reliable server management; and an affordable feature set.



Dominion LX benefits include:

- ▶ Efficient, reliable server management
- ▶ Economical, secure remote access from anywhere
- ▶ Economical footprint
- ▶ Efficient server diagnostics and restore capabilities
- ▶ Reduced travel time and training costs
- ▶ Cable package options for a minimum initial investment

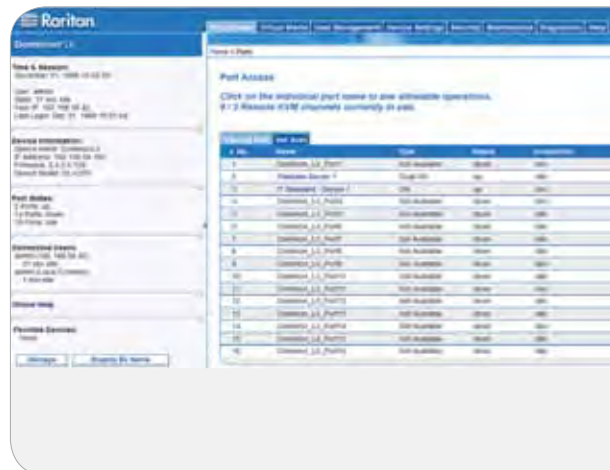


Specifications


DLX-216 shown

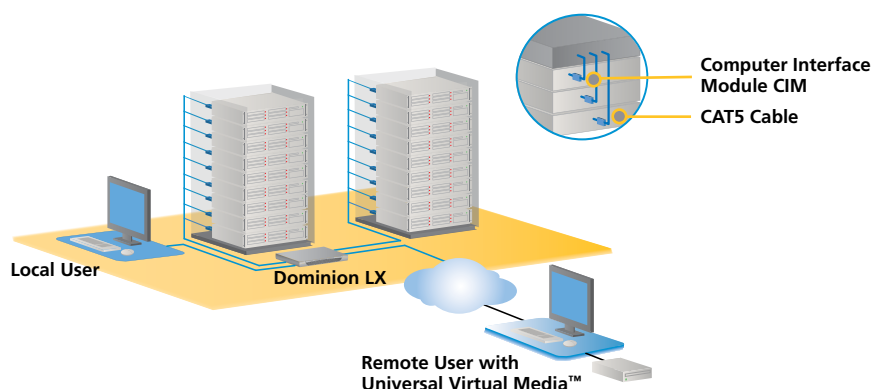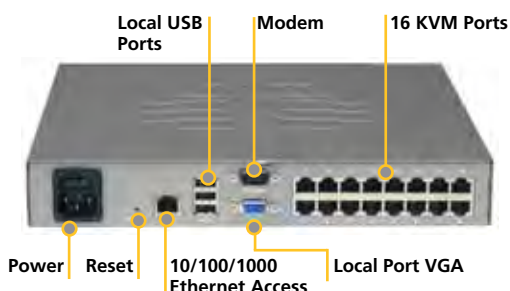


Dominion LX Model	Description	Product Dimension (WxDxH), Shipping Weight and Power	Environment	Cable Packages
DLX-108	Economical 8-port KVM-over-IP switch, 1 remote, 1 local user, virtual media, single power and single LAN	291 mm x 270 mm x 44 mm; 11.45" x 10.63" x 1.73";	Operating Temperature: 0° – 40° C (32° – 104° F) Humidity: 20% – 85% RH	DLX-108-MPAC: One DLX108 with 8 MCUTP20 1.9 meter (6.5 foot) cables
DLX-116	Economical 16-port KVM-over-IP switch, 1 remote, 1 local user, virtual media, single power and single LAN	4.0 kg ; 8.82 lbs		DLX-116-MPAC: One DLX116 with 16 MCUTP20 1.9 meter (6.5 foot) cables
DLX-216	Economical 16-port KVM-over-IP switch, 2 remote, 1 local user, virtual media, single power and single LAN	Single power 100-240V AC, 50-60 Hz, 0.5A, 30 watts, 25.794 kcal/h		DLX-216-MPAC: One DLX216 with 16 MCUTP20 1.9 meter (6.5 foot) cables D2CIM-VUSB or D2CIM-DVUSB required for Absolute Mouse Synchronization and Universal Virtual Media.
Hardware Supported				
Form Factor	1U, rack mountable (brackets included)			
Local Access Ports	Video: HD15(F) VGA; Keyboard/Mouse: USB(F); 3 USB rear			
Sample Video Resolutions	PC text mode: 640x350, 640x480, 720x400 PC graphic mode: 640x480, 800x600, 1024x768, 1152x864, 1280x1024, 1440x900, 1680x1050, 1600x1200, 1920x1080 Sun video mode: 1024x768, 1152x864, 1152x900, 1280x1024			
Remote Connection				
Ports	8 (DLX-108) or 16 (DLX-116, DLX-216)			
Users	Local user; 1 or 2 remote users (model dependent)			
Network	Single 10/100/1000 gigabit Ethernet access, dual-stack: IPv4 and IPv6			
Protocols	TCP/IP; HTTP; HTTPS; UDP; RADIUS; SNMP; DHCP; PAP; CHAP			
Computer Interface Modules (CIMs) and Cat5 Cables				
Dominion CIMs	Available for USB, Dual USB, Universal Virtual Media/Absolute Mouse Synchronization, PS2, Sun, Serial Devices Dimensions (WxDxH) = 43 mm x 90 mm x 19 mm ; 1.7" x 3.5" x 0.8" (dual USB) and 33 mm x 76 mm x 15 mm; 1.3" x 3.0" x 0.6" (other DCIMs)			
Cat5 MCUTP Cables	KVM UTP cable for PS/2, USB, Sun – lengths from 0.6m (2 ft.) – 6m (20 ft.). Specifications: RJ45 <-> HDB-15M, mini-din 6 x 2 (PS/2), USB type A (USB/Sun)			
Service and Support				
Warranty	Two years. In addition, Raritan offers two years extended warranty.			




D2CIM-VUSB




MCUTPxx-PS2




DCIM-PS2



MCUTPxx-USB



D2CIM-DVUSB



DCIM-USBG2



© 2011 Raritan Inc. All rights reserved. Raritan®, Know more. Manage smarter.™, Dominion®, Universal Virtual Media™ and Absolute Mouse Synchronization™ are registered trademarks or trademarks of Raritan Inc. or its wholly-owned subsidiaries. All others are registered trademarks or trademarks of their respective owners.

Based in Somerset, NJ, Raritan has 38 offices worldwide, serving 76 countries. For more information, please visit www.raritan.eu