

## Anixter Part No : RG11-LSNH-BLACK

Part NO. □ 20070912-20

Ver. □ A0


Product Code □ RG11 LSNH

Page □ 1 / 1

### 1.CONSTRUCTION

Item		A.Q.L	Description
Conductor	NO./mm	T0.40	Stranded tinned copper
	T0.40mm x 7	(+/-0.010)	
Insulation	NO./mm	7.25	Solid PE insulation
	7.25 SPE	(+/-0.30)	
Shield	NO./mm	192 (+/-2)	Bare copper braid shield
	0.18mm x 192	0.18 (+/-0.008)	
Jacket	NO./mm	10.30	LSNH jacket
	10.30	(+/-0.50)	

### 2.DESIGN

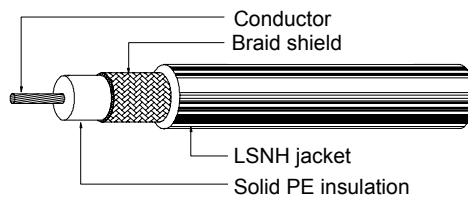

### 3.CHARACTERISTICS

Item	Description	Standards	
1. Cond. Res.	20□, Conductor DC Resistance	< 2.36 Ω/100M	
2. Insul. Res.	20□, Insulation Resistance	> 200 MΩ.M	
3.Braid coverage	-----	96(+/-3)%	
4. Capacitance	-----	67.0 ±5 pF/M	
5. Velocity ratio	-----	66.6 ±3 %	
6. Char. Imped.	-----	75 ±5 Ω	
7. Attenuation	20°c	100 MHz	7.10
	-dB/100M	500 MHz	20.0
	□ +/-15%□	1000 MHz	28.5

\*Remark: Please contact us if you have more requirements or specifications subject to change, or else in accordance with the standards.\*

Prepared: Zhao

Approved by □

Client approved:

Date :2007-09-12