



Anixter Part No : AL-6C-PVC-P100

Part NO. : 0840320

Ver. : A0


Product Code : AL-6022 WT CABLE

Page : 1 / 1

1.CONSTRUCTION

Item		A.Q.L	Description
Conductor	NO./mm	0.19	Stranded tinned copper
	6 / T0.19 x 7	(+/-0.008)	
Insulation	NO./mm	1.00	PVC insulation
	6 / 1.0mm	(+/-0.10)	
Jacket	NO./mm	4.0	Nylon rip cord
	4.0	(+/-0.18)	White PVC jacket

2.DESIGN

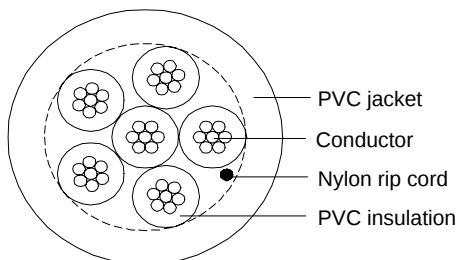

3.CHARACTERISTICS

Item	Description	Standards
1. Cond. Res.	20°C, Conductor DC Resistance	< 10.43 Ω/100M
2. Insul. Res.	20°C, Insulation Resistance	> 200 MΩ.M
3. Rated Tem.	-----	60°C
4. Rated Voltage	-----	300 V

Remark: Please contact us if you have more requirements or specifications subject to change, or else in accordance with the standards.

Prepared: Dalen

Approved by :

Client approved :

Date : 2007-11-16