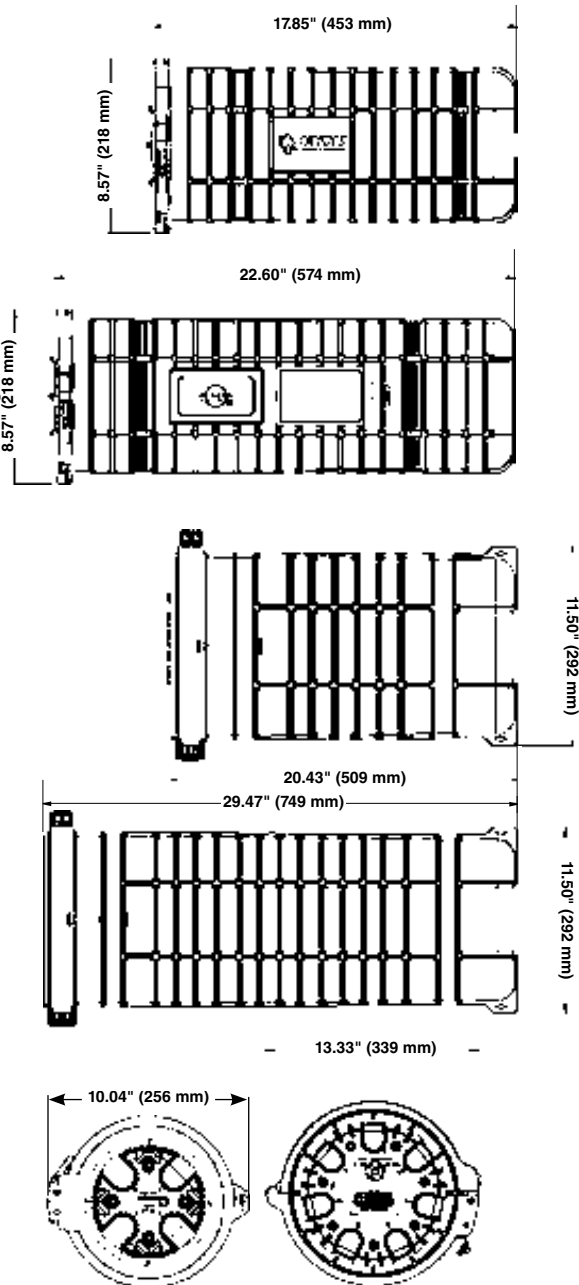


COYOTE® Dome Closures



The COYOTE® Dome closures have the versatility and features that make it a perfect choice for fiber-to-the-premise networks. Both the 6.5" and 9.5" dome closure designs use PLP's patented segmented end plate system which allows independent access to each cable port without disruption to surrounding cables.

Key Features

- Sizes:** 6.5" x 17" (218 mm x 453 mm)
 6.5" x 22" (218 mm x 574 mm)
 9.5" x 19" (292 mm x 509 mm)
 9.5" x 28" (292 mm x 749 mm)
- Max. Splice Capacity:**
 6.5" x 17": (144) Single Fusion (80809958 Tray), (216) Ribbon/Mass Fusion (LGSTR144 Tray)
 6.5" x 22": (240) Single Fusion (LGSTS72), (648) Ribbon/Mass Fusion (LGSTR216 Tray)
 9.5" x 19": (288) Single Fusion (80809958 Tray), (720) Ribbon/Mass Fusion (LGSTR144 Tray)
 9.5" x 28": (720) Single Fusion (LGSTS72), (1296) Ribbon/Mass Fusion (LGSTR216 Tray)
- Configuration:** Butt/Expressed Splice
- Port Quantity:** 4 in the 6.5" End Plate
 7 in the 9.5" End Plate
- Ground Stud Quantity:** 4 in the 6.5" End Plate
 7 in the 9.5" End Plate
- Application:** Direct buried, below grade, pole/wall mount or aerial
- Quick to assemble, no special tools required
- Tested in accordance to GR-771-CORE by an independent outside lab
- Available in flame retardant material
- Collar system allows for quick re-entry
- Segmented end plate design provides independent access to every cable
- Flexible grommet sealing technology supports a wide range and quantity of flat or round cable profiles. See grommet chart on page 3.
- Standard 6-1/2" Dome Kits provided with (2) 8003701 grommets. Customized kits available upon request.
- Standard 9-1/2" Dome Kits provided with (2) 8003692 grommets and (2) 8003693 grommets –customized kits available upon request.
- In-Line options available – Contact PLP for details



Independent Access



9.5" Segmented End Plate - 7 Port



Transition Tray for Ribbon Storage



6.5" x 22" Dome with 288ct Buffer Tube Expressed



9.5" x 28" Dome with Buffered Ribbon Cable Expressed



6.5" Dome End Plate Web Breakout










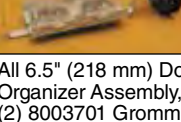
6.5" Segmented End Plate - 4 Port





End Plate w/Bobbin




COYOTE® Dome Closures

6.5" x 17" (218 x 453 mm) COYOTE Dome Closure Kits		
Organizer	Catalog No.	Description
	8006944	Dome Closure with Buffer Tube/Loose Tube Organizer
	8006945	Dome Closure with Unitube/Ribbon Organizer
	800012940	Flame Retardant Dome with Buffer Tube Organizer
	800012941	Flame Retardant Dome with Unitube/Ribbon Organizer









 
 
6.5" x 22" (218 x 574 mm) COYOTE Dome Closure Kits		
Organizer	Catalog No.	Description
	8006877	Dome Closure with Buffer Tube/Loose Tube Organizer
	8006878	Dome Closure with Unitube/Ribbon Organizer
	800012942	Flame Retardant Dome with Buffer Tube Organizer
	800012943	Flame Retardant Dome with Unitube/Ribbon Organizer

All 6.5" (218 mm) Dome Kits shown above include: (1) End Plate with Organizer Assembly, (1) Dome, (1) Gasket, (1) Small Parts Bag, (2) 8003701 Grommets and Cable Restraint Hardware

9.5" x 19" (292 x 509 mm) COYOTE Dome Closure Kits		
Organizer	Catalog No.	Description
	COYD919B-000	Dome Closure with Buffer Tube Organizer
	COYD919R-000	Dome Closure with Unitube/Ribbon Organizer

9.5" x 28" (292 x 749 mm) COYOTE Dome Closure Kits		
Organizer	Catalog No.	Description
	80061055	Dome Closure with Buffer Tube Organizer
	80061056	Dome Closure with Unitube/Ribbon Organizer
	80061057	Dome Closure with Max Tray Organizer (Buffer Tube/Loose Tube or Buffered Ribbon Applications)

All 9.5" (292 mm) Dome Kits shown above include: (1) End Plate with Organizer Assembly, (1) Dome, (1) Gasket, (1) Small Parts Bag, (2) 8003692 Grommets, (2) 8003693 Grommets and Cable Restraint Hardware

COYOTE Dome Closure Accessories					
Kit	Catalog No.	Description	Kit	Catalog No.	Description
	8003681	End Plate Kit for 6.5" (218 mm) Dome Closure		80808878	Large Strength Member Adapter Kit
	8003839	End Plate Kit for 9.5" (292 mm) Dome Closure		80808997	End Plate Gasket for 6.5" (218 mm) Dome Closures
	80808651	Long Strength Member Bracket Kit Includes 4 Brackets		80809045	End Plate Gasket for 9.5" (292 mm) Dome Closures
	80809205	Short Strength Member Bracket Kit Includes 2 Brackets		COYEP-FIX1	End Plate Assembly Fixture for 6.5" (218 mm) or 9.5" (292 mm) Dome Closures
	80811036	6 Port Drop Cable Retention Bobbin Kit		80811037	4 Port Cable Retention Bobbin Kit
Mounting Hardware	See Mounting Bracket Chart on page 26				



End Plate Assembly Fixture

Domes

- Re-Enterable
- Re-Usable
- Hermetically Sealed
- Free- Breathing
- Aerial
- Pole/Wall Mount
- Below Grade
- Direct Buried
- Flame Retardant