

2-conductor fuse terminal block; for miniature metric fuses; without indicator; 5 x 20 mm

Item No.: 282-122



2-conductor fuse terminal block; for miniature metric fuses; without indicator; 5 x 20 mm

Marking

RoHS ✓
Compliant

Business data

Supplier	WAGO
Item no.	282-122
EAN	4044918562027
Content	1
Order amount	40
Customer item number	

Notes

Technical data

Miscellaneous

Total number of connection points	2
Total number of potentials	2
Color	gray
Pollution degree (1)	3
Rated voltage EN (1) [V]	500 [V]
Rated surge voltage (1) [kV]	6 [kV]
Nominal current [A]	10 [A]
Connection technology (1)	CAGE CLAMP®
Cross section from (1) [mm²]	0.2 [mm²]

Technical data	
Cross section up to (1) [mm²]	6 [mm²]
Cross section from (1) [AWG]	24 [AWG]
Cross section up to (1) [AWG]	10 [AWG]
Stripped length from (1) [mm]	12 [mm]
Stripped length up to (1) [mm]	13 [mm]
Stripped length (1) [in]	0.49 [in]
Type of wiring	Side-entry wiring
Design	horizontal
Marking level	Side marking
Fire load [MJ]	0.536 [MJ]
Weight [g]	25.867 [g]
Width [mm]	13 [mm]
Width [in]	0.512 [in]
Height [mm]	54.5 [mm]
Height [in]	2.146 [in]
Length [mm]	62 [mm]
Length [in]	2.441 [in]
Type of mounting	DIN 35 rail

Approbation					
Item No.	Registration	Registration no.	Voltage [V]	Current [A]	Cross section [mm², AWG]
282-122	CCA	2160584.31	500		
282-122	CCA	NL5470	500	10	6
282-122	CCA	NTR NL-7135	500	10	
282-122	CSA	154112-1505033	250	10	24-10
282-122	KEMA	98.2759.05	500		6
282-122	KR	HMB05880-EL001	500/800	10/46	6
282-122	PRS	TE/1718/880590/08	500	10	6
282-122	UL	E45172	600	10	24-10

Accessories

Accessories

Jumper

Item no.	Description	Pack. unit (Sub Pack)
282-402	Adjacent jumper; insulated; nominal current 41 A	25
282-409	Alternate jumper; insulated; nominal current 41 A	25
282-424	Adjacent jumper; insulated; nominal current 41 A	25

End plate

Item no.	Description	Pack. unit (Sub Pack)
282-311	End and intermediate plate; 4 mm thick	25
282-312	End and intermediate plate; 4 mm thick	25

Carrier rail

Item no.	Description	Pack. unit (Sub Pack)
210-112	Steel carrier rail; 35 x 7.5 mm; 1 mm thick; 2 m long; slotted; according to en 60715; "Hole width 25 mm	1
210-113	Steel carrier rail; 35 x 7.5 mm; 1 mm thick; 2 m long; unslotted; according to en 60715	1
210-114	Steel carrier rail; 35 x 15 mm; 1.5 mm thick; 2 m long; unslotted; according to en 60715	1
210-115	Steel carrier rail; 35 x 7.5 mm; 1 mm thick; 2 m long; slotted; according to en 60715; "Hole width 18 mm	1
210-118	Steel carrier rail; 35 x 15 mm; 2.3 mm thick; 2 m long; unslotted; according to en 60715	1
210-196	Aluminum carrier rail; 35 x 8.2 mm; 1.6 mm thick; 2 m long; unslotted; according to en 60715	1
210-197	Steel carrier rail; 35 x 15 mm; 1.5 mm thick; 2 m long; slotted; according to en 60715	1
210-198	Copper carrier rail; 35 x 15 mm; 2.3 mm thick; 2 m long; unslotted; according to en 60715	1
210-504	Steel carrier rail; 35 x 7.5 mm; 1 mm thick; 2 m long; slotted; galvanized; according to EN 60715	1
210-505	Steel carrier rail; 35 x 7.5 mm; 1 mm thick; 2 m long; unslotted; galvanized; according to EN 60715	1
210-506	Steel carrier rail; 35 x 15 mm; 1.5 mm thick; 2 m long; unslotted; galvanized; ähnlich EN 60715	1
210-508	Steel carrier rail; 35 x 15 mm; 1.5 mm thick; 2 m long; slotted; galvanized; ähnlich EN 60715	1

Accessories

Marking accessories

Item no.	Description	Pack. unit (Sub Pack)
209-501	WSB quick marking system; plain; for terminal block width 5 - 17.5 mm; 10 strips with 10 markers per card	5
209-501/000-002	WSB quick marking system; plain; for terminal block width 5 - 17.5 mm; 10 strips with 10 markers per card	5
209-501/000-005	WSB quick marking system; plain; for terminal block width 5 - 17.5 mm; 10 strips with 10 markers per card	5
209-501/000-006	WSB quick marking system; plain; for terminal block width 5 - 17.5 mm; 10 strips with 10 markers per card	5
209-501/000-007	WSB quick marking system; plain; for terminal block width 5 - 17.5 mm; 10 strips with 10 markers per card	5
209-501/000-012	WSB quick marking system; plain; for terminal block width 5 - 17.5 mm; 10 strips with 10 markers per card	5
209-501/000-017	WSB quick marking system; plain; for terminal block width 5 - 17.5 mm; 10 strips with 10 markers per card	5
209-501/000-023	WSB quick marking system; plain; for terminal block width 5 - 17.5 mm; 10 strips with 10 markers per card	5
209-501/000-024	WSB quick marking system; plain; for terminal block width 5 - 17.5 mm; 10 strips with 10 markers per card	5
793-501	WMB Multi marking system; plain; for terminal block width 5 - 17.5 mm; 10 strips with 10 markers per card	5
793-501/000-002	WMB Multi marking system; plain; for terminal block width 5 - 17.5 mm; 10 strips with 10 markers per card	5
793-501/000-005	WMB Multi marking system; plain; for terminal block width 5 - 17.5 mm; 10 strips with 10 markers per card	5
793-501/000-006	WMB Multi marking system; plain; for terminal block width 5 - 17.5 mm; 10 strips with 10 markers per card	5
793-501/000-007	WMB Multi marking system; plain; for terminal block width 5 - 17.5 mm; 10 strips with 10 markers per card	5
793-501/000-012	WMB Multi marking system; plain; for terminal block width 5 - 17.5 mm; 10 strips with 10 markers per card	5
793-501/000-017	WMB Multi marking system; plain; for terminal block width 5 - 17.5 mm; 10 strips with 10 markers per card	5
793-501/000-023	WMB Multi marking system; plain; for terminal block width 5 - 17.5 mm; 10 strips with 10 markers per card	5

Accessories

793-501/000-024	WMB Multi marking system; plain; for terminal block width 5 - 17.5 mm; 10 strips with 10 markers per card	5
793-5501	WMB Multi marking system; plain; for terminal block width 5 - 17.5 mm; stretchable 5 - 5.2 mm; 10 strips with 10 markers per card	5
793-5501/000-002	WMB Multi marking system; plain; for terminal block width 5 - 17.5 mm; stretchable 5 - 5.2 mm; 10 strips with 10 markers per card	5
793-5501/000-005	WMB Multi marking system; plain; for terminal block width 5 - 17.5 mm; stretchable 5 - 5.2 mm; 10 strips with 10 markers per card	5
793-5501/000-006	WMB Multi marking system; plain; for terminal block width 5 - 17.5 mm; stretchable 5 - 5.2 mm; 10 strips with 10 markers per card	5
793-5501/000-007	WMB Multi marking system; plain; for terminal block width 5 - 17.5 mm; stretchable 5 - 5.2 mm; 10 strips with 10 markers per card	5
793-5501/000-012	WMB Multi marking system; plain; for terminal block width 5 - 17.5 mm; stretchable 5 - 5.2 mm; 10 strips with 10 markers per card	5
793-5501/000-017	WMB Multi marking system; plain; for terminal block width 5 - 17.5 mm; stretchable 5 - 5.2 mm; 10 strips with 10 markers per card	5
793-5501/000-023	WMB Multi marking system; plain; for terminal block width 5 - 17.5 mm; stretchable 5 - 5.2 mm; 10 strips with 10 markers per card	5
793-5501/000-024	WMB Multi marking system; plain; for terminal block width 5 - 17.5 mm; stretchable 5 - 5.2 mm; 10 strips with 10 markers per card	5

Protective warning marker


Item no.	Description	Pack. unit (Sub Pack)
282-405	Protective warning marker; with high-voltage symbol, black; for 5 terminal blocks	25



Accessories

General accessory

Item no.	Description	Pack. unit (Sub Pack)
209-100	Collective carrier for adjacent jumpers; suitable for 279 to 284 Series adjacent jumpers, 215 Series banana plugs	25
209-106	Mounting carrier; for isolated mounting on DIN 35 rails	25
209-143	Group marker carrier; e.g., for 282 Series 2- and 3-conductor terminal blocks; straight	25
209-144	Group marker carrier; e.g., for 282 Series transformer terminal blocks; angled	25
209-170	Test plug adapter; 8.3 mm wide; for test plug 4 mm Ø; suitable for 1.5 mm ² - 10 mm ² terminal blocks	25
209-196	Spare fixing/retaining screw; for cover	25
210-141	Operating pliers; for 281, 282, 283, 284 Series side-entry rail-mounted terminal blocks	1
210-182	Stickers for operating instructions; for side-entry rail-mounted terminal blocks; 279 to 284 Series	100
210-549	Spare knurled nut; for cover	25
210-721	Operating tool with partially insulated shaft; Type 3, blade (5.5 x 0.8) mm; suitable for 282, 283, 284, 285, 782, 783, 784, 785, 2006, 2010 and 2016 Series	1
249-105	Pivoting group marker carrier	25
281-407	Test plug; 6 mm wide; nominal current 24 A; for 0.08 mm ² - 2.5 mm ²	25
282-451	Miniature metric fuse; without indicator; 5 x 20 mm; medium-slow	10
709-153	Cover; type 1; suitable for cover carrier, type 1; 1 m long	10

Images & drawings

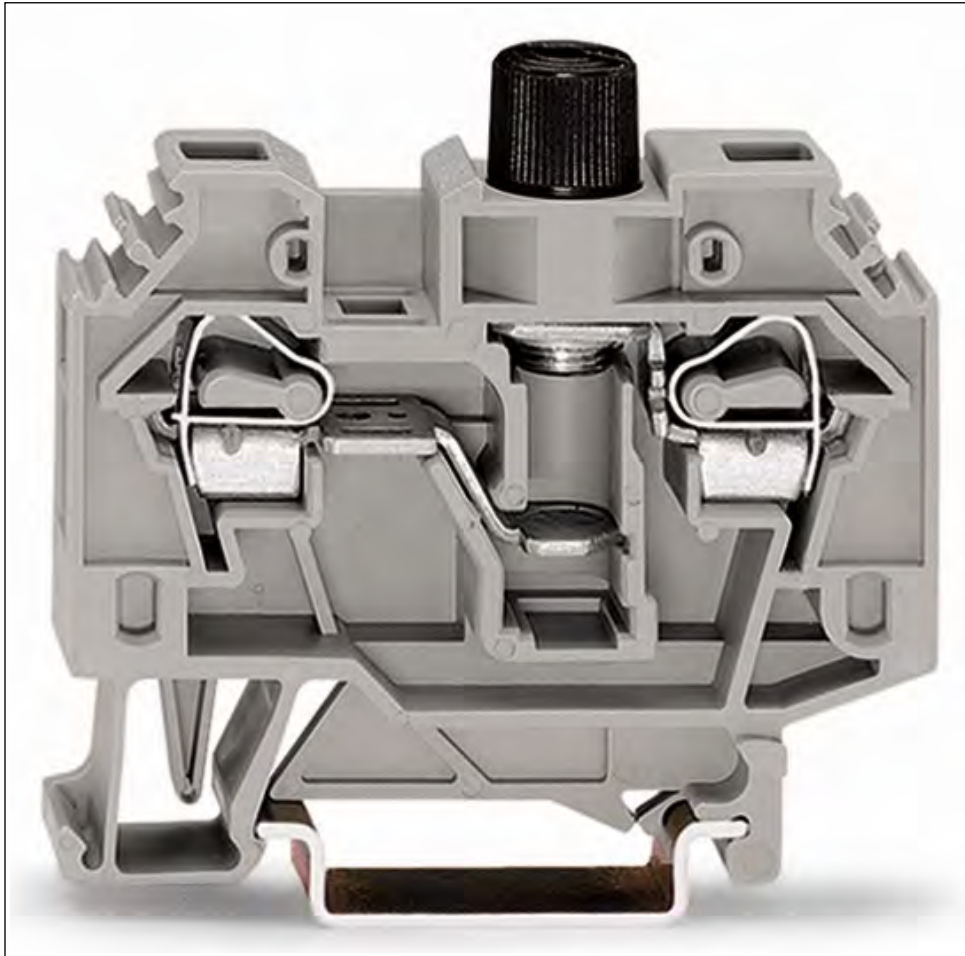

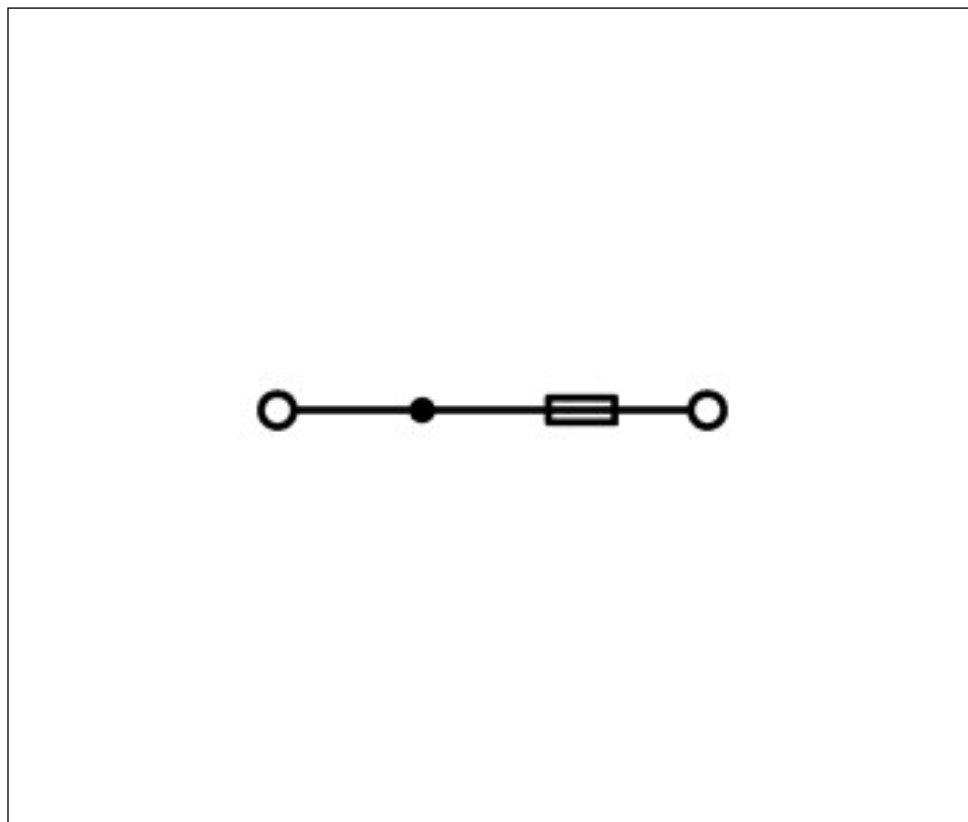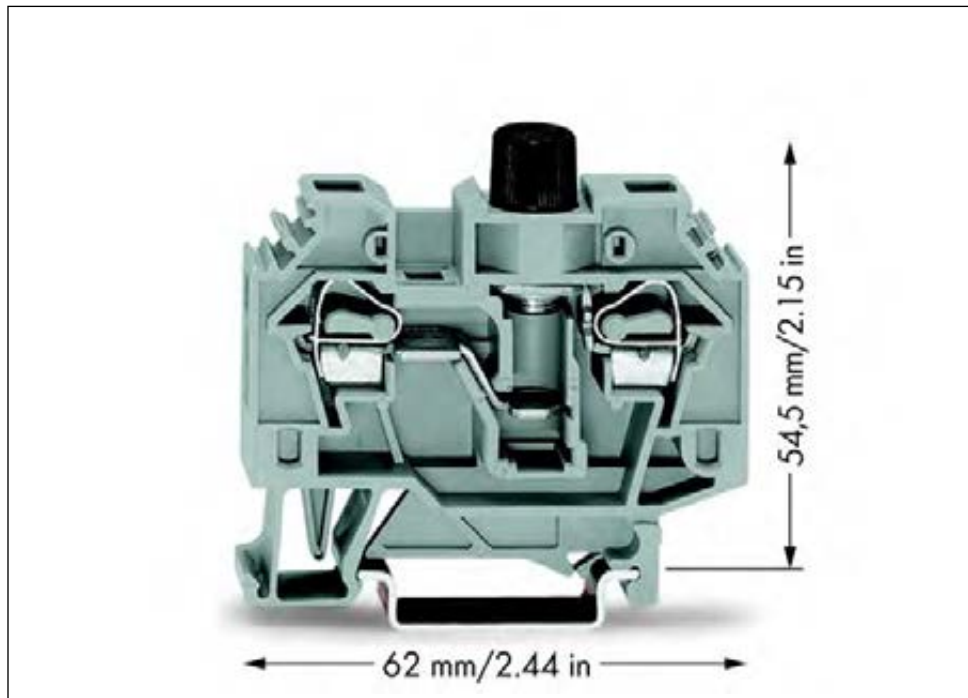

Address

WAGO Kontakttechnik GmbH & Co. KG

Hansastr. 27

32423 Minden

Telefon: 0571/887-0

Fax: 0571/887-169

<http://www.wago.com>

© WAGO Kontakttechnik GmbH & Co. KG

Technische Änderungen und Irrtümer vorbehalten.