

Interface module; with D-subminiature female connector; 9-pole

Item No.: 289-725



Interface module; with D-subminiature female connector; 9-pole

Marking

RoHS ✓
Compliant

Business data

Supplier	WAGO
Item no.	289-725
EAN	4045454371227
Content	1
Order amount	1
Customer item number	

Notes

Technical data

Miscellaneous


No. of Poles	9
Pollution degree (1)	2
Rated voltage EN (1) [V]	125 [V]
Rated surge voltage (1) [kV]	0.8 [kV]
Wire connection	WAGO 736 Series
Operating voltage	125 V AC / DC
Nominal current [A]	2 [A]
Ambient operating temperature	-20 °C ... +50 °C
Connector contact	plating, 0.5 µm ... 0.8 µm Au over 2 µm Ni
Contact resistance [m]	10 [m]

Technical data	
Performance level	2 / 200 mating cycles
Mounting direction	vertical
Pull relief stud bolt	UNC 4-40
Connection technology (1)	CAGE CLAMP®
Cross section from (1) [mm²]	0.08 [mm²]
Cross section up to (1) [mm²]	2.5 [mm²]
Cross section from (1) [AWG]	28 [AWG]
Cross section up to (1) [AWG]	12 [AWG]
Stripped length from (1) [mm]	5 [mm]
Stripped length up to (1) [mm]	6 [mm]
Stripped length (1) [in]	0.22 [in]
Weight [g]	50.6 [g]
Width [mm]	33.5 [mm]
Width [in]	1.319 [in]
Height [mm]	48 [mm]
Height [in]	1.89 [in]
Length [mm]	85 [mm]
Length [in]	3.346 [in]
Storage temperature	-40 °C ... +70 °C
Type of mounting	DIN 35 rail

Accessories

Marking accessories		
Item no.	Description	Pack. unit (Sub Pack)
709-196	Marking strips; plain; 7.5 mm wide; 1 m long; for center marking - group marking; transparent	1

Images & drawings

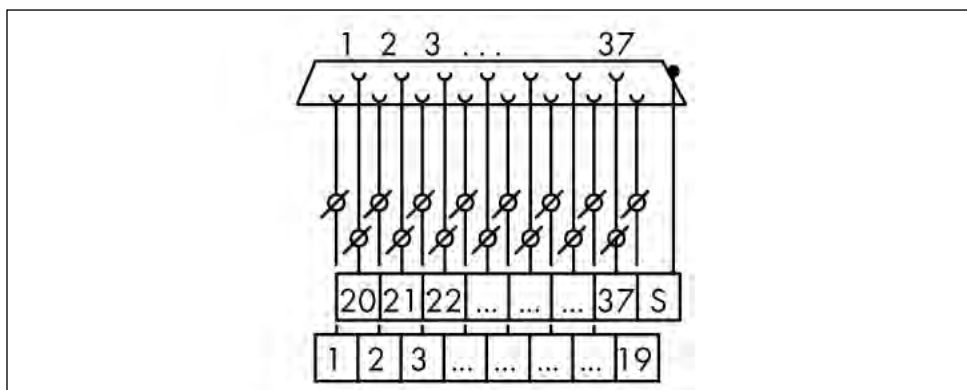

Address

WAGO Kontakttechnik GmbH & Co. KG

Hansastr. 27

32423 Minden

Telefon: 0571/887-0

Fax: 0571/887-169

<http://www.wago.com>

© WAGO Kontakttechnik GmbH & Co. KG

Technische Änderungen und Irrtümer vorbehalten.