



A STATIONARY SHELVES

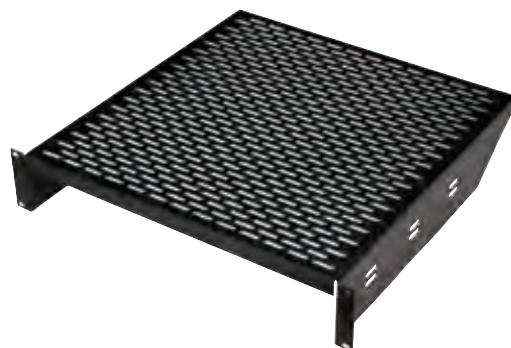

PART NO. 7206-BT
DESCRIPTION Dimensions 17" x 20.75";
 Weight Capacity 300 lbs.; 3 RMU
 Maximum Tab Placement 25.250"




PART NO. 7206-FM
DESCRIPTION Dimensions 17.25"W X 18"D;
 Weight Capacity 60 lbs. ; 2 RMU

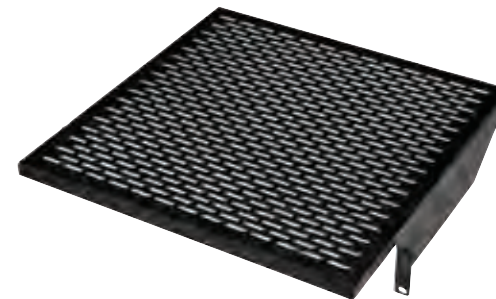

PART NO. 7206-EIA
DESCRIPTION Dimensions 17.468"W x 18"D;
 Weight Capacity 80 lbs. ; 2 RMU

7206-14
 Dimensions 17.5"W x 14"D;
 Weight Capacity 80 lbs.; 2 RMU

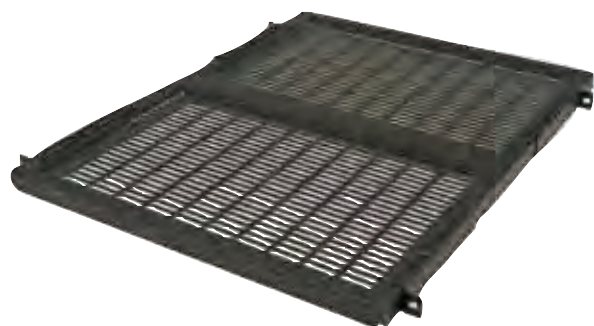

PART NO. 7206-FR-A18
DESCRIPTION Dimensions 17.5"W x 18"D;
 Weight Capacity 150 lbs.; 1 RMU
 Maximum Tab Placement 21.5"

7206-FR-AHD
 Dimensions 17.5"W x 22.25"D;
 Weight Capacity 200 lbs.; 1 RMU
 Maximum Tab Placement 26.125"

7206-FR-ADHD
 Dimensions 17.5"W x 27.25"D;
 Weight Capacity 150 lbs.; 1 RMU
 Maximum Tab Placement 32.25"

7206-FR-A28HD
 Dimensions 17.5"W x 28"D;
 Weight Capacity 300 lbs.; 1 RMU
 Maximum Tab Placement 30.18"

7206-FR-A32HD*
 Dimensions 17.5"W x 32"D;
 Weight Capacity 300 lbs.; 1 RMU
 Maximum Tab Placement 36"

* Fits in 36"D Enclosure

