


R 2 POST RACKS

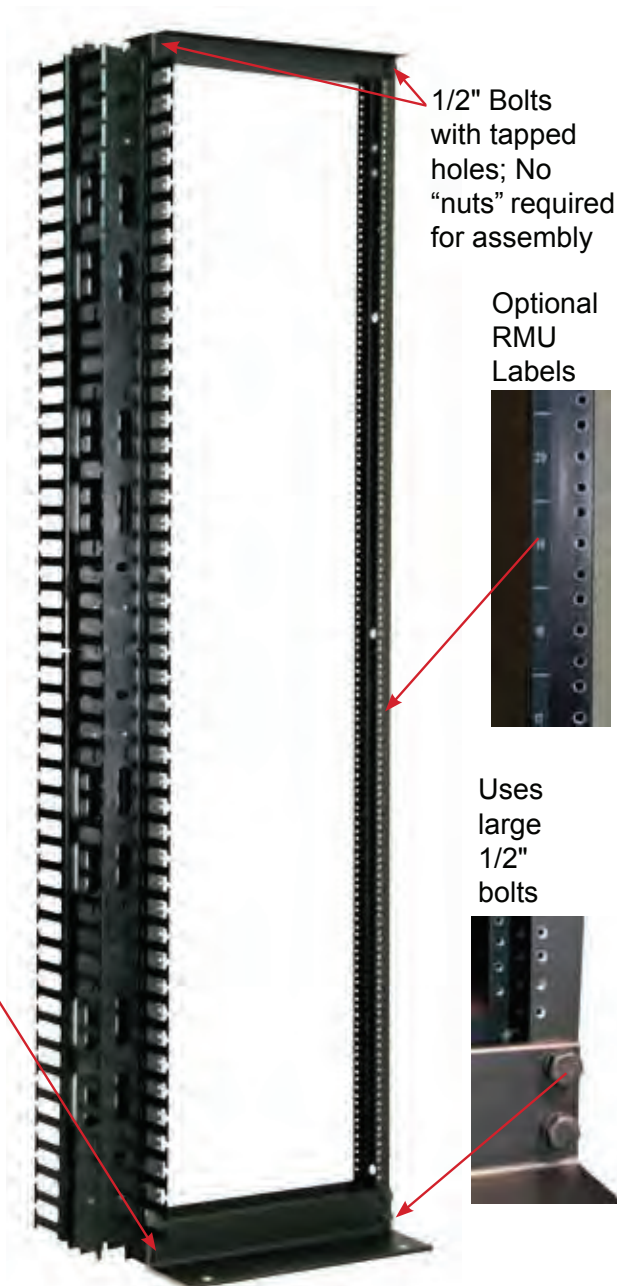

1/2" Bolts
with tapped
holes; No
"nuts" required
for assembly

Optional
RMU
Labels



Uses
large
1/2"
bolts



Tapped
holes
No "nuts"
required
for assembly



Shown with optional accessories

DIMENSIONS: 84"H x 20.31"W x 14"D

RACK SPACES: 45 RMU • 19" EIA 310-D Compliant; 23" mounting is available; contact Great Lakes for more information

WEIGHT CAPACITY: 1500 lbs.

CONSTRUCTION: Double sided extruded aluminum with #12-24 tapped holes

SHIPPING WEIGHT AND CARTON SIZE: 30 lbs./86"L x 6"W x 4"H

| PART NO. | DESCRIPTION |
|-----------------|--------------------------------------------------------------------------------------------------------|
| GLRR-1984BA-5FO | 2 Post Rack with 5" Vertical Front Cable Management; includes mounting hardware; black anodized finish |
| GLRR-1984BA-5FR | Same as above except with 5" Vertical Front and Rear Cable Management |
| GLRR-1984BA-8FO | Same as above except with 8" Vertical Front Cable Management (includes cover) |
| GLRR-1984BA-8FR | Same as above except with 8" Vertical Front and Rear Cable Management (includes cover) |
| GLRR-1984 | 2 Post Rack with mounting hardware; mill finish |
| GLRR-1984BA | 2 Post Rack with mounting hardware; black anodized finish |

ACCESSORIES

| PART NO. | DESCRIPTION |
|------------|-----------------------------------------------------------------------------------------------------------------|
| 7215 | 16 position, 15 amp Power Strip; 5-15R receptacle and 5-15P plug; requires PSBGLRR |
| 7219 | 6 position Power Strip for 19" mounting; 5-15R receptacle and 5-15P plug |
| 7219-SR14 | 14 position (6 front/8 back) Power Strip for 19" mounting; 5-15R receptacle and 5-15P plug with surge protector |
| PSBGLRR | Vertical Power Strip Mounting Bracket |
| 1984-VCM10 | 7'H x 10"D Double-sided Vertical Cable Manager with 6"W x 5"D cable runs |
| CM-07 | Waterfall Cable Management Trough |
| 7206-EIA | Stationary Shelf, 17.468"W x 18"D, 80 lb. weight capacity |
| 7206-14 | Stationary Shelf, 17.50"W x 14"D, 80 lb. weight capacity |
| 7206-SL | Sliding Shelf, 16.343"W x 17.5"D, 40 lb. weight capacity |
| GL-RMUTA | Package of 4 RMU Labels in ascending order (1 on the bottom, 45 on the top) |
| GL-RMUTD | Package of 4 RMU Labels in descending order (1 on the top, 45 on the bottom) |