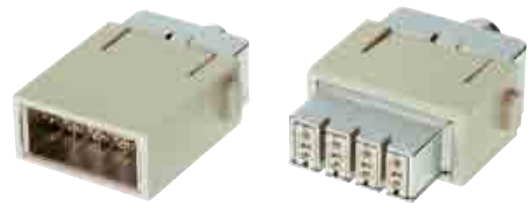

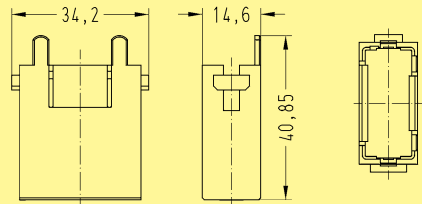
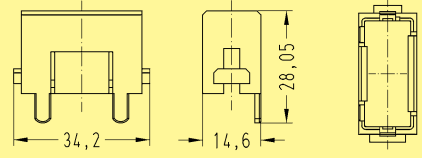



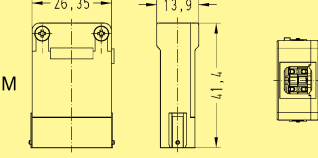
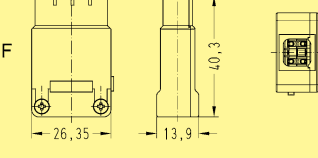
Number of contacts

8



Identification	Part number		Drawing	Dimensions in mm
	Male insert (M)	Female insert (F)		
Module 	09 14 001 3011	09 14 001 3111	M  F 	

Han Modular

Identification	Wire gauge (mm ²)	Part number		Drawing	Dimensions in mm												
		Male contact	Female contact														
Han® GigaBit insert 8 + shielding Order crimp contacts separately 		09 14 008 3011	09 14 008 3111	M  F 													
D-Sub crimp contacts				<table border="1"> <thead> <tr> <th colspan="2">Wire gauge</th> <th>Stripping length</th> </tr> </thead> <tbody> <tr> <td>0,08-0,21 mm²</td> <td>AWG 28-24</td> <td>4 mm</td> </tr> <tr> <td>0,13-0,33 mm²</td> <td>AWG 26-22</td> <td>4 mm</td> </tr> <tr> <td>0,21-0,52 mm²</td> <td>AWG 24-20</td> <td>4 mm</td> </tr> </tbody> </table>		Wire gauge		Stripping length	0,08-0,21 mm ²	AWG 28-24	4 mm	0,13-0,33 mm ²	AWG 26-22	4 mm	0,21-0,52 mm ²	AWG 24-20	4 mm
Wire gauge		Stripping length															
0,08-0,21 mm ²	AWG 28-24	4 mm															
0,13-0,33 mm ²	AWG 26-22	4 mm															
0,21-0,52 mm ²	AWG 24-20	4 mm															
	0,08-0,21 0,13-0,33 0,21-0,52	09 67 000 7576 09 67 000 5576 09 67 000 8576	09 67 000 7476 09 67 000 5476 09 67 000 8476														

06
93

Stock items in bold type