

HT7246H 2.8 -12mm DC auto iris varifocal lens, dark grey housing


Features

- 700 lines of color resolution
- Amplify existing light with no distance limitations
- No problems caused by objects that reflect or absorb IR light sources
- Heater circuitry eliminates fog or condensation under any weather condition
- Minimum illumination 0.00002 lux (Intensify @ 512x)
- Chameleon Cover™: snaps on and can be painted to match any décor!*
- 12VDC / 24VAC dual voltage operation
- Full OSD operation
- 3 axis lens mount
- Vandal resistant operation
- Weather resistant operation
- IP66 compliant
- Relay outputs for motion detection
- 5 year warranty

Now with Presets:
Outdoor, Indoor, Elevator,
Lobby, Hallway & Dark



Shown with included paintable, snap-on Chameleon Cover™

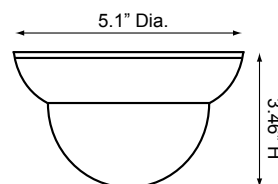

Specifications

Image Sensor	1/3" 960H Sony Super-HAD™ CCD
Resolution.....	700 TV lines
Minimum Illumination.....	CDS Off: 0.15 lux CDS On: 0.00002 lux
Total Pixels	1020 (H) x 508 (V)
Effective Pixels	976 (H) x 494 (V)
TV System.....	NTSC
Scanning Frequency.....	15.734kHz (H) & 59.94Hz (V)
Scanning System.....	2:1 interlace
Synchronization.....	Internal
S/N Ratio	More than 52dB
Video Output.....	CVBS: 1.0Vp-p / 75 Ohm
Electronic Shutter Speed.....	1/60 sec. – 1/120,000 sec.
OSD.....	Available
WDR.....	On / Off (level adjustable)
Backlight Compensation.....	BLC / HLC / Off
Day/Night.....	Color / BW / Auto / Ext
AGC.....	High / Low / Off
White Balance	ATW / Outdoor / Indoor / Manual / AWC (1,700°K – 11,000°K)
Intensify	Auto / Off (selectable x2 – x512)
Motion Detection.....	On / Off (8 programmable zones)

Privacy Masking	On / Off (12 programmable zones)
Speco DNR.....	On / Off (level adjustable)
Digital Zoom	On / Off (1x - 16x)
DIS.....	On / Off
Sharpness	On / Off (level adjustable)
Flip / Mirror	On / Off
Power Supply	12VDC / 24VAC dual voltage operation (power supply not included)
Power Consumption	12VDC, 380mA / 24VAC, 170mA
Operating Temperature.....	-4° F – 140° F
Dimensions.....	3.46" (H) x 5.1" (Dia.)
Weight	1 lb.

Optional Accessories



* Chameleon Cover™ - for best results when used outdoors, waterproof paint is recommended.

Speco Technologies is constantly developing and improving products.

We reserve the right to modify product design and specifications without notice and without incurring any obligation.



Rev. 6/28/13

For more information contact Speco Technologies

200 New Highway, Amityville, NY 11701 • Toll Free: 1-800-645-5516 • Fax: 631-957-9142 or 631-957-3880

www.specotech.com