

VIP2P1 3.7mm fixed lens



Features:

- Supports up to Full HD 1080p @ 30fps
- Built-in standard PoE (IEEE 802.3af)
- Supports H.264, MPEG4, and MJPEG codecs
- Micro SD card slot (card not included)
- Multiple web browser support
- ONVIF Profile S listed*
- 2 year warranty

Camera Specifications

Image Sensor	Progressive scan 1/2.8" CMOS, 2.0M pixels
Maximum Resolution	1920x1080
Minimum Illumination	F1.8, 1.6 lux
IR LEDs	N/A
IR Range	N/A
White Balance	Automatic, Incandescent, Fluorescent, Outdoor
Exposure Control	Yes
Digital Slow Shutter	Yes
WDR/BLC	BLC
Day/Night	Digital
DNR	2D

Video Specifications

Supported Resolutions	1920x1080, 1280x1024, 1280x720, 704x576, 704x480, 640x480, 352x288, 352x240, 320x240 @ 30fps
----------------------------	--

Compression	H.264 (HP/MP/BP), MPEG4 (SP), MJPEG
Bitrate Control	VBR, CBR
Multiple Streaming	3 simultaneous profiles

Audio Specification


Mono Input	N/A
Mono Output	N/A

External Terminal Specification

Ethernet	10/100 Mbps
Alarm	1 sensor input, 1 output
Video	Analog output (3.5mm)
Audio	N/A
Power	DC Jack
Storage	Micro SD card slot



VIP series

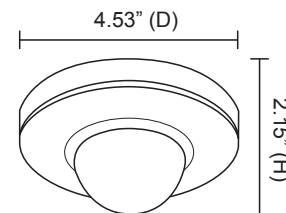

Network Specifications

Protocols	IPv4, IPv6, TCP, UDP, ARP, RTCP, RTP, RTSP, HTTP, HTTPS, SMTP, FTP, DHCP, UPnP, QoS, Zeroconf, Bonjour
DDNS Support	Speco DDNS (free of charge)
Security	User ID & Password protection, IP address filtering, HTTPS
User Access	10 simultaneous users Performance may vary depending on resolution and number of connections

System Specifications

PoE	Standard (IEEE 802.3af)
Analytics	Motion detection (8 regions)
Alarm Triggers	Motion, sensor input, on boot, network loss, manual
Alarm Events	FTP video file upload, email image upload, micro SD card recording, HTTP server, alarm out, boost
Video Buffer	Configurable pre-record & post-record
Image Settings	Privacy Mask

Client Specifications

Web Browser Support	Windows (Internet Explorer 8 and up, Chrome, Firefox)
Mobile Apps	Speco VIP (iOS®, Android™)
PC Application	Speco VMS, Secure Guard®

Operating & Unit Specifications

Power Supply	PoE, 12VDC (power supply not included)
Power Consumption	PoE, 93mA / 12VDC, 375mA
Operating Temperature	14° F – 104° F
Operating Humidity	0% – 80% RH
Unit Dimensions	2.15" (H) x 4.53" (D)
Unit Weight	8.5 oz.
Certifications	FCC, RoHS
Included in Package	Unit, CD (manual, software), mounting template sheet, mounting screws, alarm cable

Optional Accessories



IPPOEINJ1295
PoE Injector



PSW5
12VDC
Power Supply



VIPRC
Remote Control

*visit www.specotech.com/onvif.html for latest ONVIF support

iPhone is a trademark of Apple Inc., registered in the U.S. and other countries. Android is a trademark of Google Inc.

Speco Technologies is constantly developing and improving products.

We reserve the right to modify product design and specifications without notice and without incurring any obligation.



Rev. 10/15/13

For more information contact Speco Technologies

200 New Highway, Amityville, NY 11701 • Toll Free: 1-800-645-5516 • Fax: 631-957-9142 or 631-957-3880
www.specotech.com