

OIPC72B7G 4.3mm fixed lens, dark grey housing

Features

- Dual-codec (H.264 & MJPEG)
- Multi-profile streaming (up to 3 streams of different resolutions, frame rates and codec selections)
- Robust design
- Convenient installations
- ONVIF support*
- 2 year warranty

Camera Specifications


Image Sensor	1/3" CMOS
Resolution.....	420 TV lines
Minimum Illumination.....	0.2 lux (30 IRE)
Total Pixels	720 (H) x 480 (V)
Electronic Shutter	1/60 sec. – 1/600,000 sec.
Scanning System.....	2:1 interface
Synchronization.....	Internal
S/N Ratio	46dB
S/N (Y Signal).....	52dB (AGC off, weight on)
White Balance	AWB

Video Specifications

Compression Method	Simultaneous dual-codec (H.264 & MJPEG)
Resolution.....	704 x 480 (full D1), 640 x 480 (VGA), 704 x 240 (half D1), 352 x 240 (CIF), 176 x 112 (QCIF)
Multi-Profile Streaming	3 simultaneous video profiles
Intelligent Bit-Rate Control..	CBR, VBR
Motion Detection.....	3 regions

Network Specifications

Network Protocol	IPv4/v6, TCP, UDP, IGMP, ICMP, ICMPv6, ARP, RARP, PPPoE, RTCP, RTP, RTSP, SDP, HTTP, HTTPS, SMTP, FTP, DHCP, UPnP, SNMP NTP, DNS, DynDNS, SOCKS
Security.....	User ID & password protection, IP address filtering, HTTPS encryption, digest authentication, user access log, 802.1x support
Speco DDNS	Supported (free of charge)

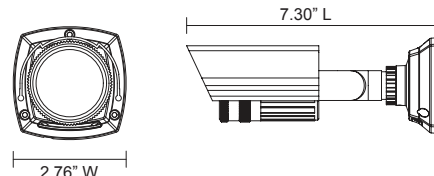

User Access

8 concurrent users on D1 resolution
Depending on resolution, number of users may vary

External Terminals

LAN.....	10/100BaseT LAN (auto MDIX)
Alarm Input	1 sensor input

System Integration

Intelligent Video	Motion detection
Alarm Triggers	Sensor input

Client Software

Speco NVR.....	64 ch (free of charge)
----------------	------------------------

Operating Environment, Power, Dimensions

Operating Temperature/	
Humidity.....	-4° F – 122° F / 8% – 80% RH
Power Supply	12VDC (power supply not included)
Power Consumption	300mA
Dimensions.....	2.76" (W) x 7.30" (L)
Weight	14.56 oz.
Housing	Aluminum, dark grey
Approvals.....	FCC, CE, MIC, RoHS
Included in Package	IP camera, CD (user's guide, software), accessories for installation
iPhone® / Android™ App....	Speco OnSIP

Optional Accessory



*visit www.specotech.com/onvif.html for latest ONVIF support

iPhone & iPad are trademarks of Apple Inc., registered in the U.S. and other countries. Android is registered to Google.

Speco Technologies is constantly developing and improving products.

We reserve the right to modify product design and specifications without notice and without incurring any obligation.



Rev. 2/26/13

For more information contact Speco Technologies

200 New Highway, Amityville, NY 11701 • Toll Free: 1-800-645-5516 • Fax: 631-957-9142 or 631-957-3880
www.specotech.com