




VL62 4mm lens, black housing
VL62W 4mm lens, white housing

Features

- Color Day/Night camera
- Built-in 4mm lens
- 12 IR LEDs with 60' range (depending on scene reflection)
- Weather resistant operation
- 12VDC power supply included
- 5 year warranty

Specifications

Image Sensor 1/3" Sony Super-HAD™ II CCD
Resolution..... 650 TV lines
Minimum Illumination..... 0 lux with IR on, 0.001 lux IR off
Total Pixels 976 (H) x 494 (V)
Number of IR LEDs 12
IR LED Wavelength 850nm
IR Range 60' (depending on scene reflection)
Electronic Shutter Speed..... 1/60 sec. – 1/1,000,000 sec.
Video S/N Ratio More than 52dB
Gamma..... 0.45 typ.
Video Signal Output..... 1.0Vp-p / 75 Ohms
Scanning System..... 2:1 Interlace
Synchronization Internal
Backlight Compensation..... Yes
AGC..... Yes
Operating Temperature/
Humidity..... -4° F – 122° F / 20% – 90% RH
Storage Temperature..... -13° F – 158° F
Power Consumption LED off (90mA)
LED on (160mA)
Power Supply 12VDC (power supply included)
Housing Plastic
Dimensions..... 4.37" (L) x 2.46" (W) x 2.05" (Dia.)
Weight 8.8 oz.
Included in Package Mounting bracket

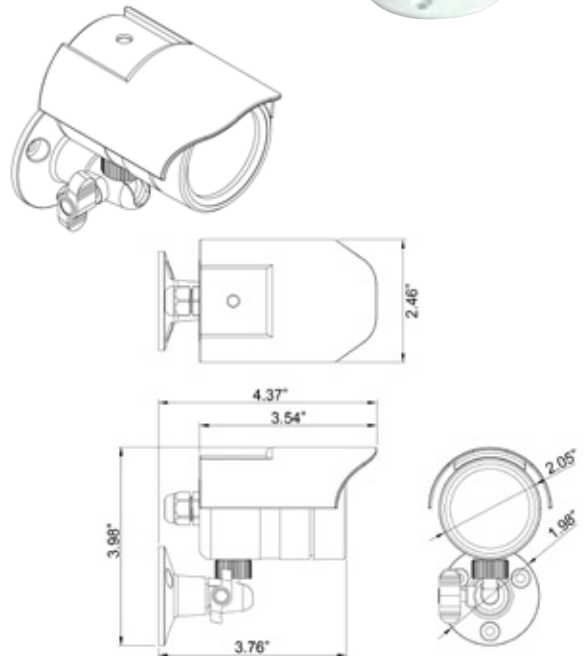

Speco Technologies is constantly developing and improving products.

We reserve the right to modify product design and specifications without notice and without incurring any obligation.

Rev. 2/22/13

For more information contact Speco Technologies

200 New Highway, Amityville, NY 11701 • Toll Free: 1-800-645-5516 • Fax: 631-957-9142 or 631-957-3880
www.specotech.com