

HT7246iHR	2.8 -12mm DC auto iris varifocal lens, dark grey housing
HT7247iHR	9 - 22mm DC auto iris varifocal lens, dark grey housing
HT7250iHR	5 - 50mm DC auto iris varifocal lens, dark grey housing


Features

- 1/3" Sony Super-HAD II™ CCD
- 650 lines of color resolution
- Amplify existing light with no distance limitations
- No problems caused by objects that reflect or absorb IR light sources
- Heater circuitry eliminates fog or condensation under any weather condition
- Minimum illumination 0.00002 lux (Intensifier3™ @ 512x)
- Chameleon Cover™: snaps on and can be painted to match any décor!*
- 12VDC / 24VAC dual voltage operation
- Full OSD operation
- 3 axis lens mount
- Vandal resistant operation
- Weather resistant operation
- IP66 compliant
- Relay outputs for motion detection
- 5 year warranty

Now with Presets:
Outdoor, Indoor, Elevator,
Lobby, Hallway & Dark



Shown with included
paintable, snap-on
*Chameleon Cover™

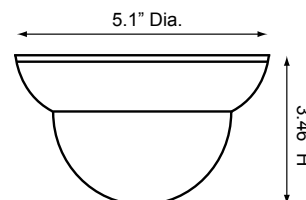

Specifications

Image Sensor	1/3" Sony Super-HAD II™ CCD
Resolution	650 TV lines
Minimum Illumination	CDS Off: 0.15 lux CDS On: 0.00002 lux
Total Pixels	811 (H) x 508 (V)
Effective Pixels	768 (H) x 494 (V)
TV System	NTSC, PAL
Scanning Frequency	15.734kHz (H) & 59.94Hz (V)
Scanning System	2:1 interlace
Synchronization	Internal
S/N Ratio	More than 52dB
Video Output	CVBS: 1.0Vp-p / 75 Ohm
Electronic Shutter Speed	1/60 sec. - 1/120,000 sec.
OSD	Available
WDR	On / Off (level adjustable)
Backlight Compensation	BLC / HLC / Off
Day/Night	Color / BW / Auto
AGC	High / Low / Off
White Balance	ATW / Outdoor / Indoor / Manual / AWC (1,700°K - 11,000°K)
Intensifier3™	Auto / Off (selectable x2 - x512)

Motion Detection	On / Off (8 programmable zones)
Privacy Masking	On / Off (12 programmable zones)
Speco DNR	On / Off (level adjustable)
Digital Zoom	On / Off (1x - 16x)
DIS	On / Off
Sharpness	On / Off (level adjustable)
Flip / Mirror	On / Off
Power Supply	12VDC / 24VAC dual voltage operation (power supply not included)
Power Consumption	12VDC, 380mA / 24VAC, 170mA
Operating Temperature	-4° F - 140° F
Dimensions	3.46" (H) x 5.1" (Dia.)
Weight	1 lb.

Optional Accessories



INTPM
Pendant
Mount



CVCJBD
Dome Camera
Junction Box



INTWM
Wall Mount



DFM
Tile Ceiling Flush
Mount Accessory



PSW4
24VAC
Power Supply



PSW5
12VDC
Power Supply

* Chameleon Cover™ - for best results when used outdoors, waterproof paint is recommended.

Speco Technologies is constantly developing and improving products.

We reserve the right to modify product design and specifications without notice and without incurring any obligation.



Rev. 6/28/13

For more information contact Speco Technologies

200 New Highway, Amityville, NY 11701 • Toll Free: 1-800-645-5516 • Fax: 631-957-9142 or 631-957-3880
www.specotech.com