

VIP2P1N 3.7mm fixed lens



Features:

- Supports up to Full HD 1080p @ 30fps
- Built-in standard PoE (IEEE 802.3af)
- Supports WiFi network connection (IEEE 802.11b/g/n)
- Supports H.264, MPEG4, and MJPEG codecs
- Micro SD card slot (card not included)
- Multiple web browser support
- ONVIF Profile S listed*
- 2 year warranty

Camera Specifications

Image Sensor	Progressive scan 1/2.8" CMOS, 2.0M pixels
Maximum Resolution	1920x1080
Minimum Illumination....	F1.8, 1.6 lux
IR LEDs	N/A
IR Range	N/A
White Balance	Automatic, Incandescent, Fluorescent, Outdoor
Exposure Control.....	Yes
Digital Slow Shutter	Yes
WDR/BLC	BLC
Day/Night.....	Digital
DNR.....	2D

Video Specifications

Supported Resolution ...	1920x1080, 1280x1024, 1280x720, 704x576, 704x480, 640x480, 352x288, 352x240, 320x240 @ 30fps
Compression	H.264 (HP/MP/BP), MPEG4 (SP), MJPEG
Bitrate Control.....	VBR, CBR
Multiple Streaming.....	3 simultaneous profiles


Audio Specifications

Mono Input.....	N/A
Mono Output.....	N/A

External Terminal Specifications

Ethernet	10/100 Mbps
Alarm	1 sensor input, 1 output
Video	Analog output (3.5mm)
Audio	N/A
Power	DC jack
Storage.....	Micro SD slot

VIP series

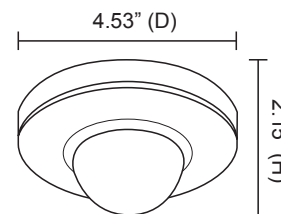

Network Specifications

Protocols.....	IPv4, IPv6, TCP, UDP, ARP, RTCP, RTP, RTSP, HTTP, HTTPS, SMTP, FTP, DHCP, UPnP, QoS, Zeroconf, Bonjour
WiFi	IEEE 802.11b/g/n
DDNS Support.....	Speco DDNS (free of charge)
Security.....	User ID & password protection, IP address filtering, HTTPS
User Access.....	10 simultaneous users Performance may vary depending on resolution and number of connections

System Specifications

PoE.....	Standard (IEEE 802.3af)
Analytics	Motion detection (8 regions)
Alarm Triggers	Motion, sensor input, on boot, network loss, manual
Alarm Events	FTP video file upload, email image upload, micro SD card recording, HTTP server, alarm out, boost
Video Buffer	Configurable pre-record & post-record
Image Settings.....	Privacy mask

Client Specifications

Web Browser Support	Windows (Internet Explorer 8 and up, Chrome, Firefox)
Mobile Apps	Speco VIP (iOS®, Android™)
PC Application	Speco VMS, Secure Guard®

Operating & Unit Specifications

Power Supply	PoE, 12VDC (power supply not included)
Power Consumption	PoE, 93mA / 12VDC, 375mA
Operating Temperature..	14° F – 104° F
Operating Humidity.....	0% – 80% RH
Unit Dimensions	2.15" (H) x 4.53" (D)
Unit Weight	8.5 oz.
Certifications.....	FCC, RoHS
Included in Package	Unit, CD (manual, software), mounting template sheet, mounting screws, alarm cable

Optional Accessories



IPPOEINJ1295
PoE Injector



PSW5
12VDC
Power Supply



VIPRC
Remote Control

*visit www.specotech.com/onvif.html for latest ONVIF support

iPhone is a trademark of Apple Inc., registered in the U.S. and other countries. Android is a trademark of Google Inc.

Speco Technologies is constantly developing and improving products.

We reserve the right to modify product design and specifications without notice and without incurring any obligation.

