

 
 
Circular connector M12 shielded, D-coded acc. to IEC 61076-2-101





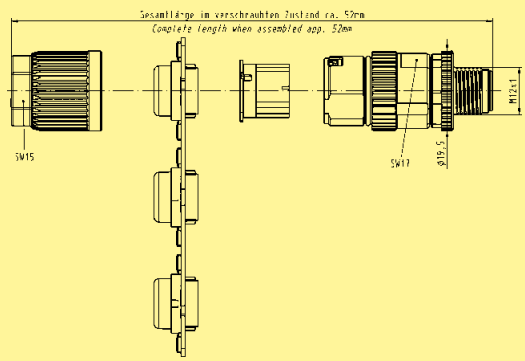
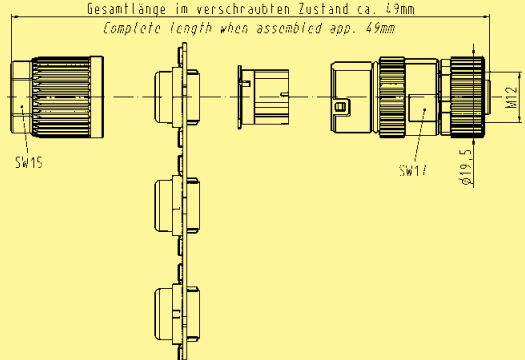


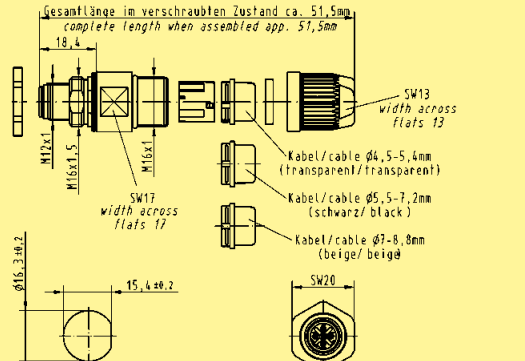
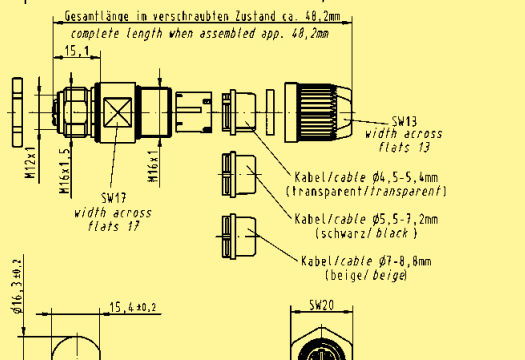
D-kodiert / D-coded

4-polig/4-pole
Buchse/female

4-polig/4-pole
Stift/male



Circular Connectors

Identification	Male	Part No.	Female	Drawing	Dimensions in mm
<p>HARAX® M12-L, screened version</p> <p>4-poles, D-coded, 0.14 - 0.34 mm², AWG 26-22 0.34 - 0.5 mm², AWG 22-20</p>  <p>4-poles, D-coded, 0.14 - 0.34 mm², AWG 26-22 0.34 - 0.5 mm², AWG 22-20</p> 					
				 <p>Gesamtlänge im verschraubten Zustand ca. 57mm Complete length when assembled app. 57mm</p>  <p>Gesamtlänge im verschraubten Zustand ca. 49mm Complete length when assembled app. 49mm</p>	
		21 03 281 1405 21 03 282 1405			
<p>HARAX® panel feed-through</p> <p>D-coded 0.14 - 0.34 mm², AWG 26 - 22</p>  <p>D-coded 0.14 - 0.34 mm², AWG 26 - 22</p> 					
				 <p>Gesamtlänge im verschraubten Zustand ca. 51,5mm complete length when assembled app. 51,5mm</p> <p>SW13 width across flats 13</p> <p>Kabel/cable Ø4,5-5,4mm (transparent/transparent)</p> <p>Kabel/cable Ø5,5-7,2mm (schwarz/black)</p> <p>Kabel/cable Ø7-8,8mm (beige/beige)</p> <p>SW17 width across flats 17</p> <p>M12x1</p> <p>M16x1,5</p> <p>M16x1</p> <p>SW20</p> <p>18,4</p> <p>15,4 ± 0,2</p> <p>Ø16,3 ± 0,2</p>	
		21 03 381 1425			
				 <p>Gesamtlänge im verschraubten Zustand ca. 48,2mm complete length when assembled app. 48,2mm</p> <p>SW13 width across flats 13</p> <p>Kabel/cable Ø4,5-5,4mm (transparent/transparent)</p> <p>Kabel/cable Ø5,5-7,2mm (schwarz/black)</p> <p>Kabel/cable Ø7-8,8mm (beige/beige)</p> <p>SW17 width across flats 17</p> <p>M12x1</p> <p>M16x1,5</p> <p>M16x1</p> <p>SW20</p> <p>15,1</p> <p>15,4 ± 0,2</p> <p>Ø16,3 ± 0,2</p>	
		21 03 381 2425			

Stock items in bold type