
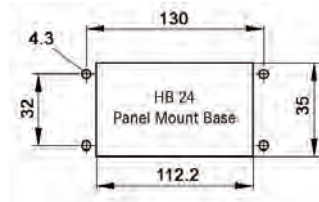
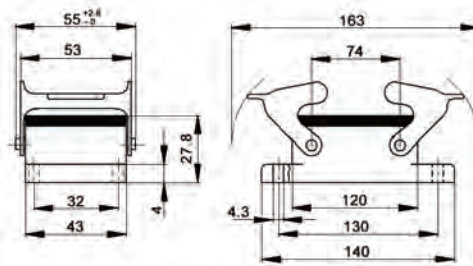


EPIC® HB 24 Panel Mount Bases

Double Levers

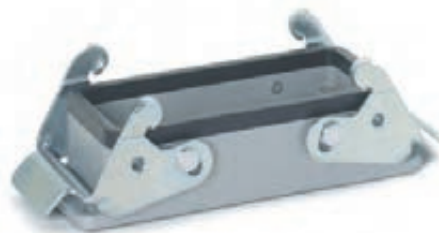

All dimensions are in mm.

Technical Data

Specifications:	DIN 43652	Protection Class:	NEMA 4, NEMA 12, IP65
Temperature Range:	-40°C to +125°C	Material:	Powder-coated aluminum alloy

Description	Part Number
Panel Mount Base	101020C0

Complete the Installation


HB Dust
Covers:
page 415

Approvals



EPIC® HB 24 Surface Mount Bases

Double Levers

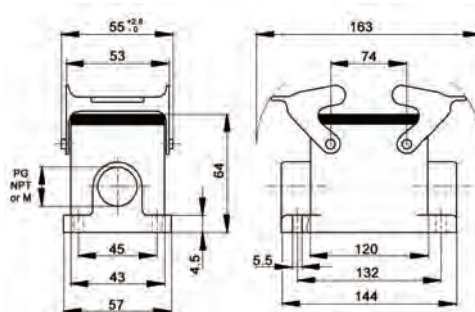

All dimensions are in mm.

Technical Data

Specifications:	DIN 43652	Protection Class:	NEMA 4, NEMA 12, IP65
Temperature Range:	-40°C to +125°C	Material:	Powder-coated aluminum alloy

PG	Size of Entry NPT	Metric	PG	Part Number NPT	Metric	Complete the Installation: SKINTOP® Strain Relief, page 368			
						PG Nylon	PG Metal	Metric Nylon	Metric Metal
2 Entries									
21	¾"	25	101050	101050NP	19105000	53015050	52015750	53111030	53112030
1 Entry									
21	¾"	25	101040	101040NP	19104000	53015050	52015750	53111040	53112030

Approvals



Complete the Installation


HB Dust
Covers:
page 415

Photographs are not to scale and are not true representations of the products in question.

For current information go to our website. If not otherwise specified, all values relating to the product are nominal values.

EPIC® HB 24 High Profile Surface Mount Bases

Double Levers

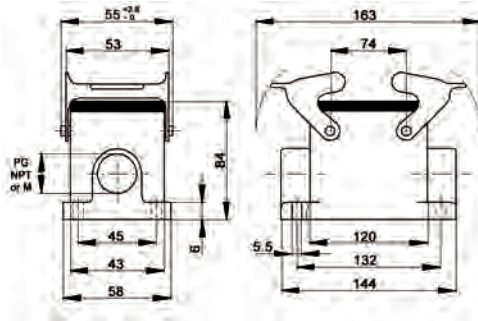

All dimensions are in mm.



Technical Data

Specifications:	DIN 43652	Protection Class:	NEMA 4, NEMA 12, IP65
Temperature Range:	-40°C to +125°C	Material:	Powder-coated aluminum alloy

PG	Size of Entry	NPT	Metric	PG	Part Number	NPT	Metric	Complete the Installation: SKINTOP® Strain Relief, page 368			
								PG Nylon	PG Metal	Metric Nylon	Metric Metal
2 Entries											
21	3/4"	25	701362	701362NP	79136200	53015050	52015750	53111030	53112030		
29	1"	32	701364	701364NP	79136400	53015060	52015760	53111040	53112040		
1 Entry											
21	3/4"	25	701352	701352NP	79135200	53015050	52015750	53111030	53112030		
29	1"	32	701354	701354NP	79135400	53015060	52015760	53111040	53112040		

Approvals




Complete the Installation



HB Dust
Covers:
page 415

EPIC® HB 24 Cable Coupler Hoods


Double Levers

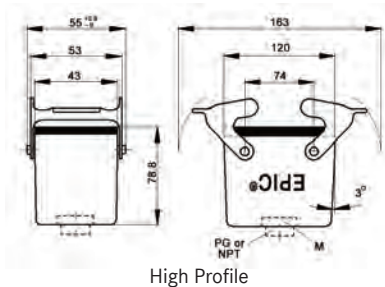

High Profile



All dimensions are in mm.

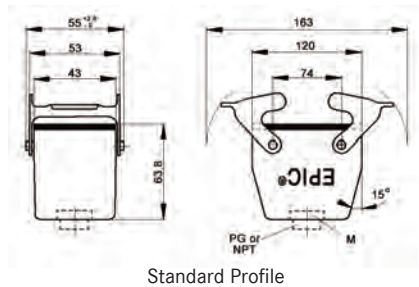

Standard Profile

Technical Data

Specifications:	DIN 43652	Protection Class:	NEMA 4, NEMA 12, IP65
Temperature Range:	-40°C to +125°C	Material:	Powder-coated aluminum alloy

PG	Size of Entry	NPT	Metric	PG	Part Number	NPT	Metric*	Complete the Installation: SKINTOP® Strain Relief, page 368			
								PG Nylon	PG Metal	Metric Nylon	Metric Metal
Standard Profile											
21	3/4"	25	101270	101270NP	19127000	53015050	52015750	53111030	53112030		
29	1"	32	101170	101170NP	19117000	53015060	52015760	53111040	53112040		
High Profile											
21	3/4"	25	701404R	701404NP	79140400	53015050	52015750	53111030	53112030		
29	1"	32	701406	701406NP	79140600	53015060	52015760	53111040	53112040		

* Metric hoods do not come with a neck.

Approvals



Complete the Installation



HB Dust
Covers:
page 415

Photographs are not to scale and are not true representations of the products in question.
For current information go to our website. If not otherwise specified, all values relating to the product are nominal values.