


EPIC® HB 24 Panel Mount Bases

Single Lever

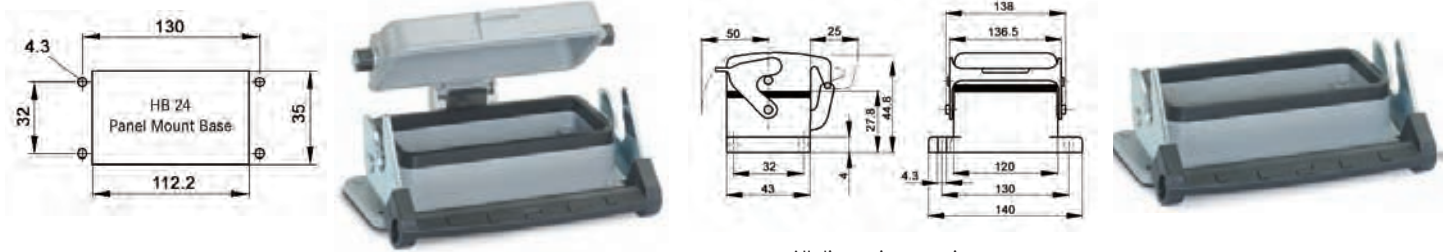

All dimensions are in mm.

Technical Data

Specifications:	DIN 43652	Protection Class:	NEMA 4, NEMA 12, IP65
Temperature Range:	-40°C to +125°C	Material:	Powder-coated aluminum alloy

Description	Part Number
Panel Mount Base	10102900
Panel Mount Base with Dust Cover	10103900

Complete the Installation




HB Dust
Covers:
page 415

Approvals



EPIC® HB 24 Surface Mount Bases

Single Lever

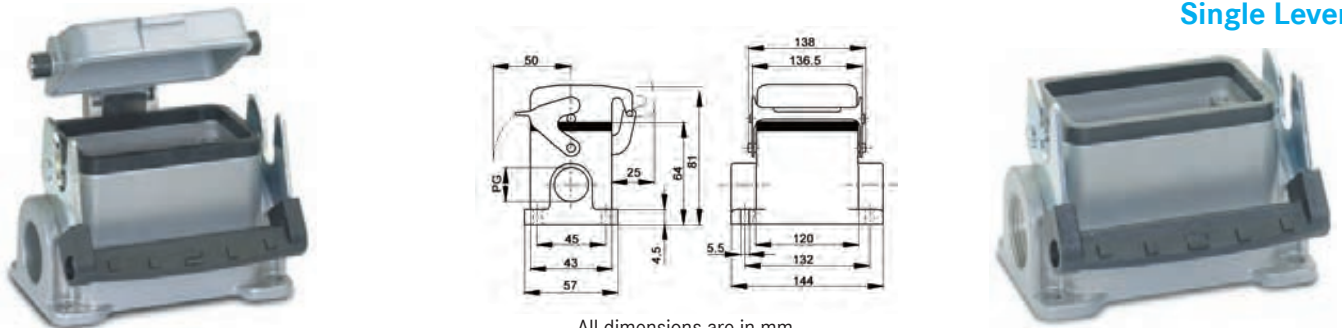

All dimensions are in mm.

Technical Data

Specifications:	DIN 43652	Protection Class:	NEMA 4, NEMA 12, IP65
Temperature Range:	-40°C to +125°C	Material:	Powder-coated aluminum alloy

Size of Entry			PG	Part Number		Metric	Complete the Installation: SKINTOP® Strain Relief, page 368			
PG	NPT	Metric		NPT	Metric		PG Nylon	PG Metal	Metric Nylon	Metric Metal
2 Entries										
21	¾"	25	101059	101059NP	19105900	53015050	52015750	53111030	53112030	
1 Entry										
21	¾"	25	101049	101049NP	19104900	53015050	52015750	53111030	53112030	
2 Entries with Dust Cover										
21	¾"	25	101099	101099NP	19109900	53015050	52015750	53111030	53112030	
1 Entry with Dust Cover										
21	¾"	25	101079	101079NP	19107900	53015050	52015750	53111030	53112040	

Approvals



Complete the Installation




HB Dust
Covers:
page 415

Photographs are not to scale and are not true representations of the products in question.
For current information go to our website. If not otherwise specified, all values relating to the product are nominal values.

EPIC® HB 24 High Profile Surface Mount Bases

Single Lever

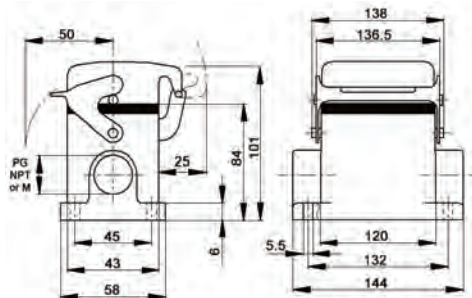

All dimensions are in mm.



Technical Data

Specifications:	DIN 43652	Protection Class:	NEMA 4, NEMA 12, IP65
Temperature Range:	-40°C to +125°C	Material:	Powder-coated aluminum alloy

PG	Size of Entry NPT	Metric	PG	Part Number NPT	Metric	Complete the Installation: SKINTOP® Strain Relief, page 368			
						PG Nylon	PG Metal	Metric Nylon	Metric Metal
2 Entries									
21	3/4"	25	701612	701612NP	79161200	53015050	52015750	53111030	53112030
29	1"	32	701614	701614NP	79161400	53015060	52015760	53111040	53112040
1 Entry									
21	3/4"	25	701602	701602NP	79160200	53015050	52015750	53111030	53112030
29	1"	32	701604R	701604NP	79160400	53015060	52015760	53111040	53112040
2 Entries with Dust Cover									
21	3/4"	25	701652	701652NP	79165200	53015050	52015750	53111030	53112030
29	1"	32	701654	701654NP	79165400	53015060	52015760	53111040	53112040
1 Entry with Dust Cover									
21	3/4"	25	701642	701642NP	79164200	53015050	52015750	53111030	53112030
29	1"	32	701644	701644NP	79164400	53015060	52015760	53111040	53112040

Approvals




Complete the Installation




HB Dust
Covers:
page 415

EPIC® HB 24 Cable Coupler Hoods


Single Lever

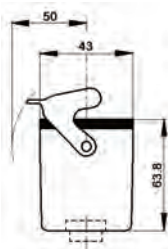


Standard Profile

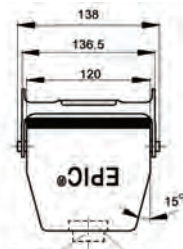

All dimensions are in mm.

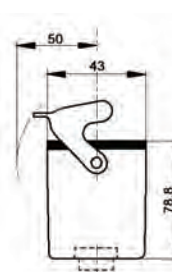

High Profile

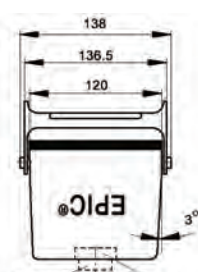

Technical Data

Specifications:	DIN 43652	Protection Class:	NEMA 4, NEMA 12, IP65
Temperature Range:	-40°C to +125°C	Material:	Powder-coated aluminum alloy

PG	Size of Entry NPT	Metric	PG	Part Number NPT	Metric*	Complete the Installation: SKINTOP® Strain Relief, page 368			
						PG Nylon	PG Metal	Metric Nylon	Metric Metal
Standard Profile									
21	3/4"	25	101279	101279NP	19127900	53015050	52015750	53111030	53112030
29	1"	32	101179	101179NP	19117900	53015060	52015760	53111040	53112040
High Profile									
21	3/4"	25	701424	701424NP	79142400	53015050	52015750	53111030	53112030
29	1"	32	701426	701426NP	79142600	53015060	52015760	53111040	53112040

* Metric hoods do not come with a neck.

Approvals



Complete the Installation



HB Dust
Covers:
page 415

Photographs are not to scale and are not true representations of the products in question.

For current information go to our website. If not otherwise specified, all values relating to the product are nominal values.