


EPIC® HB 24 Standard Hoods

Double Lever Bolts

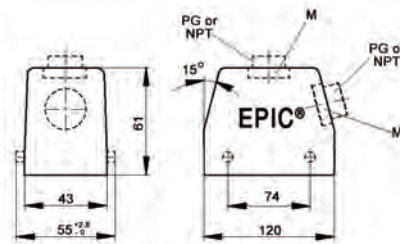

All dimensions are in mm.



Technical Data

Specifications:	DIN 43652	Protection Class:	NEMA 4, NEMA 12, IP65
Temperature Range:	-40°C to +125°C	Material:	Powder-coated aluminum alloy

PG	Size of Entry		PG	Part Number		Complete the Installation: SKINTOP® Strain Relief, page 368			
	NPT	Metric		NPT	Metric	PG Nylon	PG Metal	Metric Nylon	Metric Metal
Top Entry									
21	3/4"	25	101210	101210NP	19121000*	53015050	52015750	53111030	53112030
—	—	25x2	—	—	44422019	—	—	53111030	53112030
29	1"	32	101110	101110NP	19111000*	53015060	52015760	53111040	53112040
—	—	32x2	—	—	44422020	—	—	53111040	53112040
Side Entry									
21	3/4"	25	101130	101130NP	19113000	53015050	52015750	53111030	53112030
29	1"	32	101230	101230NP	19123000	53015060	52015760	53111040	53112040

* Metric top-entry hoods do not come with a neck.

Approvals




Complete the Installation



HB Dust Covers:
page 415

EPIC® HB 24 High Profile Hoods

Double Lever Bolts

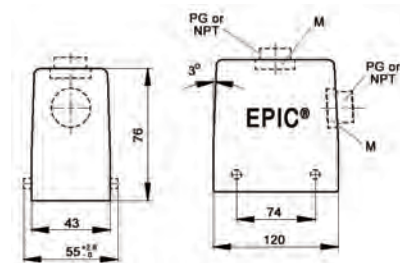

All dimensions are in mm.



* Metric hoods do not come with a neck.

Technical Data

Specifications:	DIN 43652	Protection Class:	NEMA 4, NEMA 12, IP65
Temperature Range:	-40°C to +125°C	Material:	Powder-coated aluminum alloy

PG	Size of Entry		PG	Part Number		Complete the Installation: SKINTOP® Strain Relief, page 368			
	NPT	Metric		NPT	Metric*	PG Nylon	PG Metal	Metric Nylon	Metric Metal
Top Entry									
21	3/4"	25	701504	701504NP	79150400	53015050	52015750	53111030	53112030
—	—	25x2	—	—	44422021	—	—	53111030	53112030
29	1"	32	701506	701506NP	79150600	53015060	52015760	53111040	53112040
—	—	32x2	—	—	79178500	—	—	53111040	53112040
—	—	40	—	—	79150800	—	—	53111050	53112050
Side Entry									
21	3/4"	25	701524	701524NP	79152400	53015050	52015750	53111030	53112030
29	1"	23	701526	701526NP	79152600	53015060	52015760	53111040	53112040
—	—	40	—	—	79152800	—	—	53111050	53112050

Approvals



Complete the Installation



HB Dust Covers:
page 415

Photographs are not to scale and are not true representations of the products in question.
For current information go to our website. If not otherwise specified, all values relating to the product are nominal values.